


Art. no. 348244

Surface-mounted ceiling light Can IP44, 1x 7.5 W GU10, black

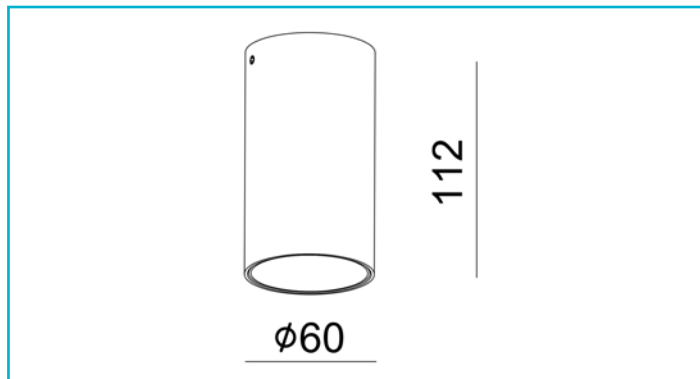

The CAN surface-mounted ceiling light provides a reliable and versatile lighting solution for commercial and private applications. Specially developed for use in wet rooms, the light is available as an IP44 version. The widely used GU10 base enables quick and simple replacement of the lamp, while the screw-on cylinder housing allows tool-free access. Installation is simple due to the push terminals for rigid and flexible conductors. The CAN surface-mounted ceiling light is part of a versatile light series, which also contains pendant, wall, reading and outdoor lights.

Special features

- USP
- USP
- USP
- USP
- USP

Housing Material	Aluminium
Housing Color	Black
Material of Lens	Polycarbonate - PC
Protection Class	Protection class II/protective insulation
max. Power	1x max. 7.5 W
Rated Input Voltage Frequency	220-240 V/AC 50 / 60 Hz
Socket Description	GU10
Socket Quantity	1 PCS
Connection Type	Clamp
Dimmable	Yes
Control	Dimmable via optional light source
Motion Detector	No
Execution	Without lamp
Light Exit Surfaces	1
Light characteristics	Direct
Light direction	Below
Height	105 mm
Diameter	60 mm
Product weight	212 g
IP Protection Class	IP 44