


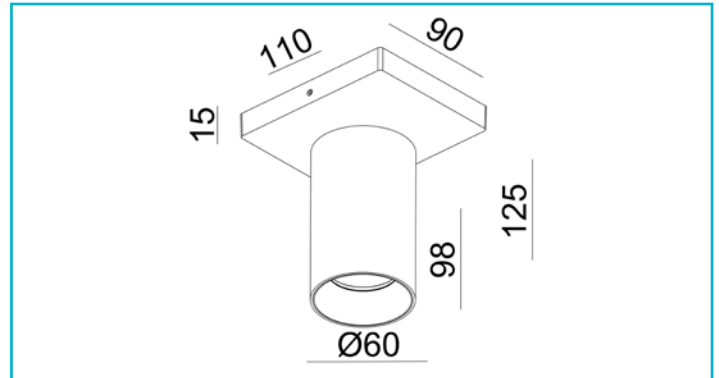

The square CAN surface-mounted ceiling light provides a flexible lighting solution for commercial and private spaces. Available as a one-, two- and three-luminaire variant in the colours black and white, it enables precise alignment of the light using rotating and swivelling luminous elements. The widely used GU10 base enables quick and simple replacement of the lamp, while the screw-on cylinder housing enables tool-free access. Installation for rigid and flexible conductors is easy and efficient due to the integrated push terminals. The CAN surface-mounted ceiling light is part of a versatile series, which also contains pendant, wall, reading and outdoor lights.

Special features

- Flat and discreet lamp base
- Can be customised with a wide range of accessories
- Replaceable lamp to offer an individual lighting solution
- Can be combined with the comprehensive CAN series product family

Housing Material	Aluminium
Housing Color	Black
Material of Lens	Polycarbonate - PC
Protection Class	Protection class I/protective grounding
max. Power	1x max. 7.5 W
Rated Input Voltage Frequency	220-240 V/AC 50 / 60 Hz
Socket Description	GU10
Socket Quantity	1 PCS
Connection Type	Clamp
Dimmable	Yes
Control	Dimmable via optional light source
Motion Detector	No
Execution	Without lamp
Swivel Angle	90 Degree
Rotation Angle	350 Degree
Light Exit Surfaces	1
Light characteristics	Direct
Light direction	Below
Height	125 mm
Diameter	60 mm
Base length	110 mm
Base width	90 mm
Base height	15 mm
Product weight	290 g
IP Protection Class	IP 20