


Art. no. 731223

Surface-mounted wall light Can IP65, 1 x 7.5 W GU10, white

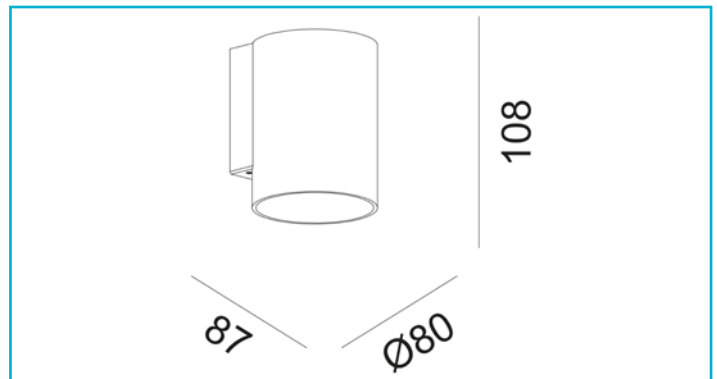

The CAN IP65 surface-mounted wall light is a robust and versatile solution for outdoor areas. Available as a classic wall light and as an up/down variant with light emission on both sides, it is ideal for demanding environments. The IP65 certification guarantees protection against dust and water. The widely used GU10 base enables quick and simple replacement of the lamp. Push terminals for rigid and flexible conductors facilitate simple installation. The CAN outdoor light is part of a versatile series and is also available as a pendant, ceiling, wall and reading light.

Special features

- Replaceable lamp to offer an individual lighting solution
- Can be combined with the comprehensive product family of the CAN series

Housing Material	Aluminium
Housing Color	White
Material of Lens	Glass
Protection Class	Protection class I/protective grounding
max. Power	1x max. 7.5 W
Rated Input Voltage Frequency	220-240 V/AC 50 / 60 Hz
Socket Description	GU10
Socket Quantity	1 PCS
Connection Type	Clamp
Control	Dimmable via optional light source
Motion Detector	No
Execution	Without lamp
Light Exit Surfaces	1
Light characteristics	Direct
Light direction	Below
Length	87 mm
Height	108 mm
Diameter	80 mm
Product weight	556 g
IP Protection Class	IP 65