


Art. no. 862276

Power supply unit (CV, DC) dimmable BASIC, DIM, CV,
LCP240AD-1H48 V

 **DEKOLIGHT**

 NEW

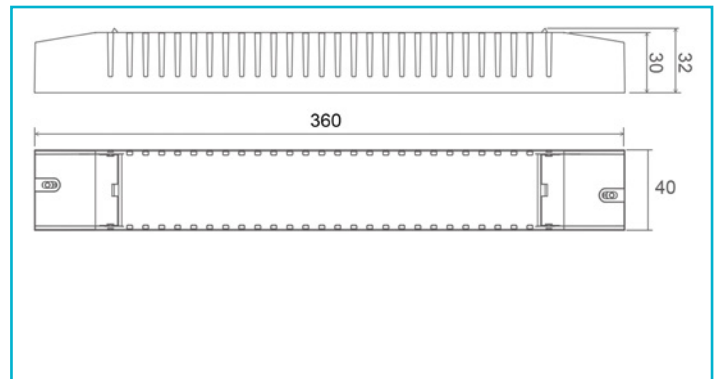

Special features

- Can be dimmed using DALI2/DALI1
- Can be dimmed using 0-10 V/1-10 V
- Can be dimmed using touch dimmer via 230 V push-button (iPush)
- New Intelli-Push function [shortcut synchronises all connected power supply units when needed]
- Power supply unit and PWM dimmer in one device
- Secured against short circuits and overloads
- Overheating protection

Housing Material	Plastic
Housing Color	White
Operating Mode	Constant voltage
Protection Class	Protection class II/protective insulation
Power	240 W
Output Voltage	48 V/DC
Output Current	0-5000 mA
Dimmable	Yes
Control	DALI 2 / DT6, 0-10 V, 1-10 V, Intelli Push-Dim
Number of Channels	1
Power Factor	0.98
Connection Type	Clamp

Inrush Current max.	60 A / 430 μ s
Reference Point Tc	85 °C
Working Temperature	-20 to 50 °C
Storage Temperature	-40 to 85 °C
IP Protection Class	IP 20

Switching Cycles	25000
Life Time	50000 h

Length	360 mm
Width	40 mm
Height	32 mm
Product weight	595 g

