



D-D5000B Specifications

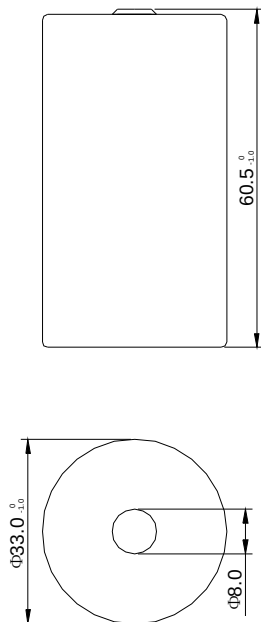


Nominal Capacity	5000mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	<6mΩ
Charge	
Standard Charge	500mA x 15h
Rapid Charge	5000mA x 1.2h
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	33.0mm
Height	60.5mm
Weight	140 g
Operating Temperature	
Charge	0 ~ 45°C
Discharge	-20 ~ 60°C
Storage Temperature	
Within 1 month	-5 ~ 35°C
Within 6 months	0 ~ 35°C

Standard charge characteristics

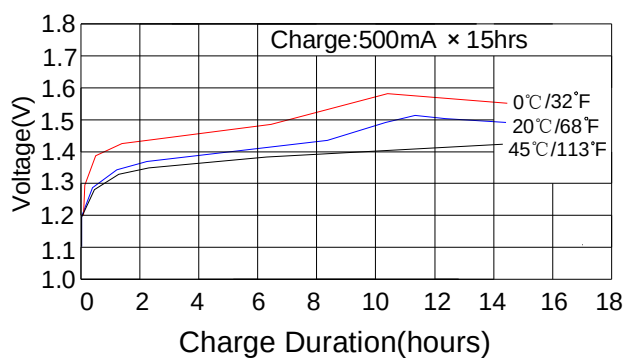

Rapid charge characteristics

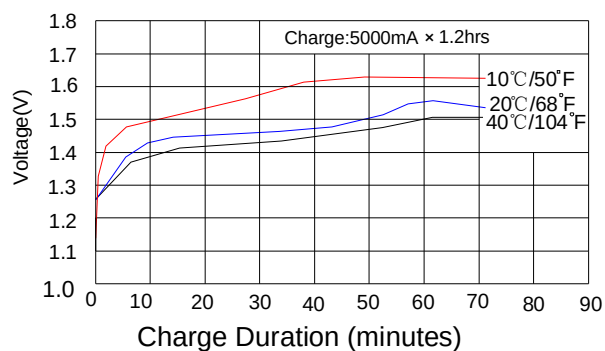

Discharge characteristics

