


H-1/3AA250 Specifications

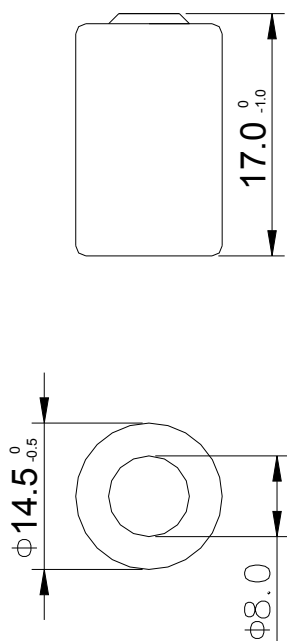

Nominal Capacity 300mAh

Nominal Voltage 1.2V

Internal Impedance (at 1000Hz) < 60mΩ

Charge

Standard Charge 30mA x 15h

Rapid Charge 300mA x 1.2h

Discharge Cut-off Voltage 1.0V

Max Dimension (with tube)

Diameter 14.5mm

Height 17.0mm

Weight 8 g

Operating Temperature

Charge 0 ~ 45°C


Discharge -20 ~ 60°C

Storage Temperature


Within 1 month -5 ~ 35°C

Within 6 months 0 ~ 35°C

Standard charge characteristics

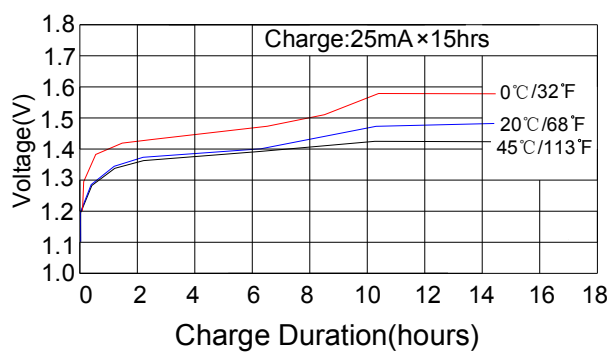

Rapid charge characteristics

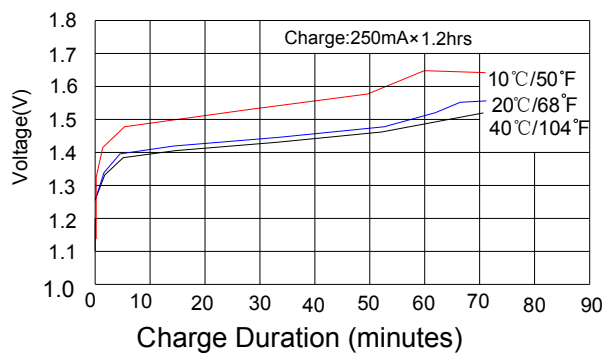

Discharge characteristics

