



H-1/2D3500 Specifications

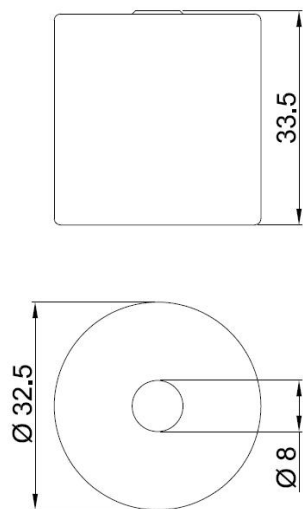

Nominal Capacity	3500mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	<20mΩ
Charge	
Standard Charge	350mA x 16h
Fast Charge	3500mA x 1.2h
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	32.5mm
Height	33.5mm
Weight	85 g
Operating Temperature	
Standard charge	0 ~ 40°C
Fast charge	10 ~ 35°C
Trickle charge	0 ~ 45°C
Discharge	-10 ~ 50°C
Storage Temperature	
More than 1 month	0 ~ 40°C
More than 3 months	0 ~ 30°C
More than 12 months	0 ~ 25°C

Charge at 20°C

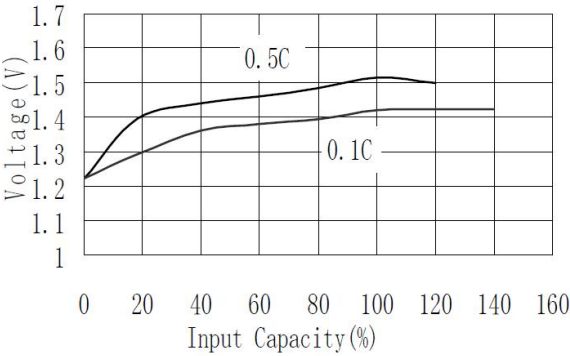

Discharge at high rate, 20°C

