



D-AA800H Specifications

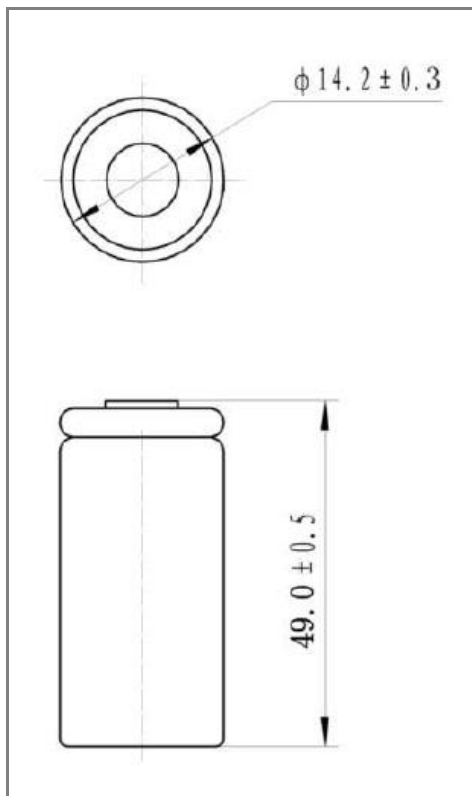


Nominal Capacity	800mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	< 28mΩ
Charge	
Standard Charge	80mA x 16h
Rapid Charge	400mA x 2.4h
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	14.2±0.3mm
Height	49.0±0.5mm
Weight	22 g
Operating Temperature	
Charge	0 ~ 70°C
Discharge	-20 ~ 70°C
Storage Temperature	-20 ~ 40°C

Standard charge characteristics

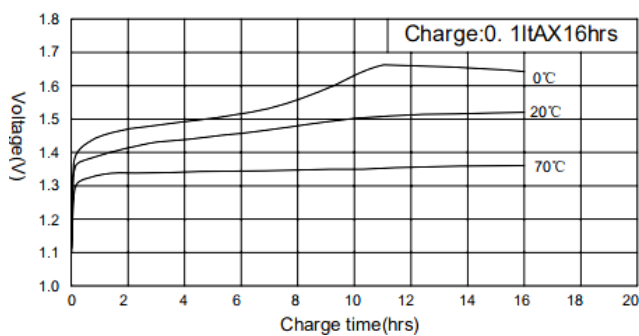

Charge / discharge efficiency

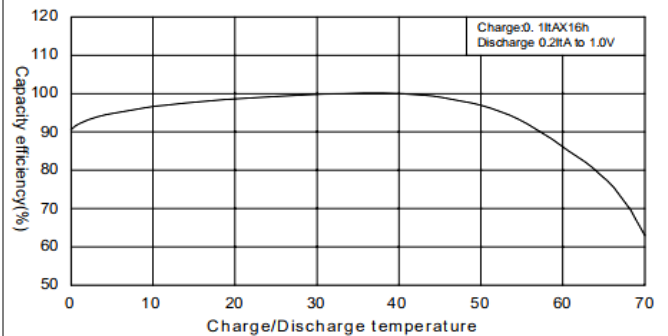

Discharge characteristics

