



H-AA2000H Specifications

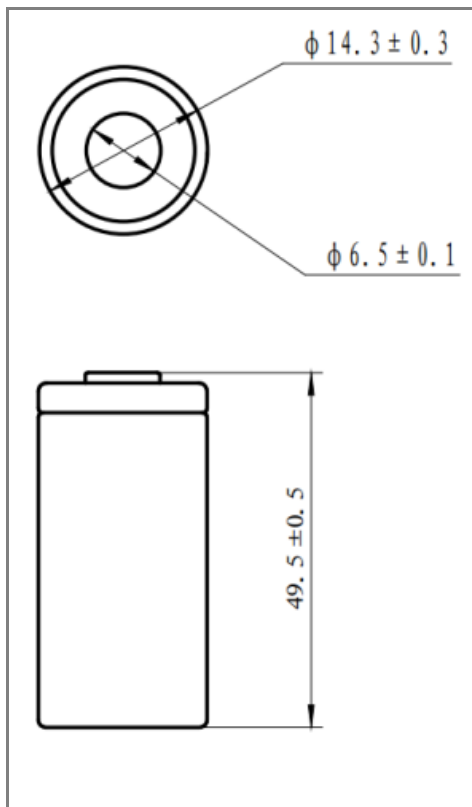


Nominal Capacity	2000mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	30m Ω (After Charge)
Charge	
Standard Charge	200mA x 15h
Rapid Charge	1000mA x 2.4h
Trickle Charge	60mA ~ 100mA
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	14.3 $\pm$ 0.3mm
Height	49.5 $\pm$ 0.5mm
Weight	29g
Operating Temperature	
Charge	-5 ~ 70°C
Discharge	-20 ~ 70°C
Storage Temperature	-20 ~ 40°C


Standard Charge

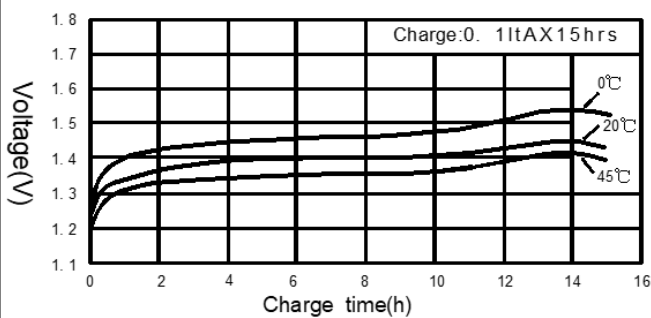

Charge/discharge efficiency

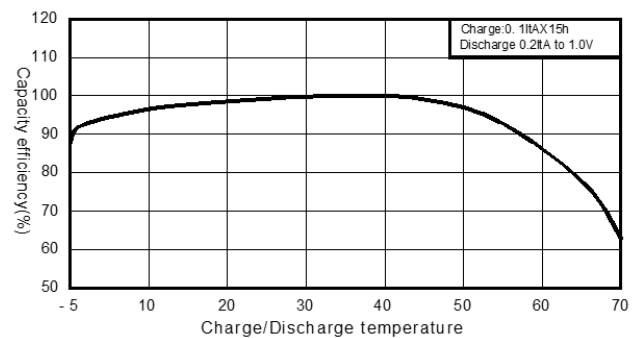

Discharge Characteristics

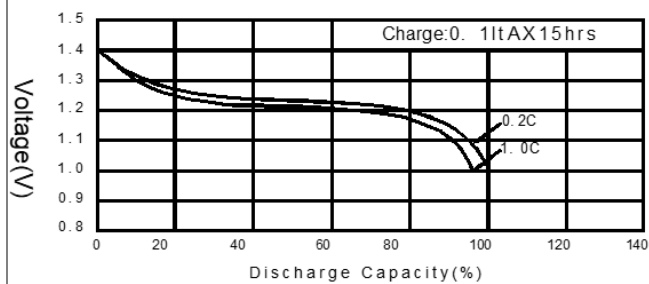

Discharge Characteristics

