



D-SC2000H Specifications

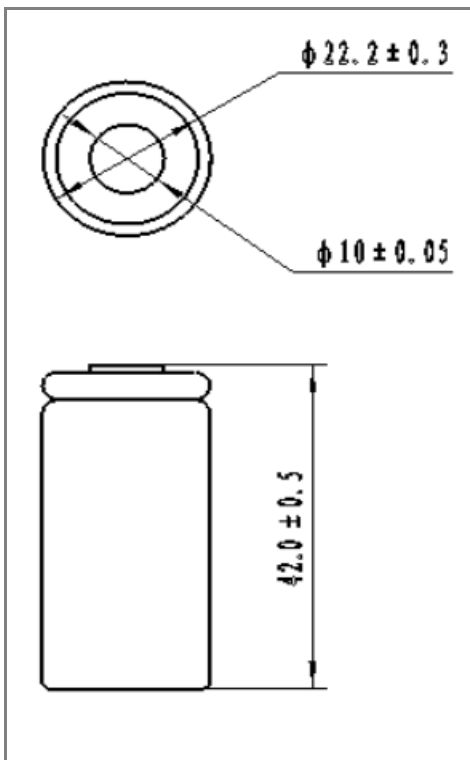


Nominal Capacity	2000mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	15m Ω (After Charge)
Charge	
Standard Charge	200mA x 16h
Rapid Charge	1000mA x 2.4h
Trickle Charge	60mA ~ 100mA
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	22.2 $\pm$ 0.3mm
Height	42.0 $\pm$ 0.5mm
Weight	50 g
Ambient Temperature	
Standard charge	-5 ~ 70°C
Rapid charge	5 ~ 70°C
Discharge	-20 ~ 70°C
Storage	-20 ~ 40°C


Standard charge

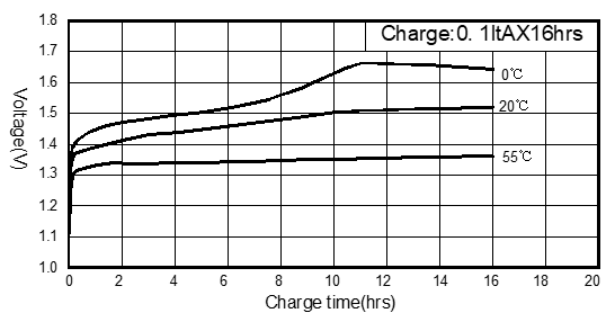

Charge/discharge efficiency

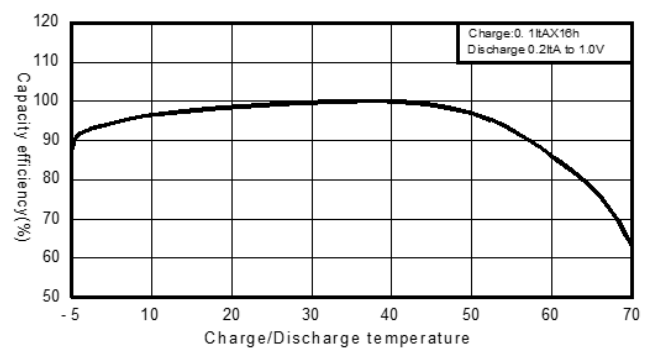

Cycle life characteristics

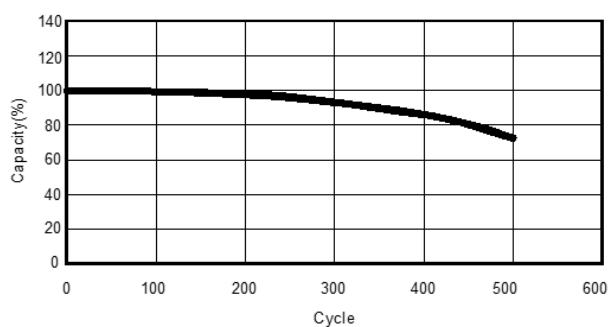

Discharge characteristics

