



H-4/3A4000H Specifications

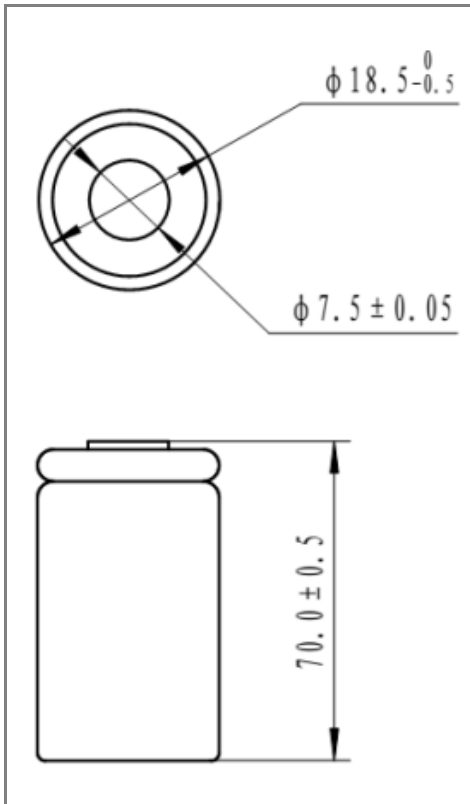


Nominal Capacity	4000mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	15m Ω (After Charge)
Charge	
Standard Charge	400mA x 15h
Rapid Charge	2000mA x 2.1h
Trickle Charge	0.03ItA-0.05ItA
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	18.5 $\pm$ 0.5mm
Height	70.0 $\pm$ 0.5mm
Weight	65g
Operating Temperature	
Charge	0 ~ 55 $^{\circ}$ C
Discharge	-20 ~ 70 $^{\circ}$ C
Storage Temperature	-20 ~ 40 $^{\circ}$ C


Standard Charge

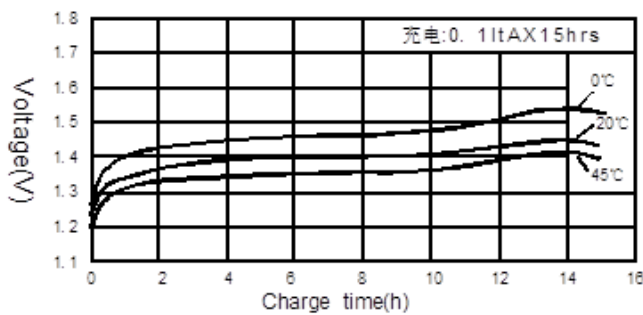

Rapid Charge

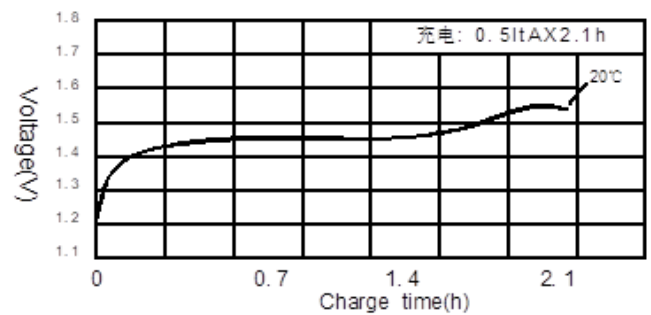

Discharge Characteristics

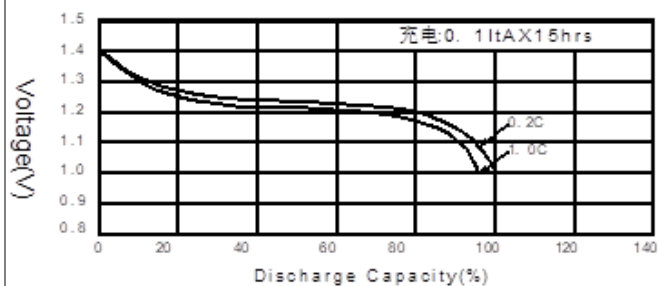

Discharge Characteristics

