


# Ada35Needle0,6

FLEXIBLE Ø0,6MM NEEDLE / Ø4MM SOCKET ADAPTER

ADAPTATEUR POINTE Ø0,6 FLEXIBLE / FICHE FEMELLE Ø4MM

ADAPTER FLEXIBEL PRÜFSPITZE / Ø4MM BUCHSE

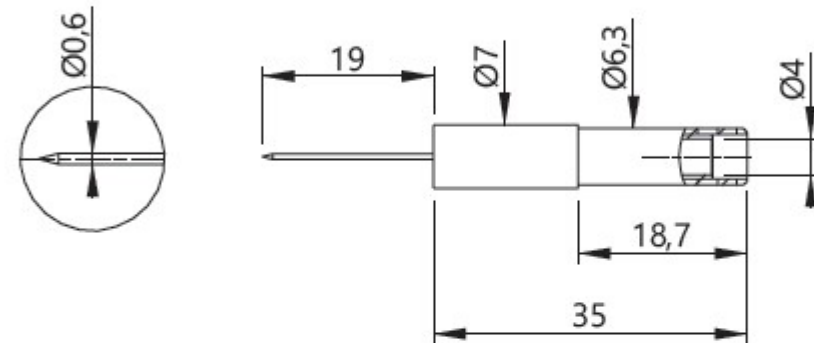

Reference  
Référence  
Bestell-Nr

Ada35Needle0.6-#

| Rated voltage<br>Tension assignée<br>Bemessungsspannung | Rated current<br>Intensité assignée<br>Bemessungsstrom | Contact parts<br>Contacts<br>Kontaktteile                                                                                     | Insulation<br>Isolant<br>Isolierteile | Colours [#]<br>Couleurs [#]<br>Farben [#]                                                                                                                     |
|---------------------------------------------------------|--------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------|---------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------------------------------|
| ≤30VAC ≤60VDC                                           | 1A                                                     | Ni Brass coated (tip uncoated)<br><b>Laiton nickelé (pointe non revêtue)</b><br>Messing vernickelt (Spitze nicht beschichtet) | PP                                    | <div>R</div> <div>N</div> <div>BL</div> <div>V</div> <div>J</div> <div>BC</div> <div>2</div> <div>0</div> <div>6</div> <div>5</div> <div>4</div> <div>9</div> |

