

PRODUCT DATA SHEET

3512a

Pressed cable terminal insulated – 3512 A Cu sn 6-1



Product Overview

SKU	3512a
Part description	Pressed cable terminals uninsulated
Part designation	3512 A Cu sn 6-1

Material

Component	Copper
Surface	pure tin-plated

Technical Details


Net weight kg/1000	0.653
Conductor cross-section	0.50 – 1.50mm ² / AWG 22 – 16
Maximum electrical rating AWG 22	9A
Maximum electrical rating AWG 20	12A
Maximum electrical rating AWG 18	17A
Maximum electrical rating AWG 16	18A

Marking

Certified UL	E235797
Standard	DIN 46234

Dimensions

for Bolt	M6
A [mm]	5.00
D [mm]	6.40
D1 [mm]	1.60
D3 [mm]	10.00
L [mm]	13.00
R [mm]	6.50
S [mm]	0.80

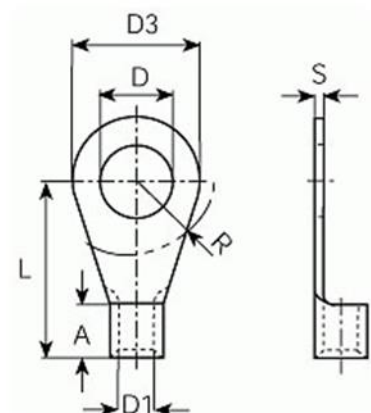

© 2022 | Vogt AG Verbindungstechnik

The general conditions of sale of Vogt AG apply to this product. See www.vogt.ch/downloads.

This data sheet is regularly revised but is not subject to any change service.

This article is a freely available article according to the above specification. The availability of certificates according to EN 10204, others acceptance test certificates or material compliance and customer-specific part submission warrant, are to be requested by the customer and, if available, can be obtained for a fee.

You can find more information on the free available product conformities at www.vogt.ch/downloads.

Form checked and approved special field: 17.02.2022 haatob

Form created: 17.02.2022 haatob

PDS_3512a_EN_V1.docx

Content created: 20.12.24 karlea / Version: 01

Page 1 / 1

PM-FO-03 / Version: 00