

Item no.: 3125124, 3125125, 3125126, 3125127,
3414945, 3414946, 3414947, 3414948, 3414949

Data Sheet

Installation box


- Cover Materials: Fire retardant ABS.
- Transparent part of cover material: PC
- Bottom box material: Cold rolled steel plate.

Dimensions

Item no. 3125124

Overall Dimensions: 240 x 200 x 95 mm

Bottom Dimensions: 217 x 180 x 75 mm

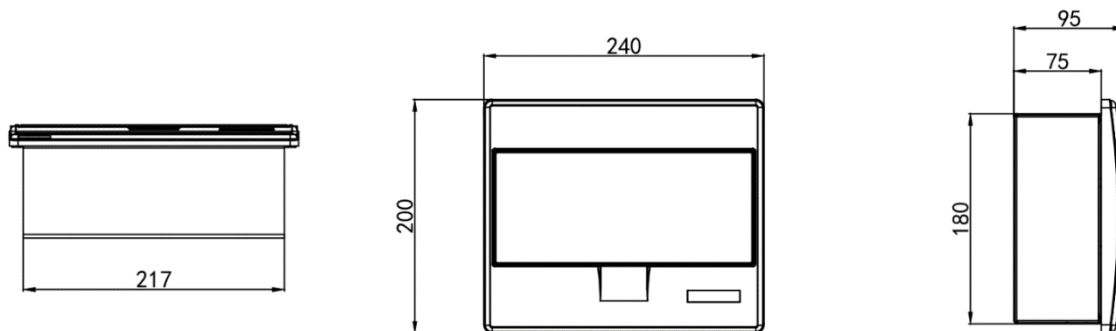

item no. 3125125

Overall Dimensions: 295 x 230 x 95 mm

Bottom Dimensions: 270 x 210 x 75 mm

Item no. 3125126


Overall Dimensions: 366 x 230 x 95 mm

Bottom Dimensions: 340 x 210 x 75 mm

Item no. 3125127

Overall Dimensions: 438 x 230 x 95 mm

Bottom Dimensions: 412 x 210 x 75 mm

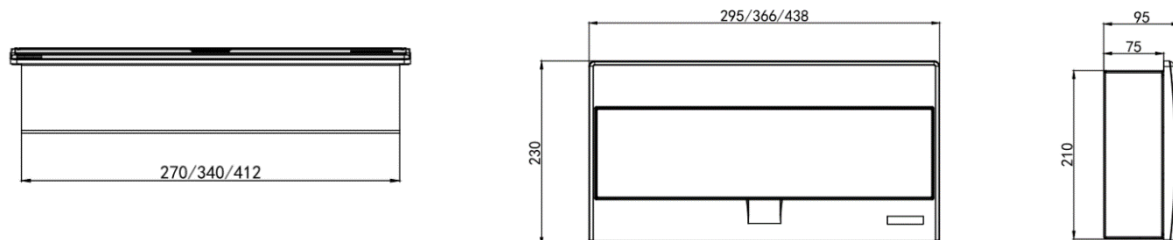


Item no.: 3125124, 3125125, 3125126, 3125127,
3414945, 3414946, 3414947, 3414948, 3414949

Data Sheet

Item no. 3414945

Overall Dimensions: 395 x 295 x 95 mm


Bottom Dimensions: 375 x 268 x 75 mm

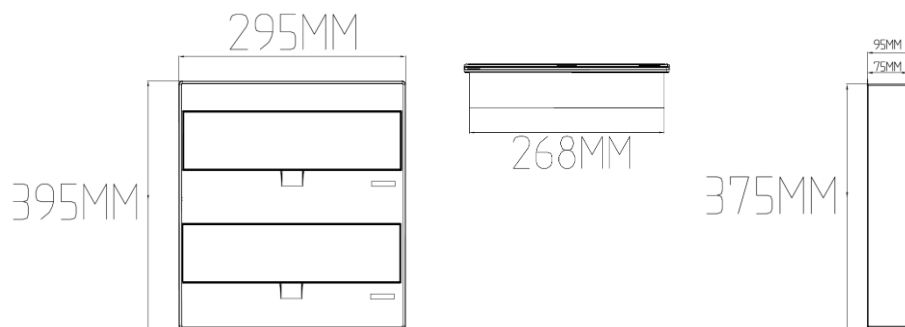

Item no. 3414946

Overall Dimensions: 395 x 366 x 95 mm


Bottom Dimensions: 375 x 340 x 75 mm

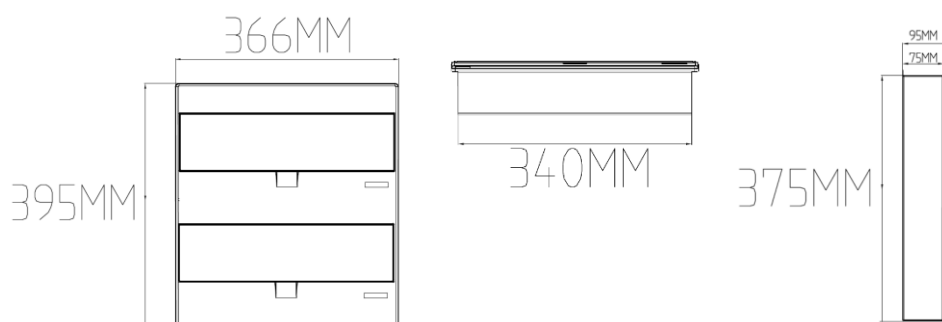

Item no. 3414947

Overall Dimensions: 395 x 438 x 95 mm

Bottom Dimensions: 375 x 412 x 75 mm

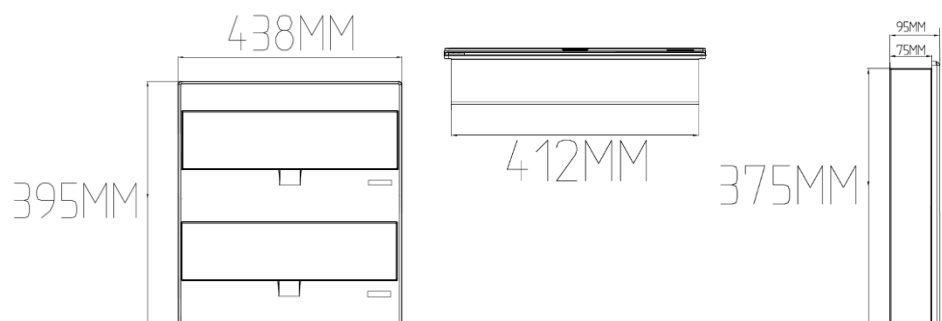


Item no.: 3125124, 3125125, 3125126, 3125127,
3414945, 3414946, 3414947, 3414948, 3414949

Data Sheet

Item no. 3414948

Overall Dimensions: 690 x 366 x 95 mm

Bottom Dimensions: 670 x 340 x 75 mm

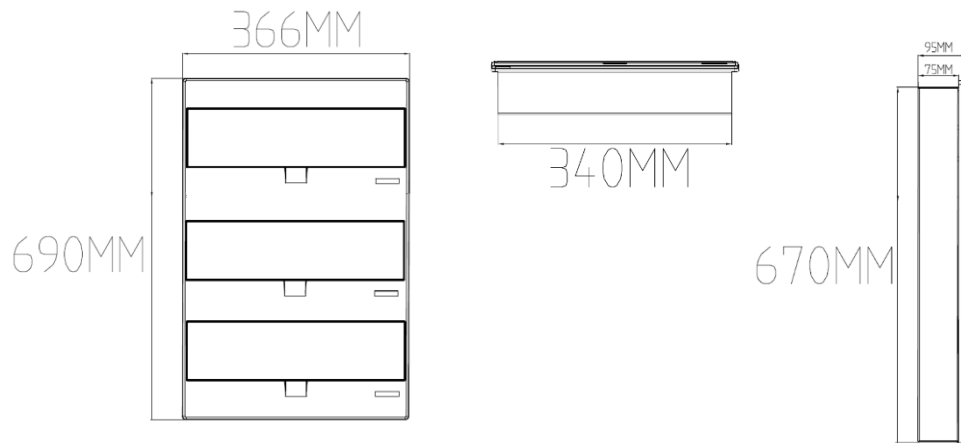

Item no. 3414949

Overall Dimensions: 690 x 438 x 95 mm

Bottom Dimensions: 670 x 412 x 75 mm

