

VOLTCRAFT

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MSK-130 rot MSK-130 sw ALLIGATOR CLIP

CE


Item no. 3431119 (MSK-130 rot)

Item no. 3431122 (MSK-130 sw)

FEATURES

CAT IV 600V // CAT III 1000V // 10 A

DIMENSIONS

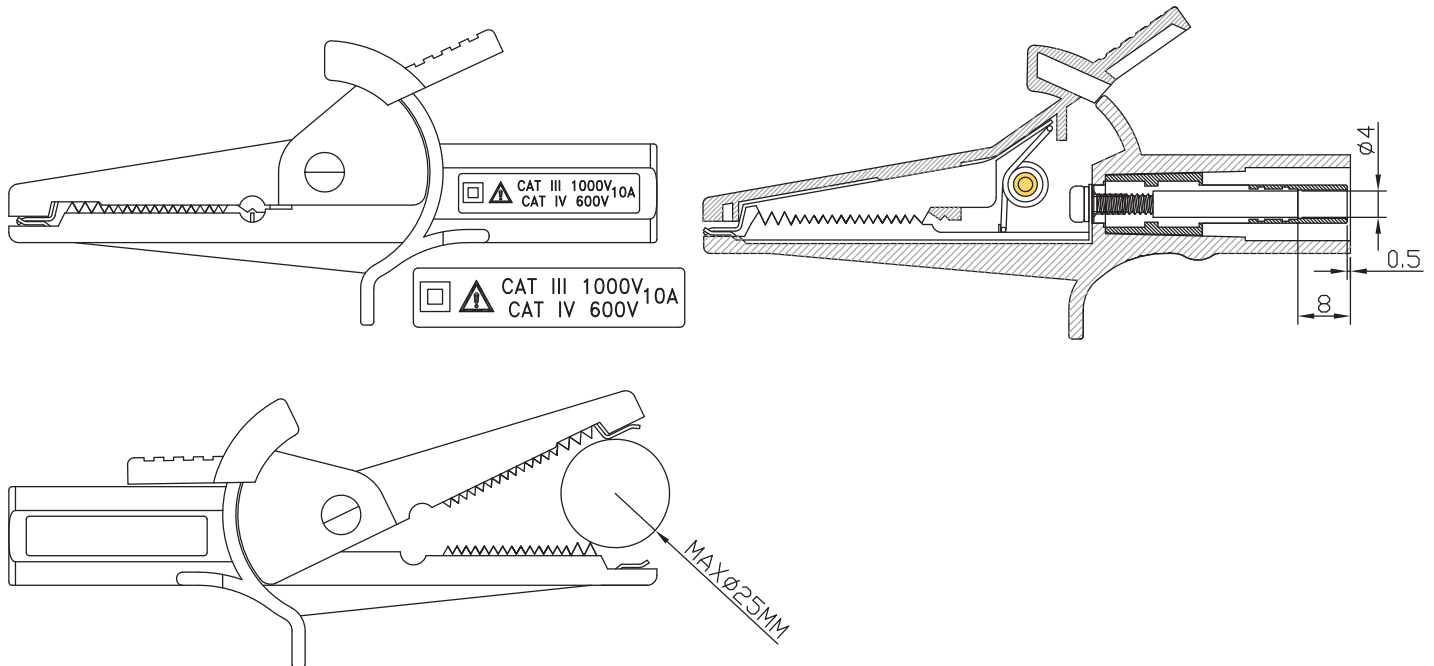

All dimensions in mm

TECHNICAL DATA

Item	Value
Overvoltage category	CAT III 1000V, CAT IV 600V
Rated current	max. 10 A
Form	Straight
Connector	4 mm
Clamp opening	max. 25 mm
Colour	Red/black
Insulated material	PA
Working temperature and humidity	-5 to +45 °C / < 85 % RH
Storage temperature and humidity	-10 to +50 °C / < 85 % RH
Dimensions	100 x 50 x 25 mm
Weight	25 g

PACKAGE CONTENTS

Alligator clip



Item no. 3431119



Item no. 3431122

