

VOLTCRAFT

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MSK-135 rot MSK-135 sw ALLIGATOR CLIP

CE


Item no. 3431120 (MSK-135 rot)

Item no. 3431123 (MSK-135 sw)

FEATURES

CAT IV 600V // CAT III 1000V // 10 A

DIMENSIONS

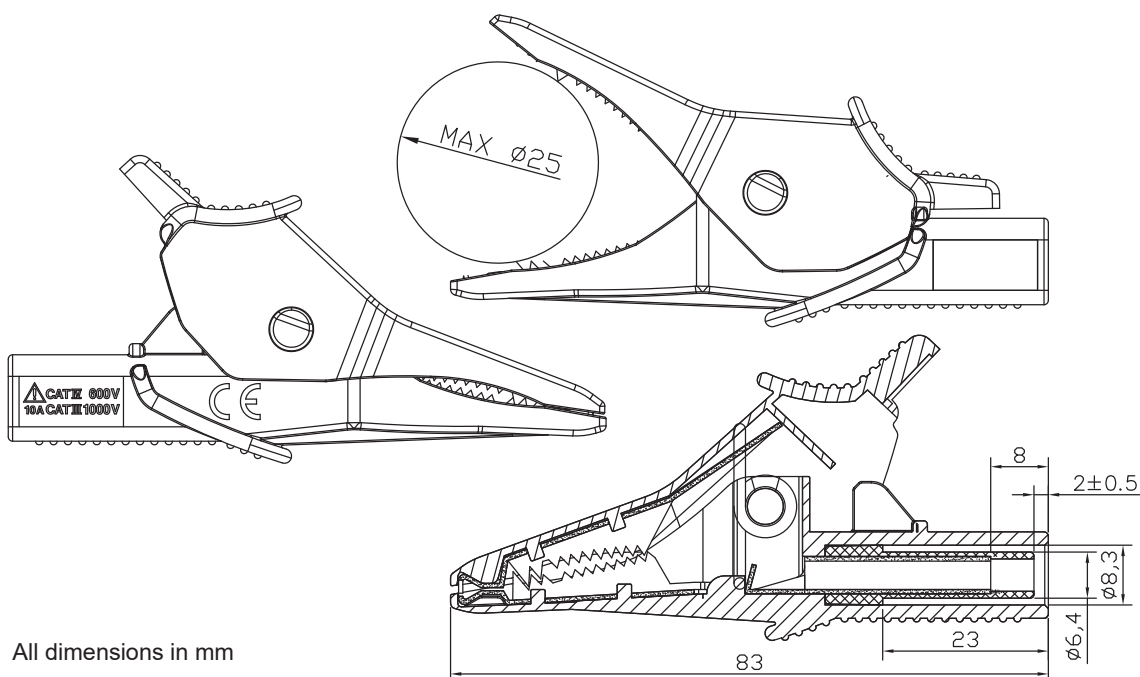

All dimensions in mm

TECHNICAL DATA

Item	Value
Overvoltage category	CAT III 1000V, CAT IV 600V
Rated current	max. 10 A
Form	Rounded
Connector	4 mm
Clamp opening	max. 25 mm
Colour	Red/black
Insulated material	PA
Working temperature and humidity	-5 to +45 °C / < 85 % RH
Storage temperature and humidity	-10 to +50 °C / < 85 % RH
Dimensions	83 x 40 x 16 mm
Weight	19 g

PACKAGE CONTENTS

Alligator clip



Item no. 3431120



Item no. 3431123

