

VOLTCRAFT

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MSK-125 rot **MSK-125 sw** **ALLIGATOR CLIP**

CE



Item no. 3431126 (MSK-125 rot)

Item no. 3431127 (MSK-125 sw)

FEATURES

CAT II 300V // 10 A

DIMENSIONS

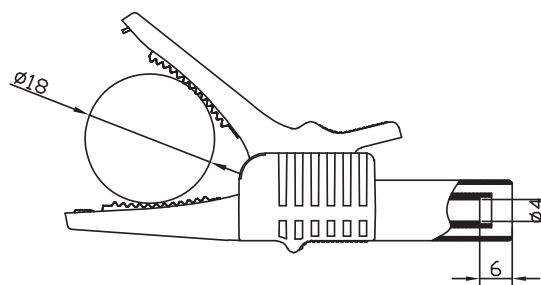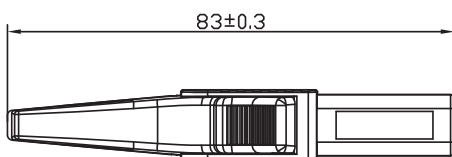

All dimensions in mm

TECHNICAL DATA

Item	Value
Overvoltage category	CAT II 300V
Rated current	max. 10 A
Connector	4 mm
Clamp opening	max. 18 mm
Colour	Red/black
Insulated material	PA
Working temperature and humidity	-5 to +45 °C / < 85 % RH
Storage temperature and humidity	-10 to +50 °C / < 85 % RH
Dimensions	83 x 37 x 12 mm
Weight	12 g

PACKAGE CONTENTS

10x Alligator clips



Item no. 3431126



Item no. 3431127

