

VOLTCRAFT

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MSS-120 MAGNETIC TEST PROBE




Item no. 3431128

FEATURES

CAT III 1000V // CAT IV 600V // 5 A

DIMENSIONS

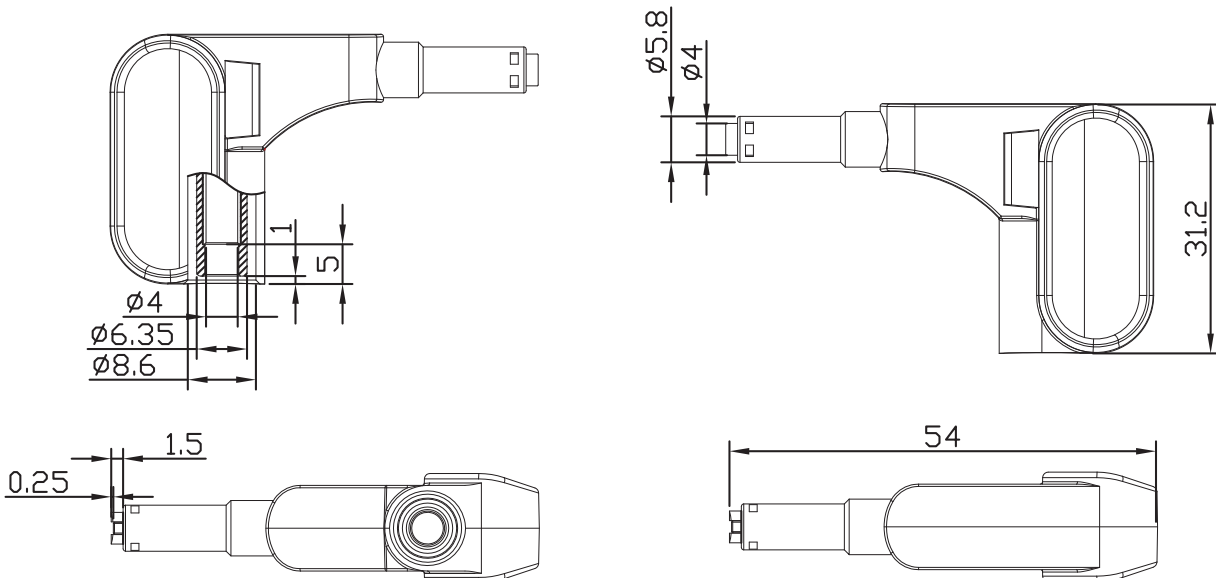

All dimensions in mm

TECHNICAL DATA

Item	Value
Overvoltage category	CAT III 1000V, CAT IV 600V
Rated current	max. 5 A
Socket	4 mm for banana plug
Colour	Black
Form	Right angle (90°)
Insulated material	PA
Pin material	Copper
Working temperature and humidity	-5 to +45 °C / <85 % RH
Storage temperature and humidity	-10 to +50 °C / <85 % RH
Dimensions (approx.)	54 x 31 x 14 mm (L x H x D)
Weight	11 g

PACKAGE CONTENTS

20x Magnetic test probes

