


Adjustable cable lockout

Item No. 3436272

Overview

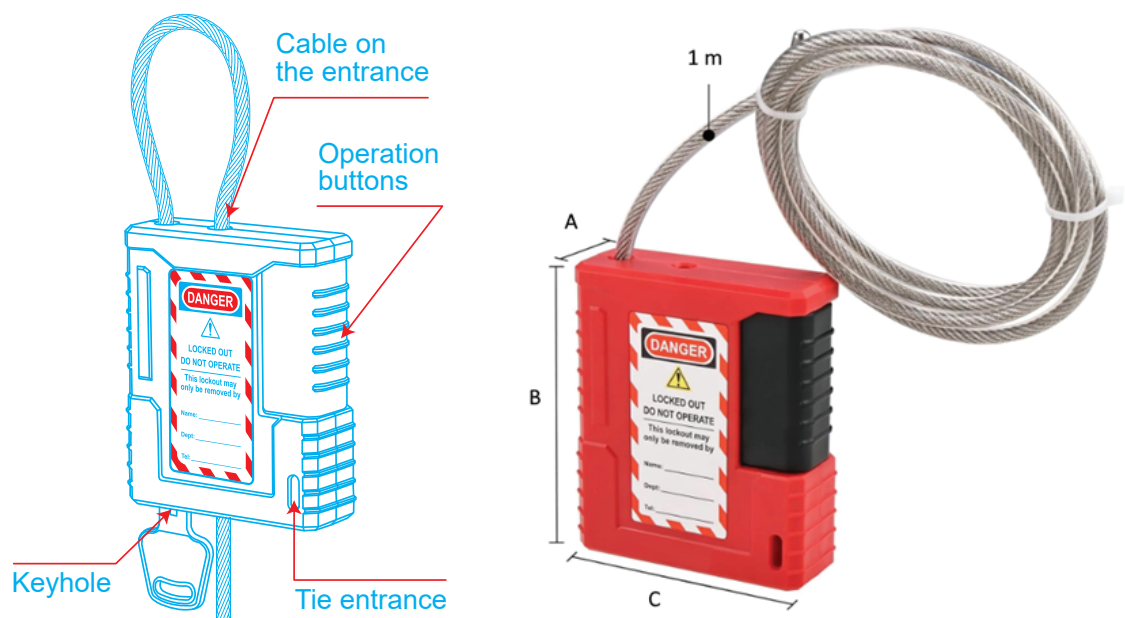

Delivery contents

- 1x Adjustable cable lockout
- 1x Key
- 1x Cable tie

Features

- Industrial-grade nylon body with stainless steel cable (4mm diameter, 1m length)
- Withstands extreme temperatures (-20°C to 120°C), oils, and moisture
- Simple push-through cable locking mechanism
- Keyed alike for convenience
- Secures multiple breakers, valves, or equipment with single lock
- Enables long-distance multi-point lockout
- Prevents unauthorized access to hazardous areas
- Compatible with handles up to 8mm thick

Technical data

Material	Plastic ABS with stainless steel cable
Stainless steel cable	1 m x Ø 4 mm
Temperature resistance	-20 to +120 °C
Weight	104 g (Lock)
Product dimensions (A x B x C)	22 x 75.8 x 61.8 mm