


Pre-Datasheet

- **Style: Simple**
- **Size: Pedestal**
- **Material: Steel Material**

Main Features

- An add-on pedestal for AX700 / AX700 TG
- Ventilation: Supports up to 8 x 120mm fan
Supports up to 8 x 140mm fan
- Support : Supports DIY cooling solutions

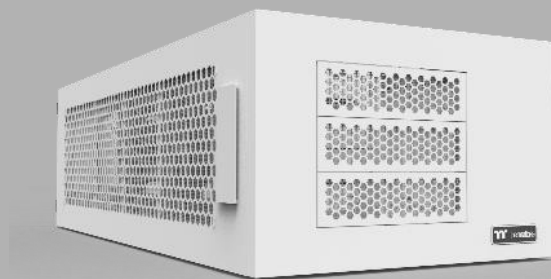


Specification

Model	AX100	AX100 Snow
P/N	CA-11C-00D1NN-00	CA-11C-00D6NN-00
Color	Black	White
Case Type	Pedestal	
Chassis Dimension (H*W*D)	201 x 320 x 678.3 mm (7.91 x 12.60 x 26.71 inch)	
Side Panel	Steel	
Material	SPCC	
Cooling System	-	
Drive Bays	8 x 3.5" or 2.5" (HDD Cage)	
PSU	Standard PS2 PSU (optional)	
Fan Support	Left Side: 4 x 120mm , 4 x 140mm Right Side: 4 x 120mm , 4 x 140mm	
Radiator Support	Left Side: 1 x 480mm (MAX), 1 x 560mm (MAX) Right Side: 1 x 480mm (MAX), 1 x 560mm (MAX)	
Clearance	PSU length limitation: 220mm (with two bottom fans)	

Packaging


Package Information	AX100	AX100 Snow
P/N	CA-11C-00D1NN-00	CA-11C-00D6NN-00
EAN Code	4711475648401	4711475648418
UPC Code	841163098417	841163098424
N.W	10.5 kg / 23.15 lbs.	
G.W	12 kg / 26.46 lbs.	
Carton Size (L x W x H)	729 x 380 x 273 mm / 28.7 x 14.96 x 10.75 inch	
Cuft	2.67	
Container	w/o pallet	
20'	383 pcs	
40'	767 pcs	
40' HQ	863 pcs	

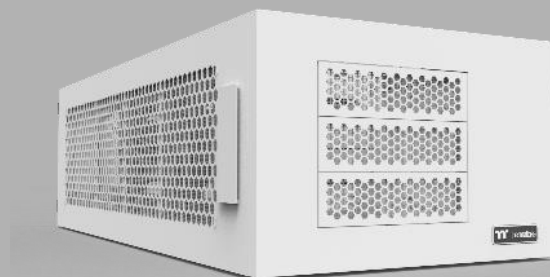

Appearance – AX100




Angle view

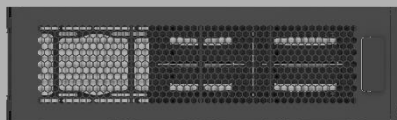

Left Side view



Front view

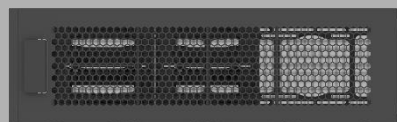


Right Side view




Internal Structure




Internal Structure

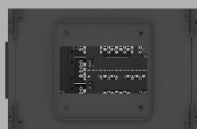

Rear view

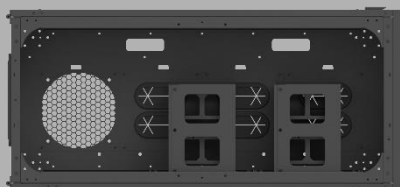


Top view

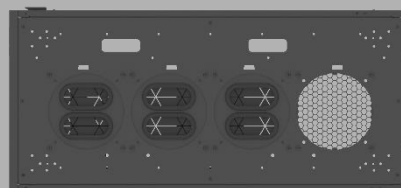


Bottom view


Appearance – AX100 Snow

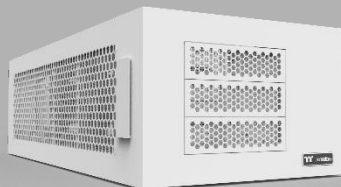


Angle view

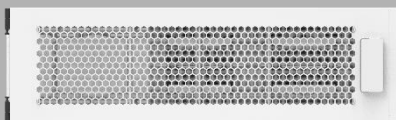


Left Side view

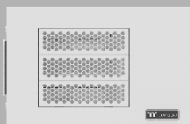

Front view

 


Right Side view

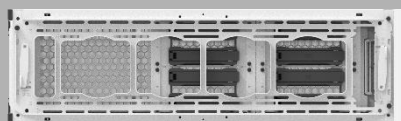


Internal Structure



 
Rear view



Internal Structure


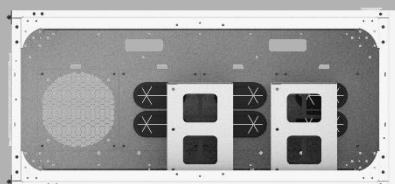


Top view

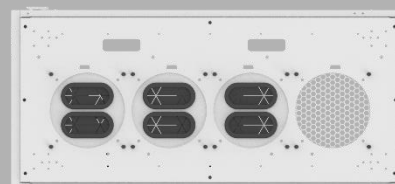


Bottom view

Exploded View

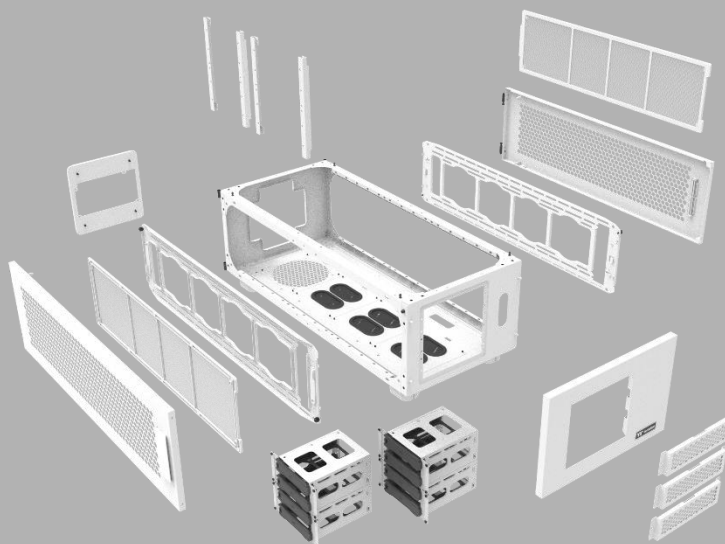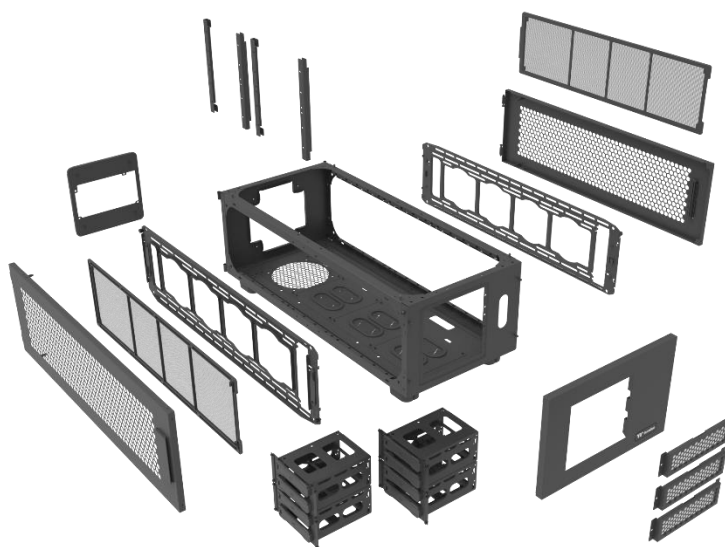



Clearance

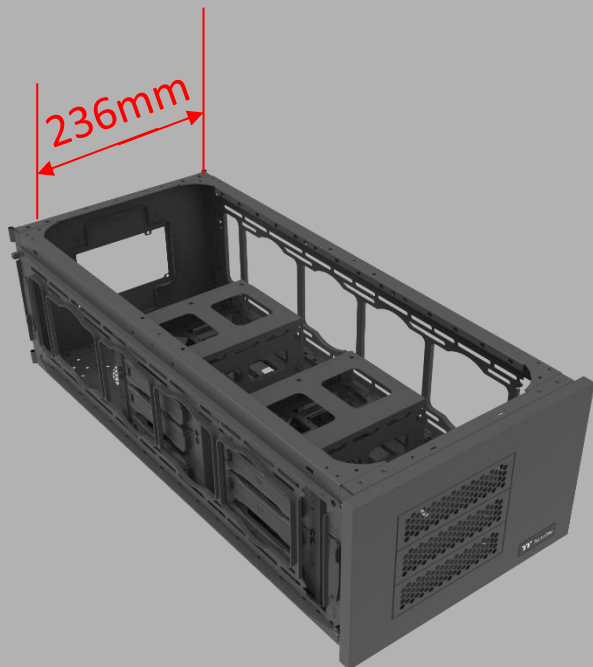

Support up to 8 x 140 mm
Fan / 560 mm Radiator Fan
on the Lateral Sides

(Radiator Clearance w/o PSU : 236 mm)


Structure (Internal)

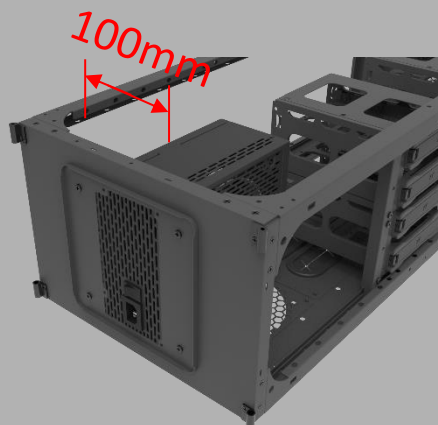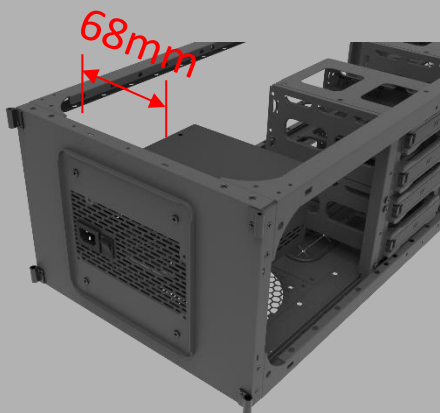

Two-Way PSU Installations


Structure (External)

Hinged Side Panels

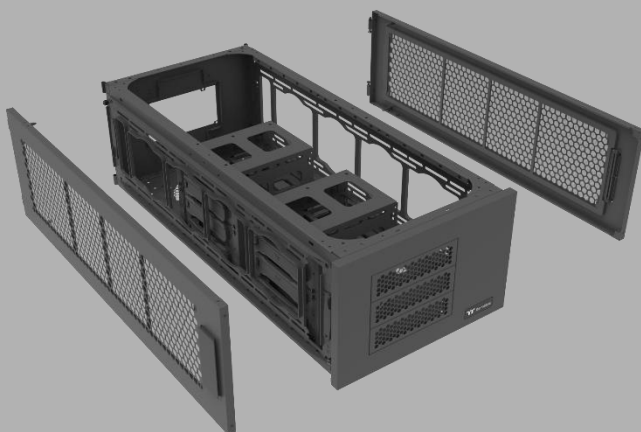

Removable Side Panels


Structure (Internal)

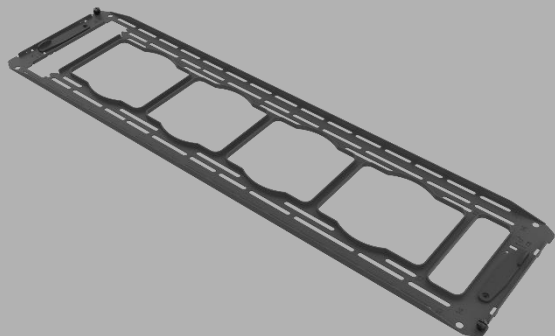


Removable Right & Left
Fan/Radiator Brackets



Tool-Free HDD Trays

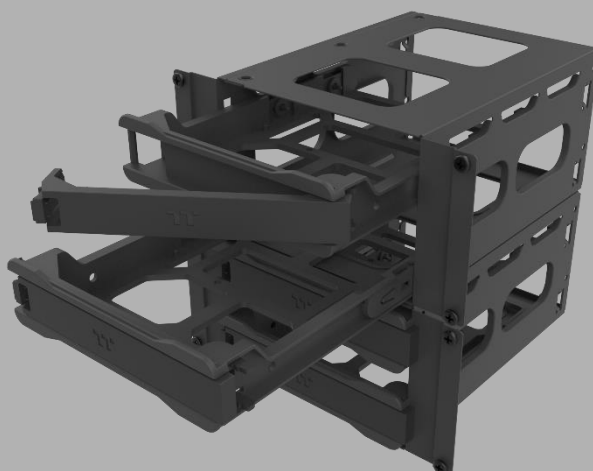


Structure (Internal)

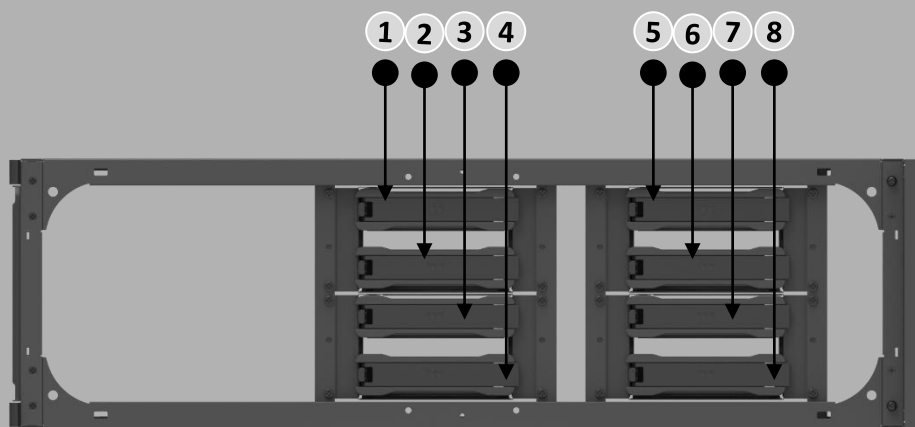

Support up to 8 x 2.5"/3.5" HDD/SSD

Structure (Internal)

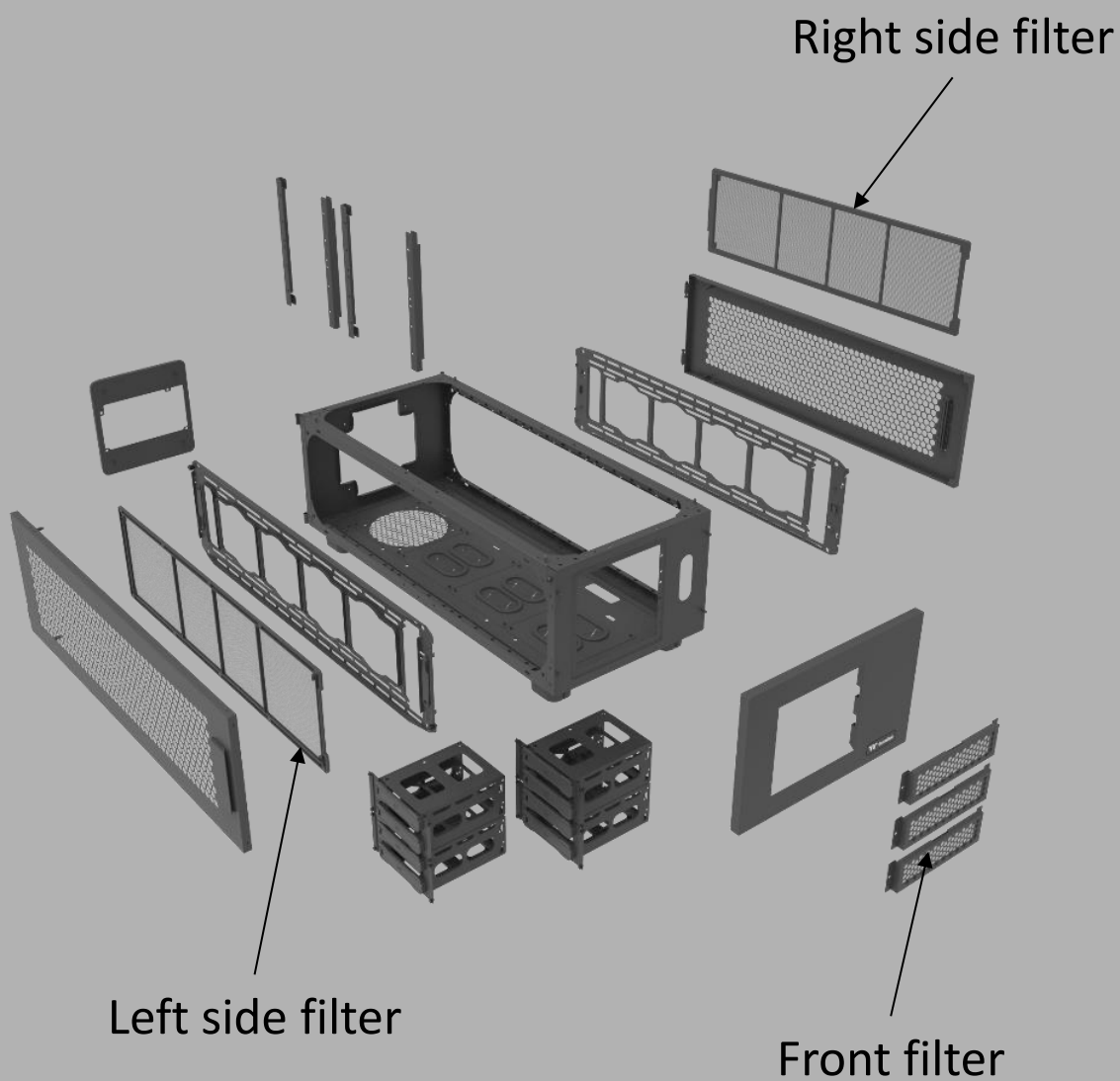

Expansion Assembly




AX700/AX700 TG

AX100

Compatibility List

AX100 Fan Compatibility List			
	120mm	140mm	200mm
Left Side	4	4	-
Right Side	4	4	-

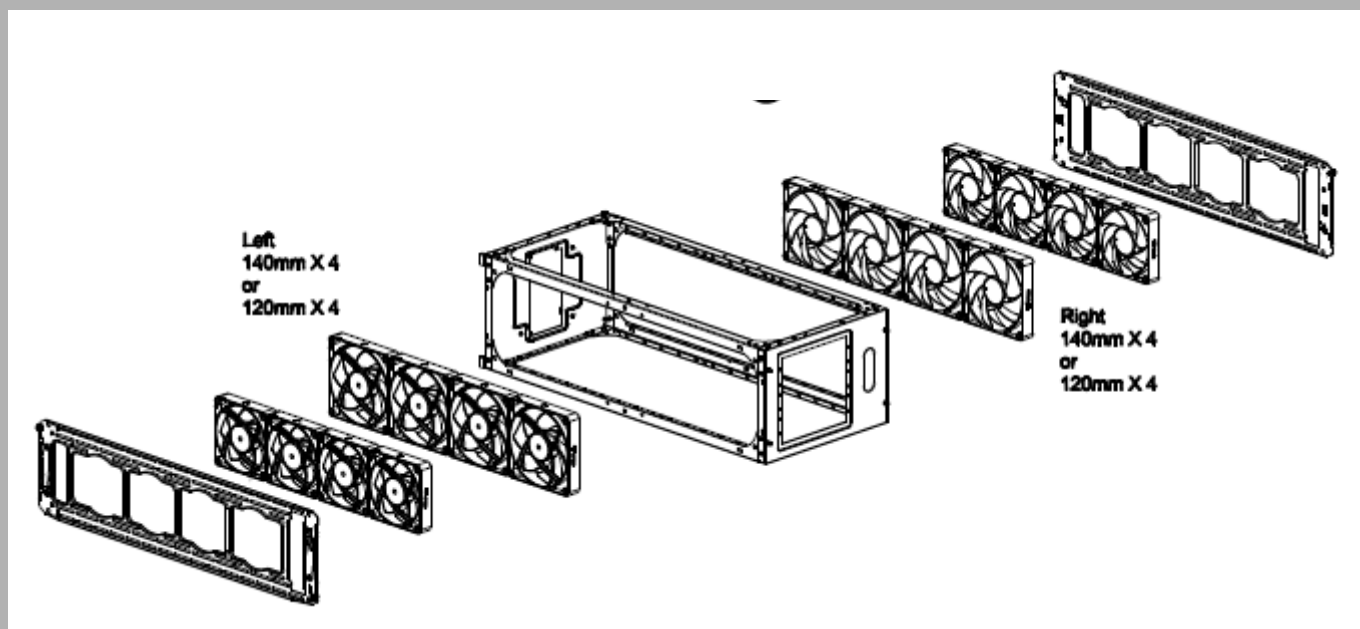

DIY Compatibility

AX100 Radiator Compatibility List

	120mm	240mm	360mm	480mm	140mm	280mm	420mm	560mm
Left	●	●	●	●	●	●	●	●
Right	●	●	●	●	●	●	●	●

