

Pre-Datasheet

- **Style: Simple**
- **Size: Super Tower supports up to XL-ATX MB**
- **Material: Steel Material**

Main Features

- **Connection :** Front I/O ports with 4 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Ventilation:** Supports up to 18 x 120 mm fan
Supports up to 18 x 140 mm fan
- **Support :** Supports AIO/DIY cooling solutions




Specification

Model	AX700	AX700 Snow	AX700 TG	AX700 TG Snow
P/N	CA-11B-00F1NN-00	CA-11B-00F6NN-00	CA-11B-00F1WN-00	CA-11B-00F6WN-00
Color	Black	White	Black	White
Case Type	Super Tower			
Chassis Dimension (H*W*D)	645 x 320 x 685 mm (25.4 x 12.60 x 26.97 inch)		645 x 324.6 x 685 mm (25.4 x 12.78 x 26.97 inch)	
Side Panel	Steel		Steel + TG	
Material	SPCC			
Cooling System	-			
Drive Bays	2 x 5.25'' 12 x 3.5'' or 2.5'' (HDD Cage) 6 x 3.5'' or 2.5'' (Behind the M/B tray)			
Expansion Slots	10			
Motherboards	6.7'' x 6.7'' (Mini ITX), 9.6'' x 9.6'' (Micro ATX), 12'' x 9.6'' (ATX) , 12'' x 13'' (E-ATX) , 13.6'' x 10.4'' (XL-ATX) , SSI-CEB, SSI-EEB			
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 4, HD Audio x 1			
PSU	Standard PS2 PSU (optional)			
Fan Support	Front: 3 x 120mm , 3 x 140mm Top: 4 x 120mm , 4 x 140mm Rear: 1 x 120mm , 1 x 140mm Bottom: 2 x 120mm , 2 x 140mm Right Side: 8 x 120mm , 8 x 140mm			
AIO-Radiator Support	Front: 1 x 360mm (MAX), 1 x 420mm (MAX) Top: 1 x 360mm (MAX), 1 x 420mm (MAX) Rear: 1 x 120mm , 1 x 140mm			
DIY-Radiator Support	Front: 1 x 360mm (MAX), 1 x 420mm (MAX) Top: 1 x 480mm (MAX), 1 x 560mm (MAX) Rear: 1 x 120mm , 1 x 140mm			
Clearance	CPU cooler height limitation: 190mm VGA length limitation: 360mm(with HDD rack) 630mm(without HDD rack) PSU length limitation: 220mm (with two bottom fans)			

Packaging

Package Information	AX700	AX700 snow
P/N	CA-11B-00F1NN-00	CA-11B-00F6NN-00
EAN Code	4711475647565	4711475647572
UPC Code	841163097571	841163097588
N.W	10.5 kg / 23.15 lbs.	
G.W	12 kg / 26.46 lbs.	
Carton Size (L x W x H)	785 x 426 x 768 mm / 30.91 x 16.77 x 30.24 inch	
Cuft	9.07	
Container	w/o pallet	
20'	104 pcs	
40'	224 pcs	
40' HQ	224 pcs	
40' HQ	AX700/AX700 TG *224pcs +AX100 * 92pcs	

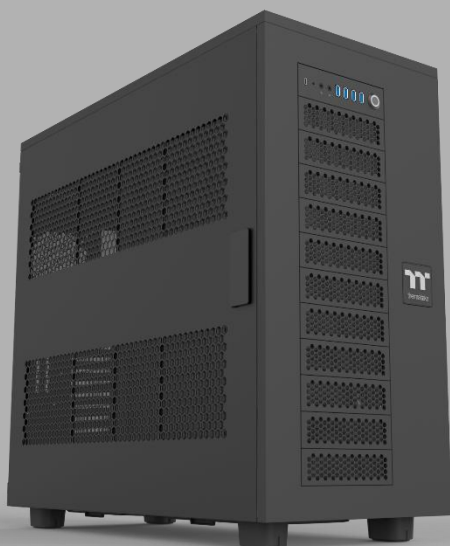

Packaging


Package Information	AX700 TG	AX700 TG Snow
P/N	CA-11B-00F1WN-00	CA-11B-00F6WN-00
EAN Code	4711475648388	4711475648395
UPC Code	841163098394	841163098400
N.W	10.5 kg / 23.15 lbs.	
G.W	12 kg / 26.46 lbs.	
Carton Size (L x W x H)	785 x 426 x 768 mm / 30.91 x 16.77 x 30.24 inch	
Cuft	9.07	
Container	w/o pallet	
20'	104 pcs	
40'	224 pcs	
40' HQ	224 pcs	
40' HQ	AX700/AX700 TG *224pcs +AX100 * 92pcs	




Appearance – AX700




Angle view

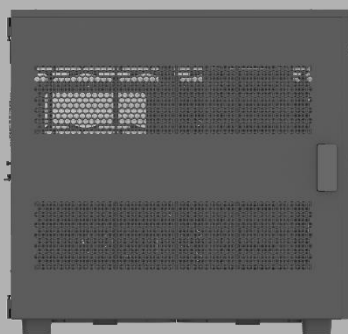

Left Side view

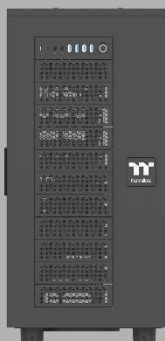


Front view

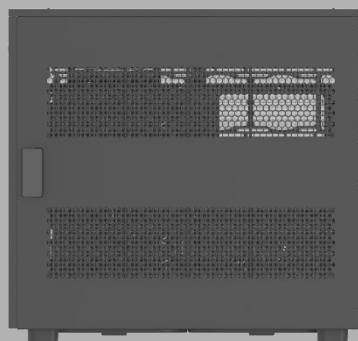


Right Side view




Internal Structure

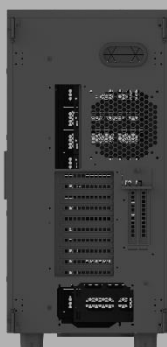


Rear view

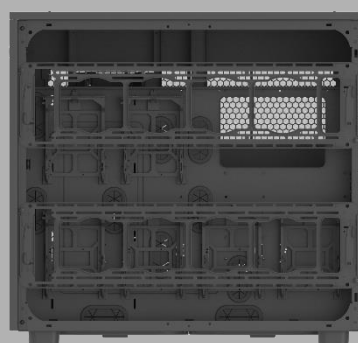

Internal Structure

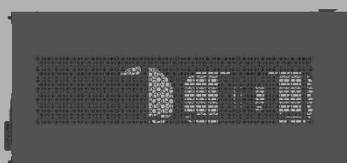

Top view

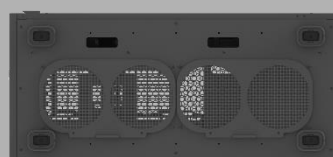


Bottom view


Appearance – AX700 Snow




Angle view

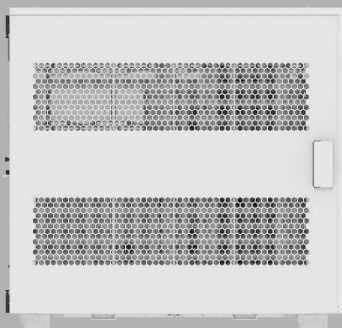


Left Side view

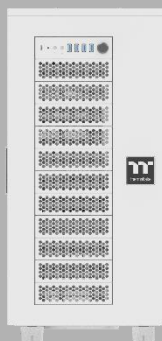


Front view

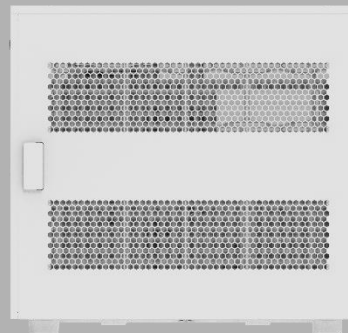


Right Side view

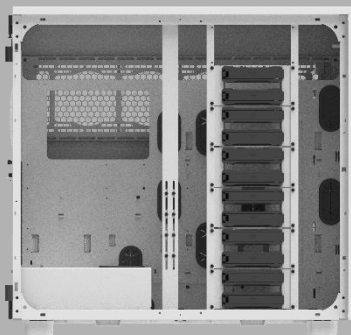


Internal Structure

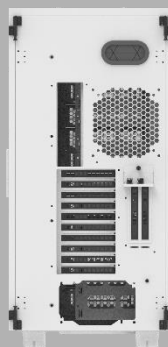

Rear view

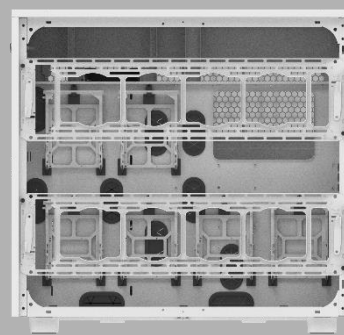

Internal Structure

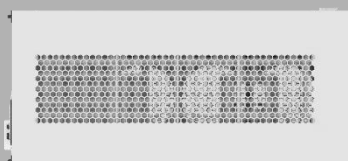

Top view




Bottom view


Appearance – AX700 TG




Angle view

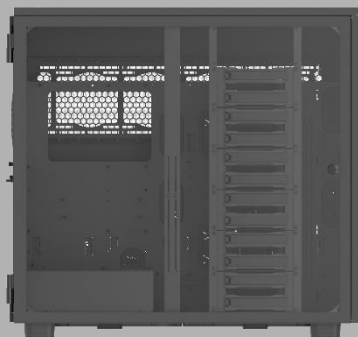

Left Side view

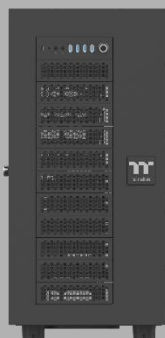

Front view

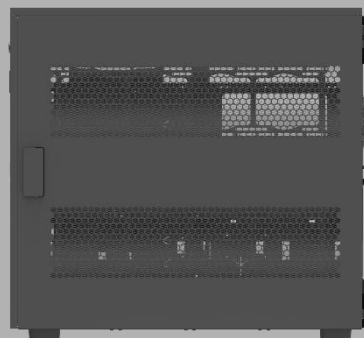


Right Side view



Internal Structure




Rear view

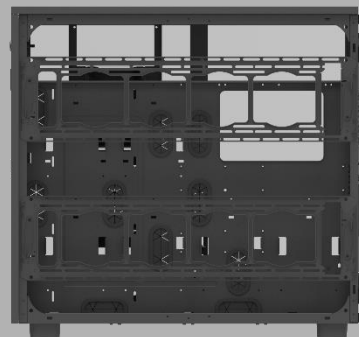

Internal Structure



Top view

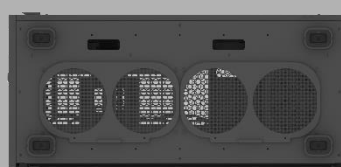


Bottom view


Appearance – AX700 TG Snow




Angle view

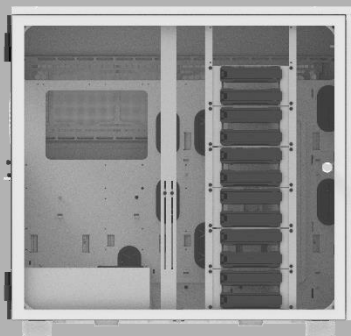


Left Side view

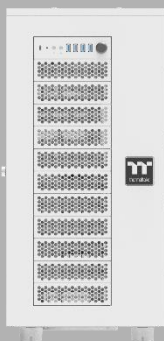


Front view

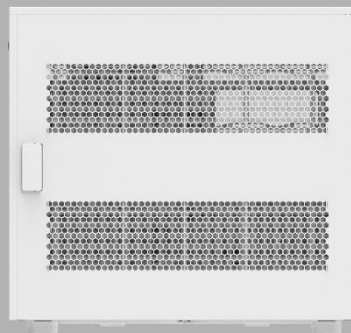


Right Side view

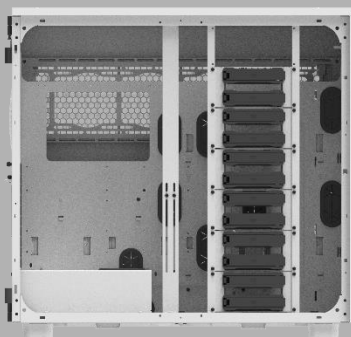


Internal Structure

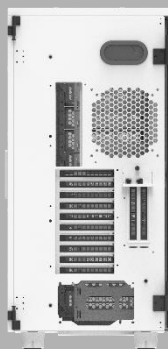


Rear view

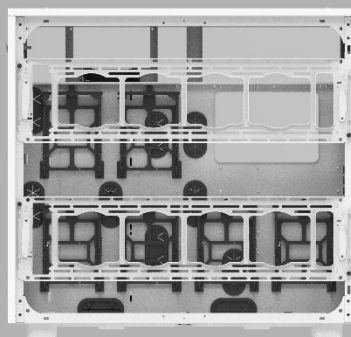

Internal Structure


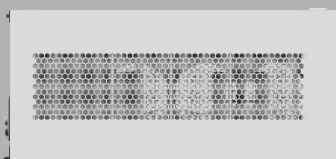


Top view


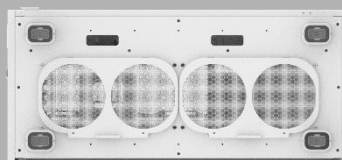


Bottom view


Exploded View

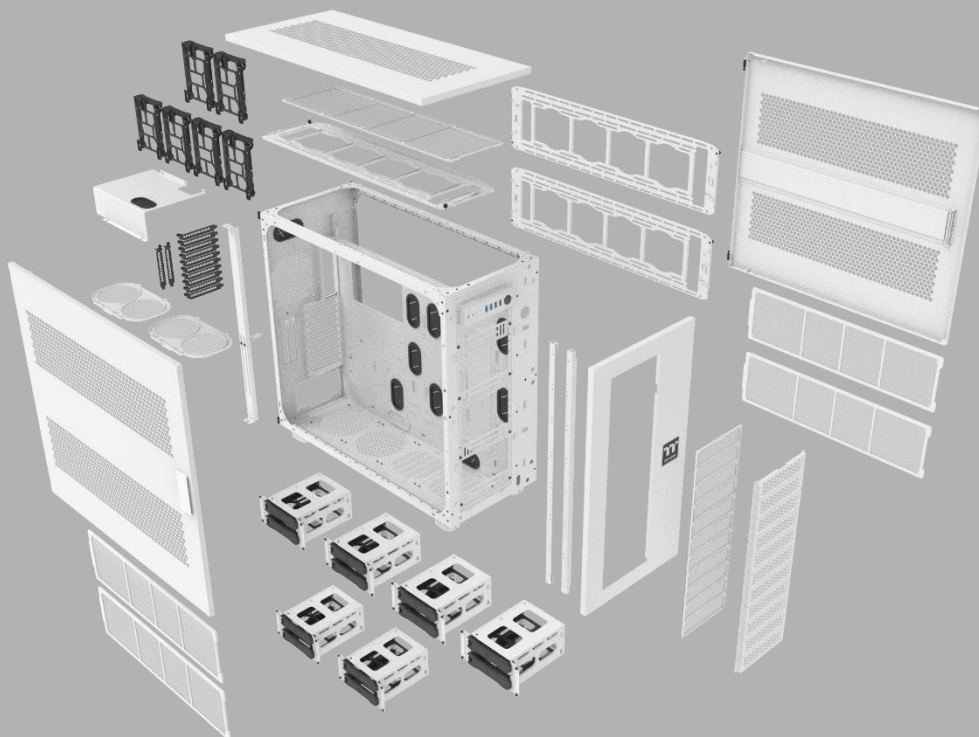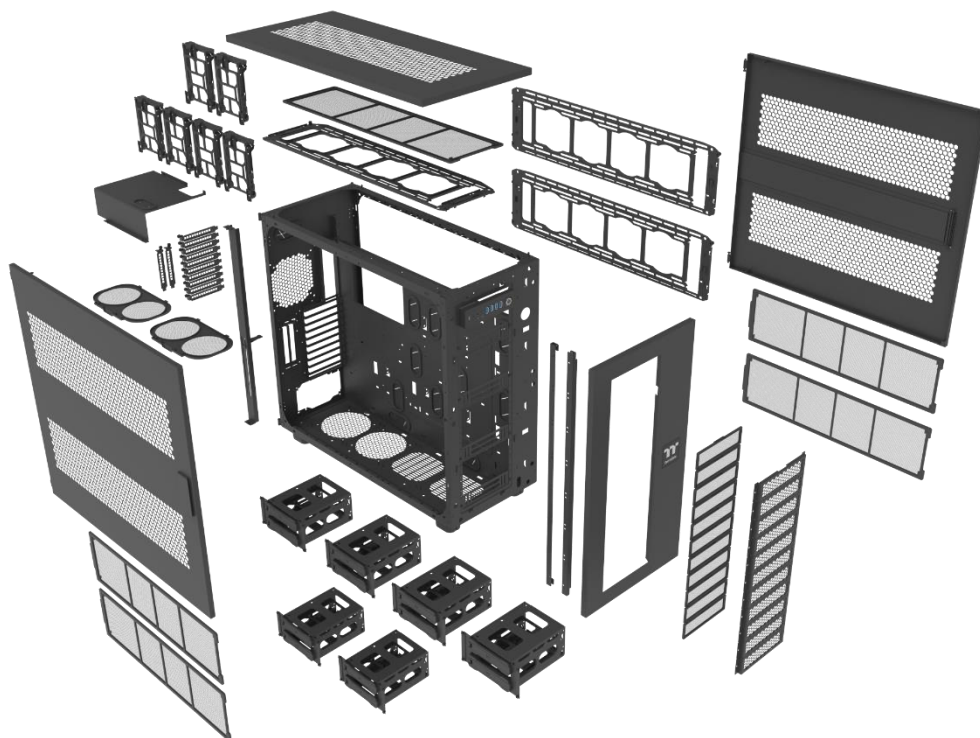


Exploded View

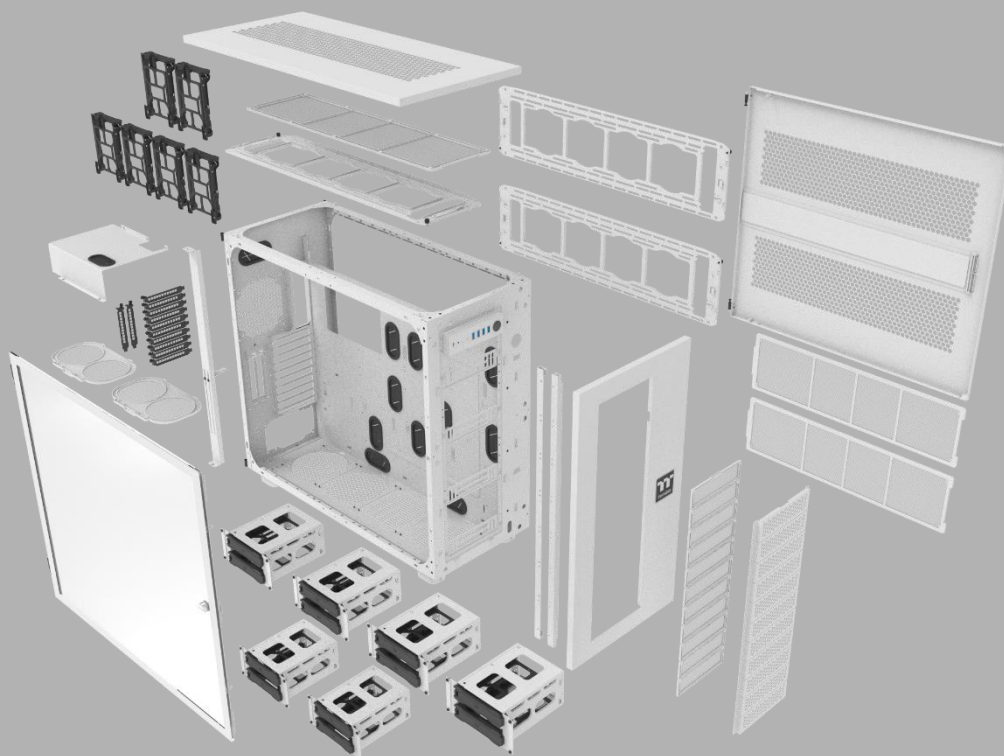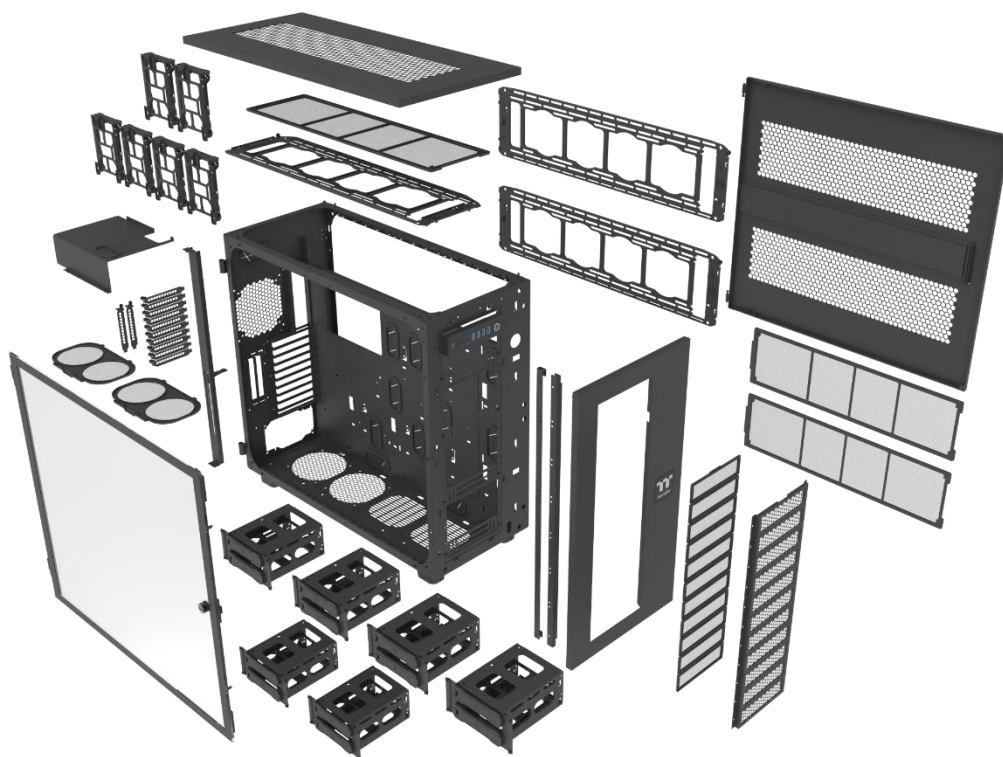

Clearance

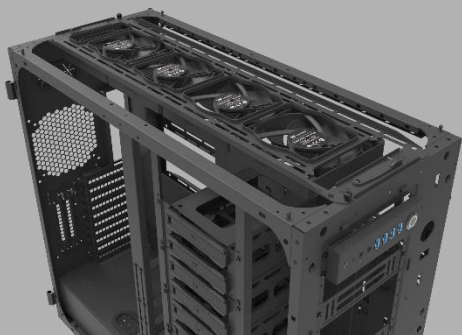

Support up to 4 x 140 mm
Fan on the Top

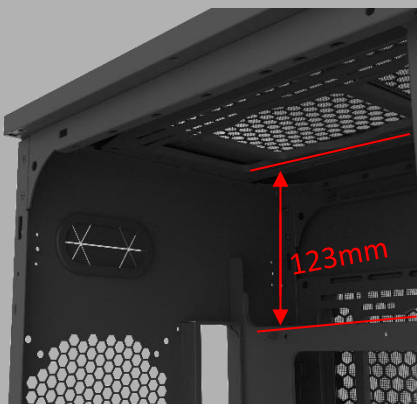

Support up to 560 mm
Radiator on the Top

(Clearance for Radiator + Fan:
123mm)

10 x PCI-e Slot Support
Multiple Graphic Cards



Structure (External)



1 x USB 3.2 (Gen 2) Type-C

4 x USB 3.0

HD Audio

**4mm Tempered Glass Left
Panel**

(AX700 TG/AX700 TG Snow)



Heightened Foot Stand



Built-In Wheels

Structure (External)

Hinged Side Panels



Removable Side Panels


VGA Holder



Built-In VGA Holder

Structure (Internal)


Removable Power Cover

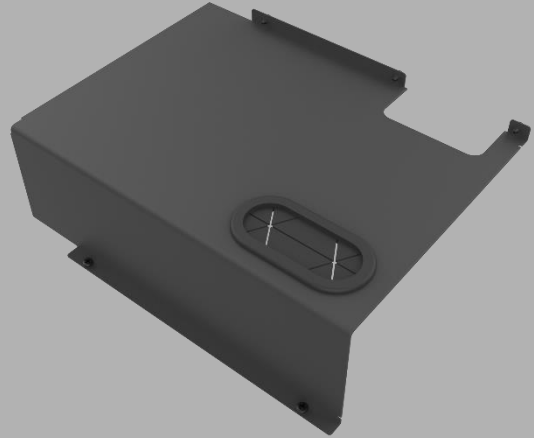

Removable 5.25" ODD bracket




Structure (Internal)

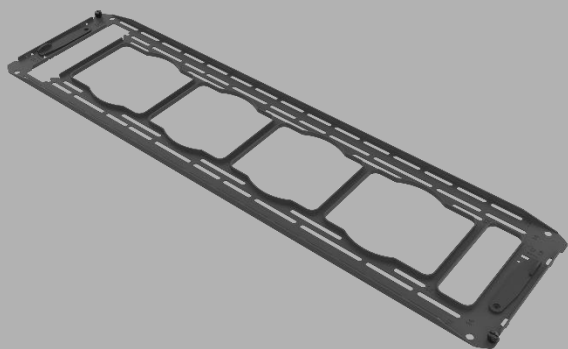



Removable Top & Right
Fan/Radiator Brackets



Tool-Free HDD Trays

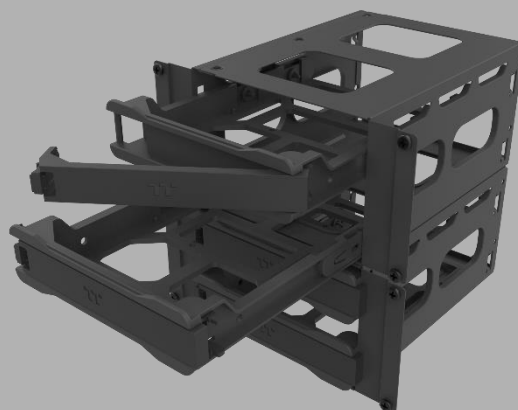


Structure (Internal)

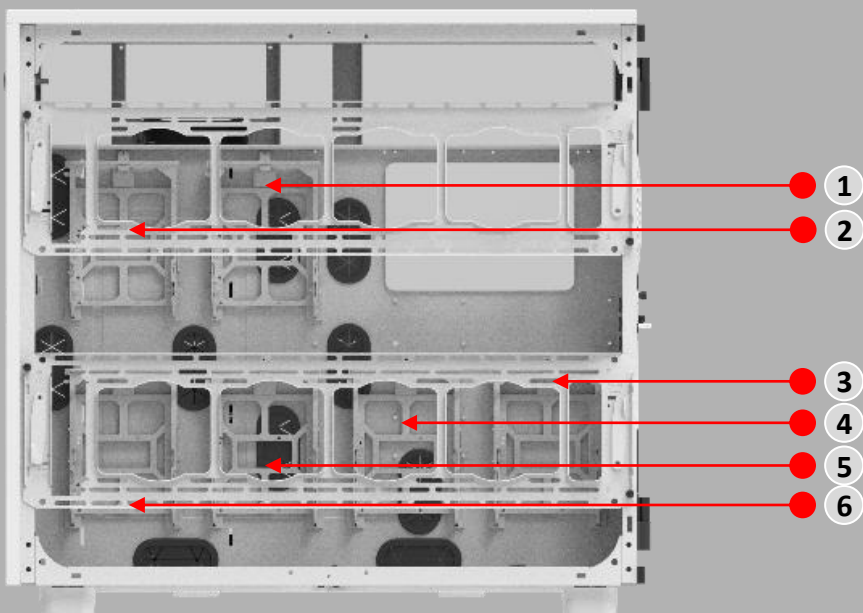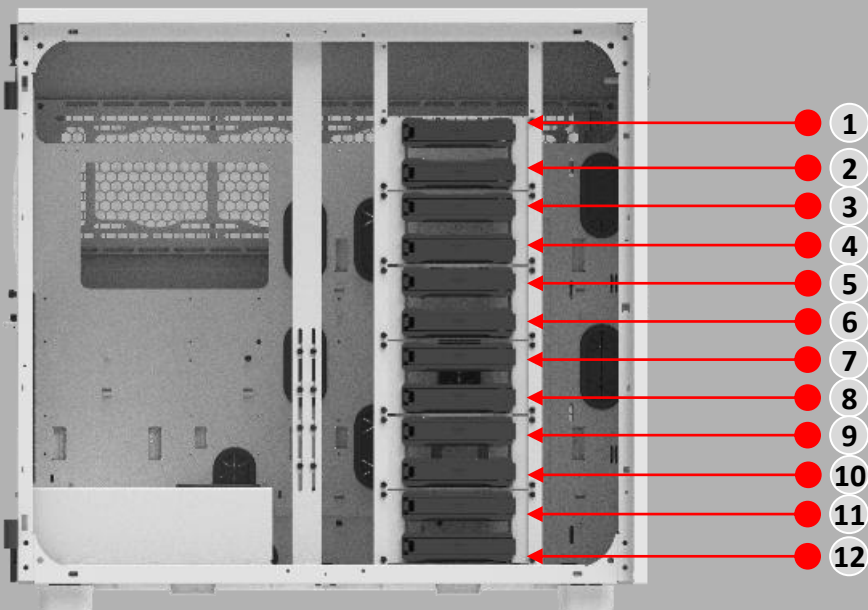

Support up to 18 x 2.5"/3.5" HDD/SSD


Structure (Internal)

AX700

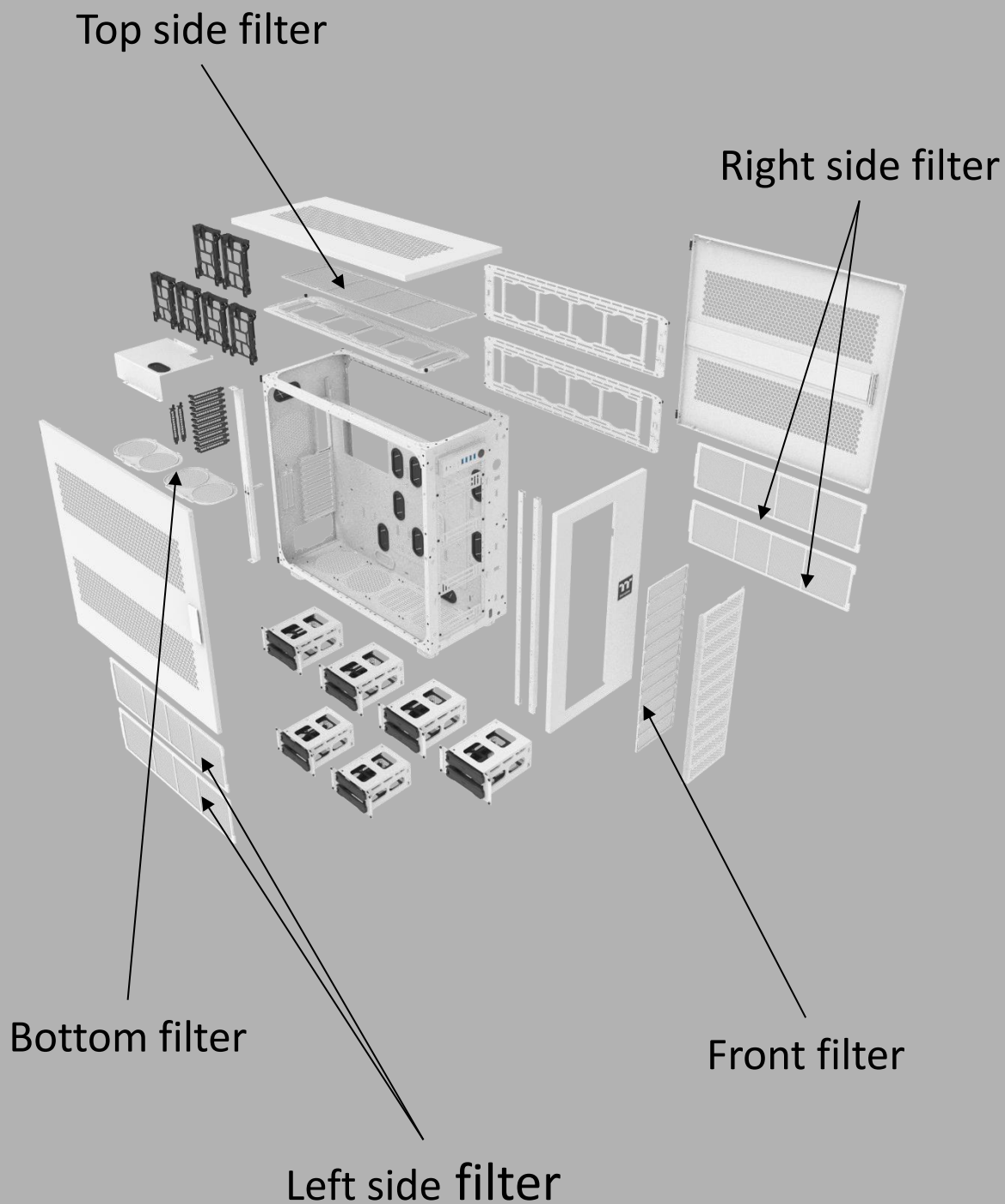

Structure (Internal)

AX700 TG

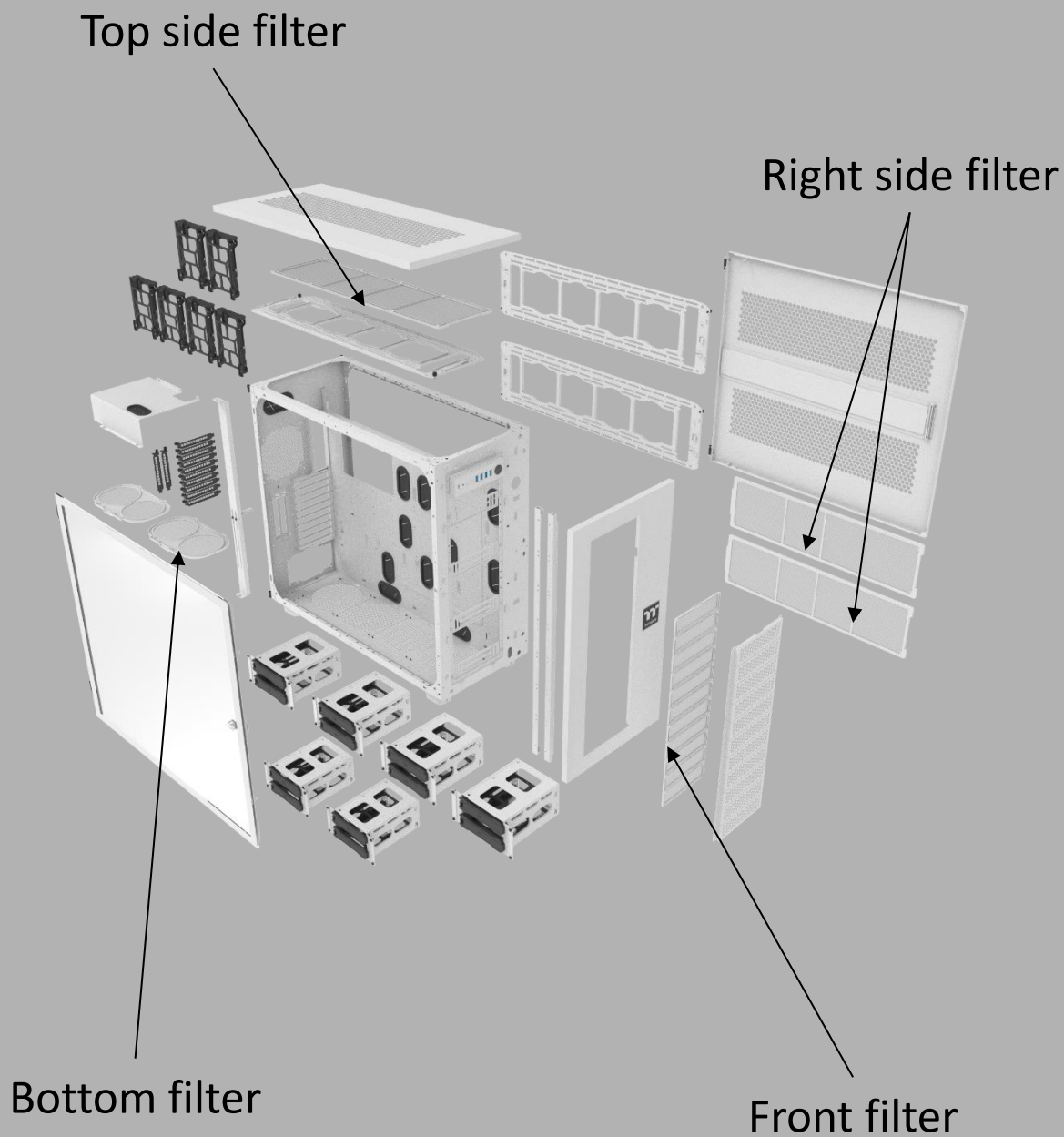

Expansion Assembly




AX700/AX700 TG

AX100

Compatibility List

AX700/AX700 TG Fan Compatibility List


	120mm	140mm
Front	3	3
Top	4	4
Rear	1	1
Bottom	2	2
Right Side	8	8

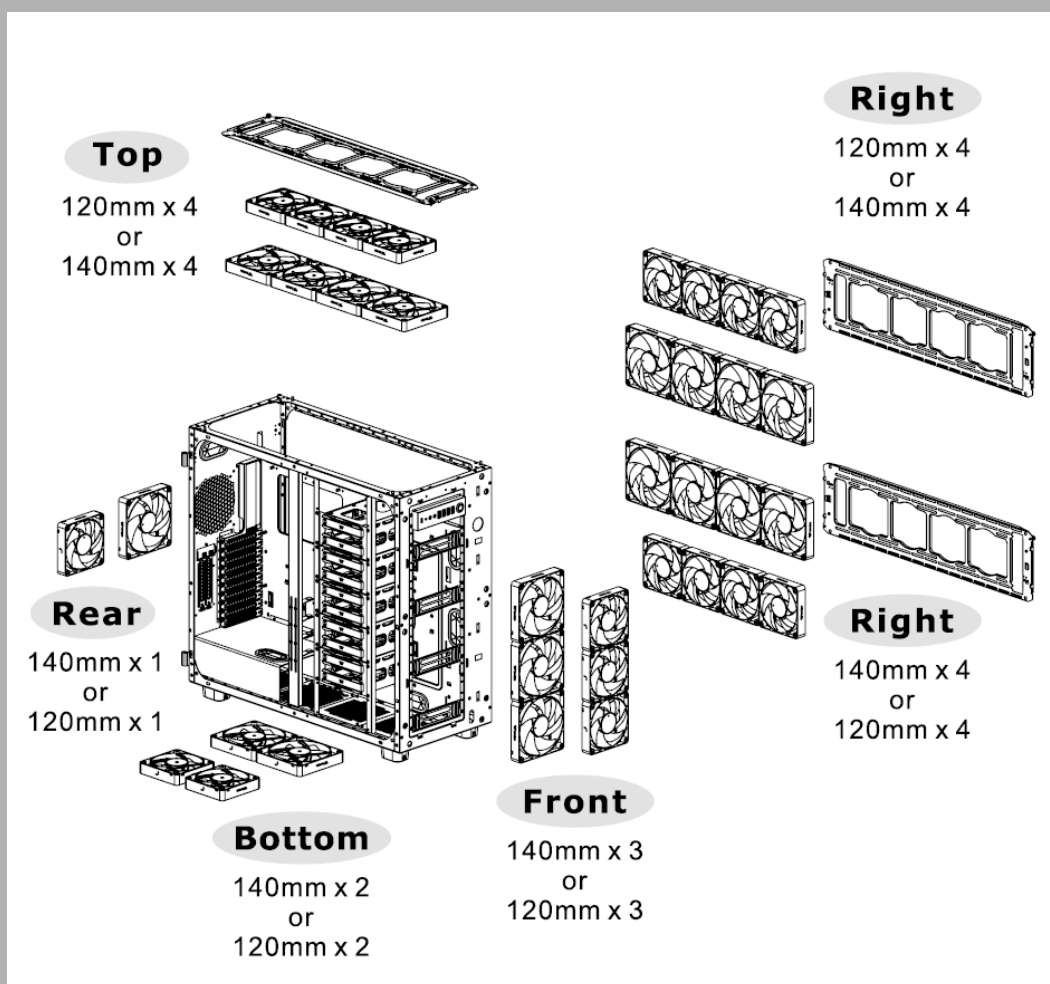

All-in-One Compatibility

AX700/AX700 TG All-in-One Radiator Compatibility List

	120mm	240mm	360mm	480mm	140mm	280mm	420mm	560mm
Front	●	●	●	-	●	●	●	-
Top	●	●	●	-	●	●	●	-
Rear	●	-	-	-	●	-	-	-

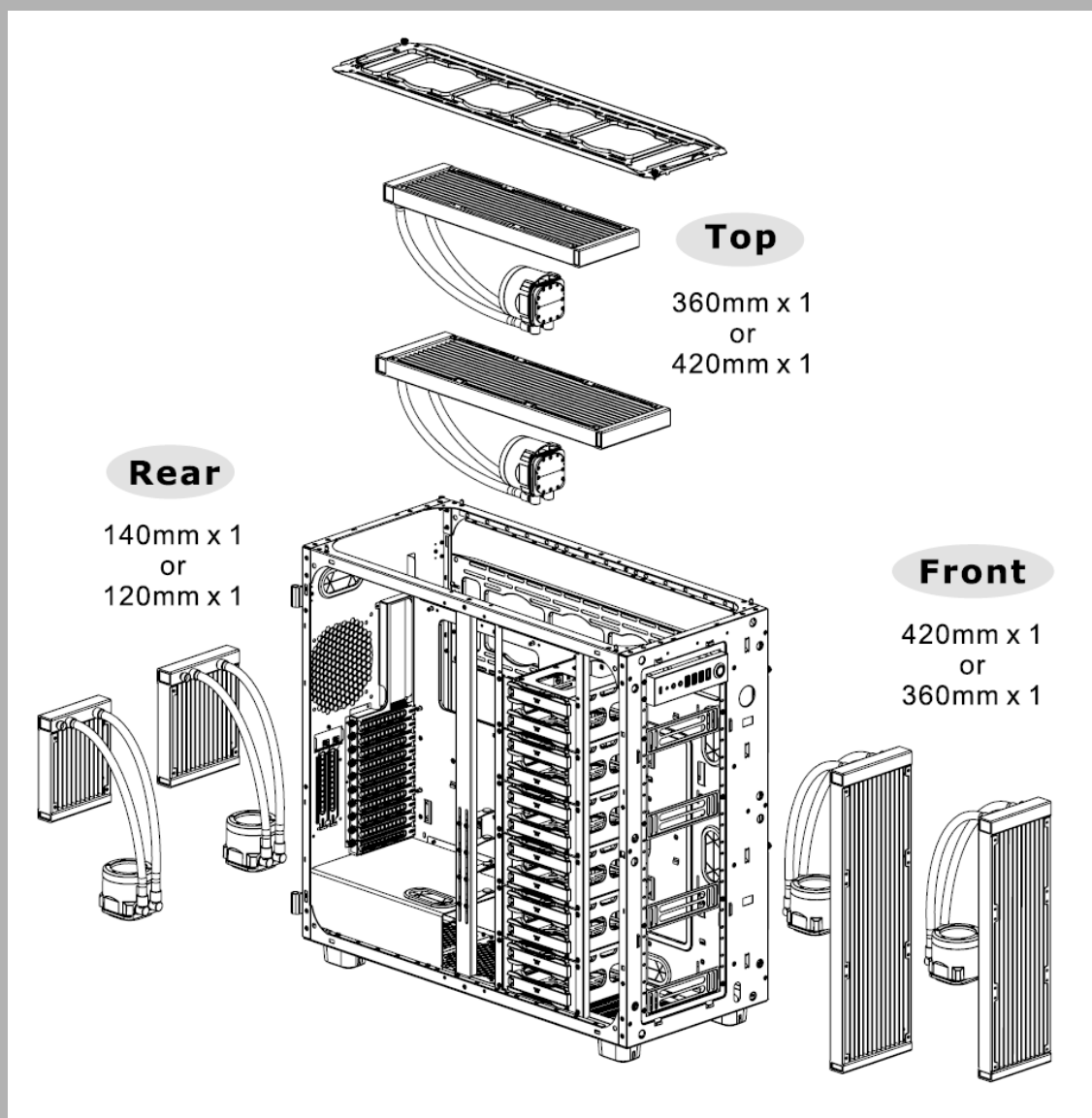

DIY Compatibility

AX700/AX700 TG DIY Radiator Compatibility List

	120mm	240mm	360mm	480mm	140mm	280mm	420mm	560mm
Front	●	●	●	-	●	●	●	-
Top	●	●	●	●	●	●	●	●
Rear	●	-	-	-	●	-	-	-

