

LA240 360 ARGB Sync

P/N: CL-W457-PL12SW-A
CL-W459-PL12SW-A

LA240 & 360

ARGB Sync

Release the full CPU Horsepower



TT thermalright

*Requires motherboard sync for ARGB lighting effect

LA240 ARGB Sync

•Specification

LA240 ARGB Sync

Product	P/N	CL-W457-PL12SW-A
Compatibility	CPU Socket	Intel LGA 2066/2011-3/2011/1851/1700/ 1200/1156/1155/1151/1150 AMD AM5/AM4/AM3+/AM3
Water Block	Material	Copper
Pump	Motor Speed	PWM 1500~2500 RPM
	Rated Voltage	12 V / 5 V
	Rated Current	0.35A / 0.3 A
	Power Input	4.2W / 1.44 W
	Connector	2510 – 4 Pin / ARGB – 3Pin
Fan	Dimension	120 x 120 x 25 mm
	Fan Speed	PWM 600~2500 R.P.M
	Rated Voltage	12 V/ 5 V
	Rated Current	0.38 A & 0.28 A (one fan)
	Power Input	4.56 W & 1.4 W (one fan)
	Air Flow.	79.3 CFM (one fan)
	Static Pressure.	3.45 mm-H2O (one fan)
	Noise Level.	38.35 dB-A (one fan)
	Connector	2510 – 4 Pin
Radiator	Dimension	277 x 120 x 27 mm
	Material	Aluminum
Tube	Length	350mm
	Material	Rubber
TDP		350W

***Requires motherboard sync for ARGB lighting effect**

•Specification

LA360 ARGB Sync

Product	P/N	CL-W459-PL12SW-A
Compatibility	CPU Socket	Intel LGA 2066/2011-3/2011/1851/1700/ 1200/1156/1155/1151/1150 AMD AM5/AM4/AM3+/AM3
Water Block	Material	Copper
Pump	Motor Speed	PWM 1500~2500 RPM
	Rated Voltage	12 V / 5 V
	Rated Current	0.35A / 0.3 A
	Power Input	4.2W / 1.44 W
	Connector	2510 – 4 Pin / ARGB – 3Pin
Fan	Dimension	120 x 120 x 25 mm
	Fan Speed	PWM 600~2500 R.P.M
	Rated Voltage	12 V/ 5 V
	Rated Current	0.38 A & 0.28 A (one fan)
	Power Input	4.56 W & 1.4 W (one fan)
	Air Flow.	79.3 CFM (one fan)
	Static Pressure.	3.45 mm-H ₂ O (one fan)
	Noise Level.	38.35 dB-A (one fan)
	Connector	2510 – 4 Pin
Radiator	Dimension	397 x 120 x 27 mm
	Material	Aluminum
Tube	Length	350mm
	Material	Rubber
TDP		360W

***Requires motherboard sync for ARGB lighting effect**

LA240 ARGB Sync


• Detailed Features :

- RGB Gaming-Style Waterblock
- Daisy-chain Design with better cable management
- Features a Large Copper Base
- Pre-installed high-performance ARGB fans
- Unique Magnetic Top Cover Design


• Appearance




High Performance ARGB fans

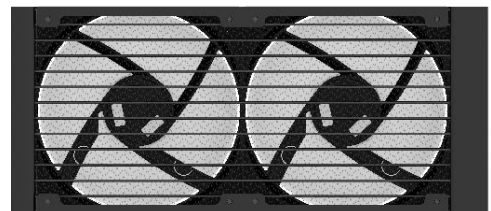

High Efficiency Radiator

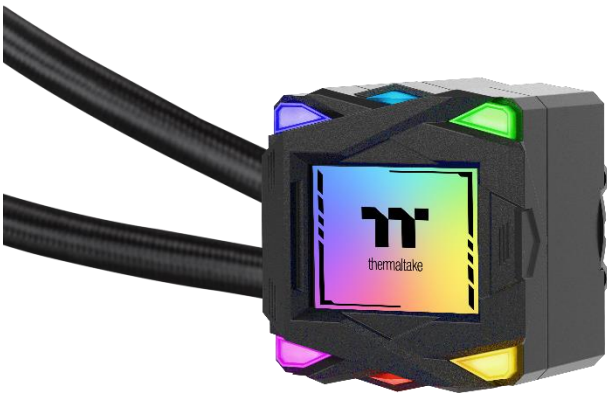

RGB Gaming-Style Waterblock

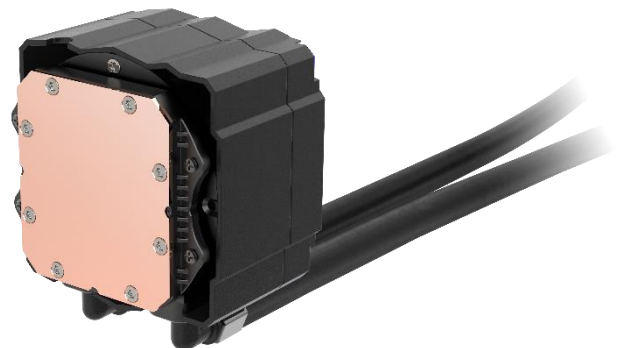

Larger Copper Base

LA360 ARGB Sync


• Detailed Features :

- RGB Gaming-Style Waterblock
- Daisy-chain Design with better cable management
- Features a Large Copper Base
- Pre-installed high-performance ARGB fans
- Unique Magnetic Top Cover Design


• Appearance




High Performance ARGB fans

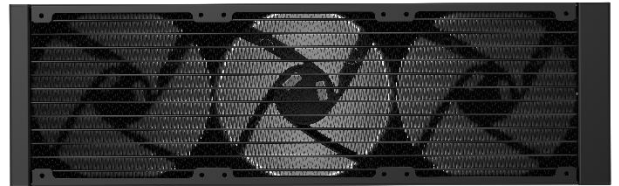

High Efficiency Radiator

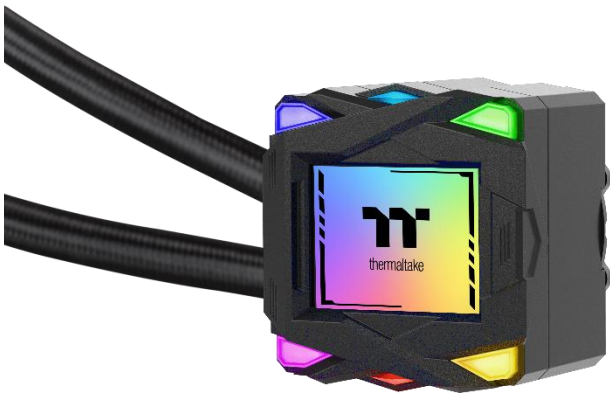

RGB Gaming-Style Waterblock

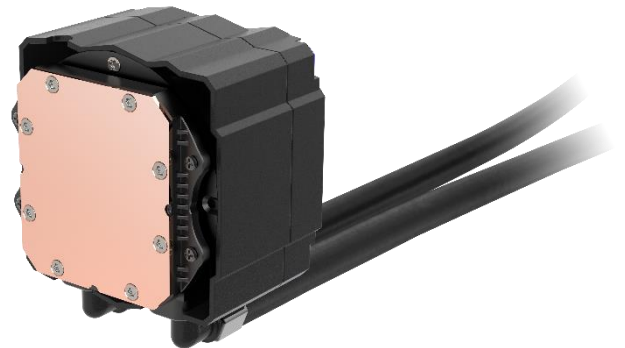


Larger Copper Base

LA240 ARGB Sync

• Appearance



Application

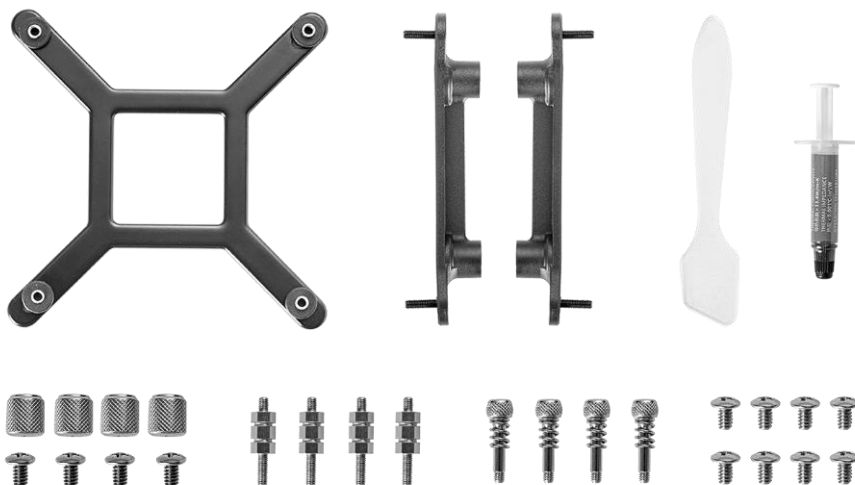

Universal Socket Compatible


Support LGA1851

LA360 ARGB Sync

• Appearance



Application

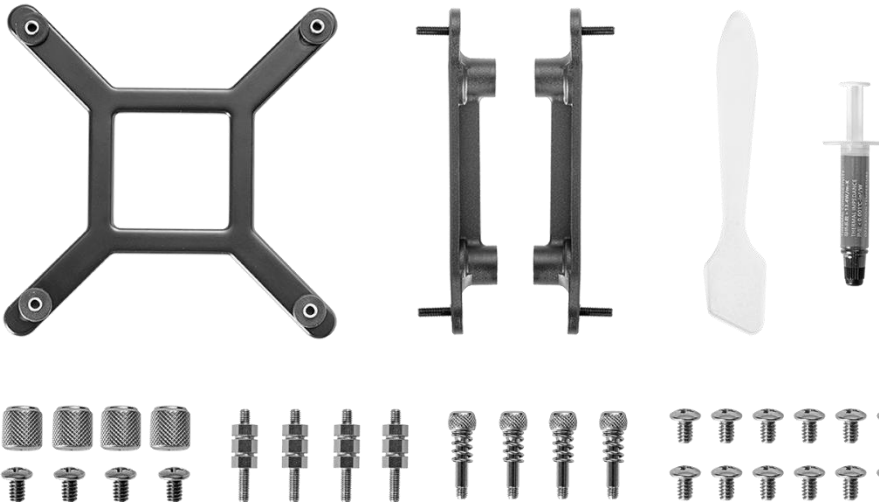

Universal Socket Compatible

Support LGA1851

LA240 360 ARGB Sync

P/N: CL-W457-PL12SW-A
CL-W459-PL12SW-A

LA240 & 360

ARGB Sync

Release the full CPU Horsepower



TT thermalright

*Requires motherboard sync for ARGB lighting effect