

LA240-S 360-S ARGB Sync

P/N: CL-W461-PL12SW-A
CL-W462-PL12SW-A

LA240-S & 360-S

ARGB Sync

Release the full CPU Horsepower



TT thermaltake

*Requires motherboard sync for ARGB lighting effect

LA240-S ARGB Sync

•Specification

LA240-S ARGB Sync

Compatibility	CPU Socket	Intel LGA 2066/2011-3/2011/1851/1700/ 1200/1156/1155/1151/1150 AMD AM5/AM4/AM3+/AM3/
Water Block	Material	Copper
Pump	Motor Speed	PWM 1500~2500 RPM
	Rated Voltage	12 V / 5 V
	Rated Current	0.35A / 0.3 A
	Power Input	4.2W / 1.44 W
	Connector	2510 – 4 Pin / ARGB – 3Pin
CPU Display	Rated Voltage	5 V
	Rated Current	0.1 A
	Power Input	0.5 W
	Display Type	2.4 inch " Segment code LCD
	Display Resolution	240 x 320 (RGB)
Software Support	Interface	USB 2.0 (9PIN)
	System Compatibility	Windows 10 / 11
Fan	Dimension	120 x 120 x 25 mm
	Fan Speed	PWM 600~2500 R.P.M
	Rated Voltage	12 V & 5 V
	Rated Current	0.38 A & 0.28 A (one fan)
	Power Input	4.56 W & 1.4 W (one fan)
	Air Flow.	79.3 CFM (one fan)
	Static Pressure.	3.45 mm-H2O (one fan)
	Noise Level.	38.35 dB-A (one fan)
	Connector	2510 – 4 Pin
Radiator	Dimension	277x 120 x 27 mm
	Material	Aluminum
Tube	Length	350mm
	Material	Rubber
TDP		350W

*Requires motherboard sync for ARGB lighting effect

•Specification

LA360-S ARGB Sync

Compatibility	CPU Socket	Intel LGA 2066/2011-3/2011/1851/1700/ 1200/1156/1155/1151/1150 AMD AM5/AM4/AM3+/AM3/
Water Block	Material	Copper
Pump	Motor Speed	PWM 1500~2500 RPM
	Rated Voltage	12 V / 5 V
	Rated Current	0.35A / 0.3 A
	Power Input	4.2W / 1.44 W
	Connector	2510 – 4 Pin / ARGB – 3Pin
CPU Display	Rated Voltage	5 V
	Rated Current	0.1 A
	Power Input	0.5 W
	Display Type	2.4 inch " Segment code LCD
	Display Resolution	240 x 320 (RGB)
Software Support	Interface	USB 2.0 (9PIN)
	System Compatibility	Windows 10 / 11
Fan	Dimension	120 x 120 x 25 mm
	Fan Speed	PWM 600~2500 R.P.M
	Rated Voltage	12 V & 5 V
	Rated Current	0.38 A & 0.28 A (one fan)
	Power Input	4.56 W & 1.4 W (one fan)
	Air Flow.	79.3 CFM (one fan)
	Static Pressure.	3.45 mm-H ₂ O (one fan)
	Noise Level.	38.35 dB-A (one fan)
	Connector	2510 – 4 Pin
Radiator	Dimension	397x 120 x 27 mm
	Material	Aluminum
Tube	Length	350mm
	Material	Rubber
TDP		360W

*Requires motherboard sync for ARGB lighting effect

LA240-S ARGB Sync


• Detailed Features :

- 2.4" Square Digital Display with Real-Time System Monitoring
- Daisy-chain Design with better cable management
- Features a Large Copper Base
- Pre-installed high-performance ARGB fans
- Unique Magnetic Top Cover Design

• Appearance




High Performance ARGB fans

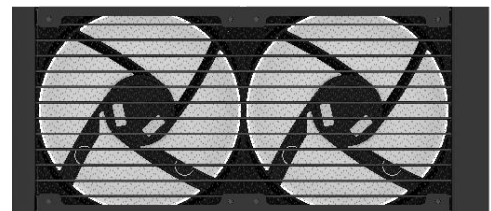

High Efficiency Radiator



Segment code LCD
Real time system information

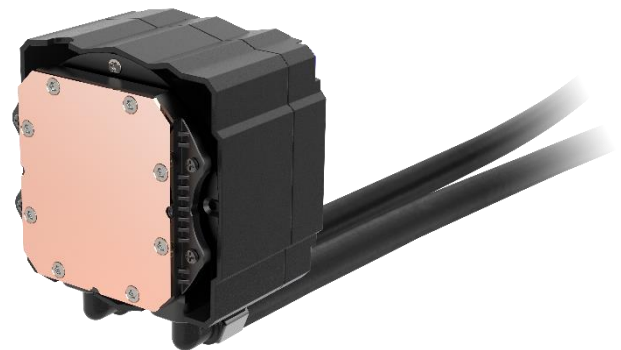

Larger Copper Base

LA360-S ARGB Sync


• Detailed Features :

- 2.4" Square Digital Display with Real-Time System Monitoring
- Daisy-chain Design with better cable management
- Features a Large Copper Base
- Pre-installed high-performance ARGB fans
- Unique Magnetic Top Cover Design

• Appearance




High Performance ARGB fans

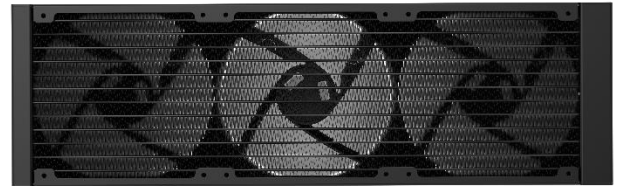

High Efficiency Radiator



Segment code LCD
Real time system information

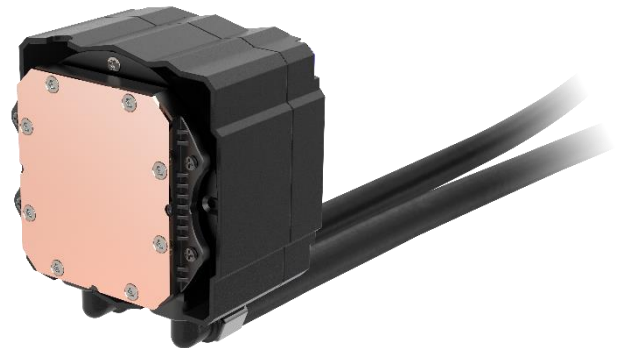


Larger Copper Base

LA240-S ARGB Sync

• Appearance



Application

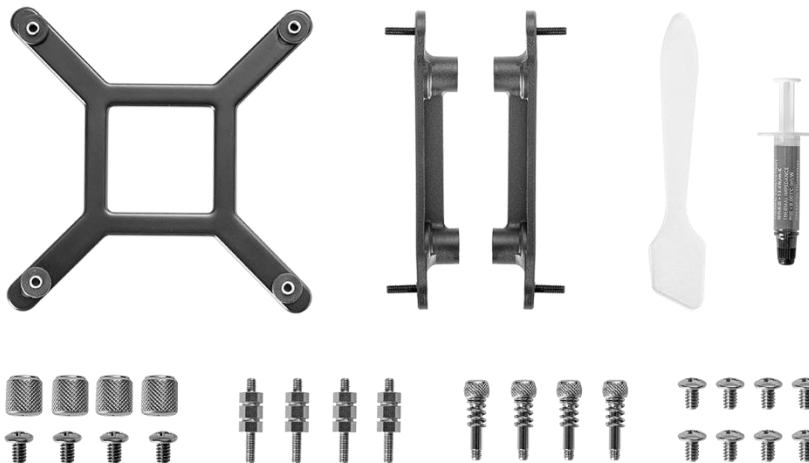

Universal Socket Compatible

Support LGA1851

- Appearance



Support LGA1851

LA240-S 360-S ARGB Sync

P/N: CL-W461-PL12SW-A
CL-W462-PL12SW-A

LA240-S & 360-S

ARGB Sync

Release the full CPU Horsepower



TT thermaltake

*Requires motherboard sync for ARGB lighting effect