

- **Style: Simple**
- **Size: Mini Case supports up to Mini ITX MB**
- **Material: Steel Material**

Main Features

- **Connection:** Front I/O ports with 2 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Ventilation:** Supports 2 x 120/140mm fan (Non- Preinstalled)
- **Support:** 280mm AIO cooling solutions & 3.9" LCD Screen Kit (AC-073-001NAN-A1)



Specification

Model	TR100	TR100 Snow	TR100 Matcha Green	TR100 Hydrangea Blue
P/N	CA-11A-00S1NN-00	CA-11A-00S6NN-00	CA-11A-00SENN-00	CA-11A-00SFNN-00
Color	Black	White	Matcha Green	Hydrangea Blue
Case Type	Mini Case			
Chassis Dimension (H*W*D)	294 x 179 x 391 mm (11.58 x 7.05 x 15.39inch)			
Side Panel	Steel			
Material	SPCC			
Cooling System	-			
Drive Bays	2 x 2.5" or 1 x 2.5"			
Expansion Slots	3			
Motherboards	6.7" x 6.7" (Mini ITX)			
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 2, HD Audio x 1			
PSU	SFX / SFX-L (optional)			
Fan Support	Top: 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm			
Radiator Support	Top Side(AIO): 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm			
Clearance	CPU cooler height limitation: 68mm VGA length limitation: 360mm VGA Width limitation: 70mm PSU length limitation: 130mm			

Packaging

Package Information	TR100	TR100 Snow
EAN Code	4711475648340	4711475648357
UPC Code	841163098356	841163098363
N.W	4.05 kg / 8.93 lbs.	
G.W	4.85 kg / 10.70 lbs.	
Carton Size (L x W x H)	436 x 239 x 358 mm / 17.17 x 9.41 x 14.10 inch	
Cuft	1.32	
Container	w/o pallet	
20'	749 pcs	
40'	1553 pcs	
40' HQ	1812 pcs	



Packaging

Package Information	TR100 Matcha Green	TR100 Hydrangea Blue
EAN Code	4711475648364	4711475648371
UPC Code	841163098370	841163098387
N.W	4.05 kg / 8.93 lbs.	
G.W	4.85 kg / 10.70 lbs.	
Carton Size (L x W x H)	436 x 239 x 358 mm / 17.17 x 9.41 x 14.10 inch	
Cuft	1.32	
Container	w/o pallet	
20'	749 pcs	
40'	1553 pcs	
40' HQ	1812 pcs	



Appearance – Black version



Angle view




Left Side view



Front view



Right Side view

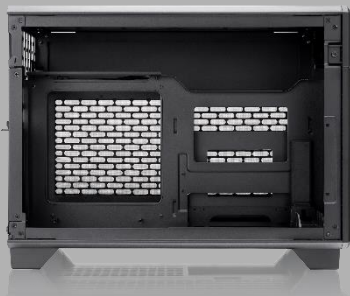

Internal Structure



Rear view



Internal Structure



Top view




Bottom view

Appearance – White version



Angle view

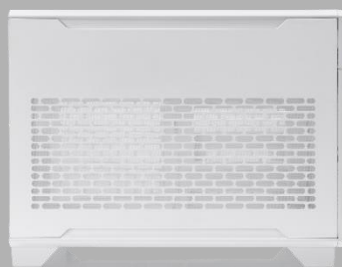


Left Side view



Front view




Right Side view

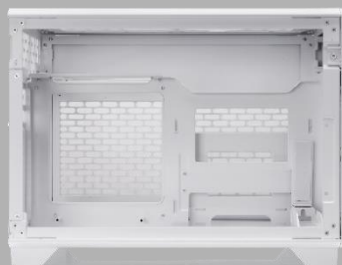

Internal Structure



Rear view

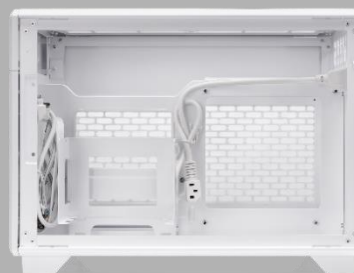

Internal Structure



Top view



Bottom view

Appearance – Matcha Green




Angle view



Left Side view



Front view

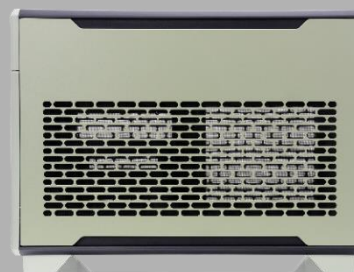

Right Side view




Internal Structure



Rear view



Internal Structure

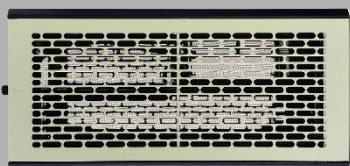

Top view




Bottom view

Appearance – Hydrangea Blue




Angle view

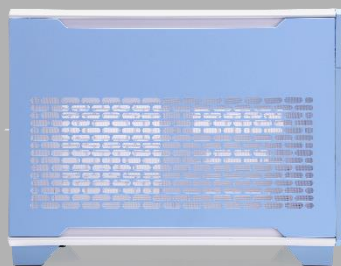

Left Side view



Front view

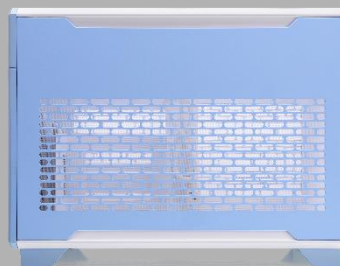

Right Side view




Internal Structure



Rear view



Internal Structure

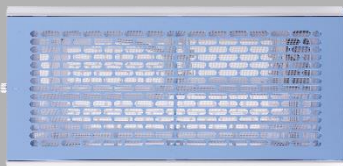


Top view





Bottom view

Exploded View

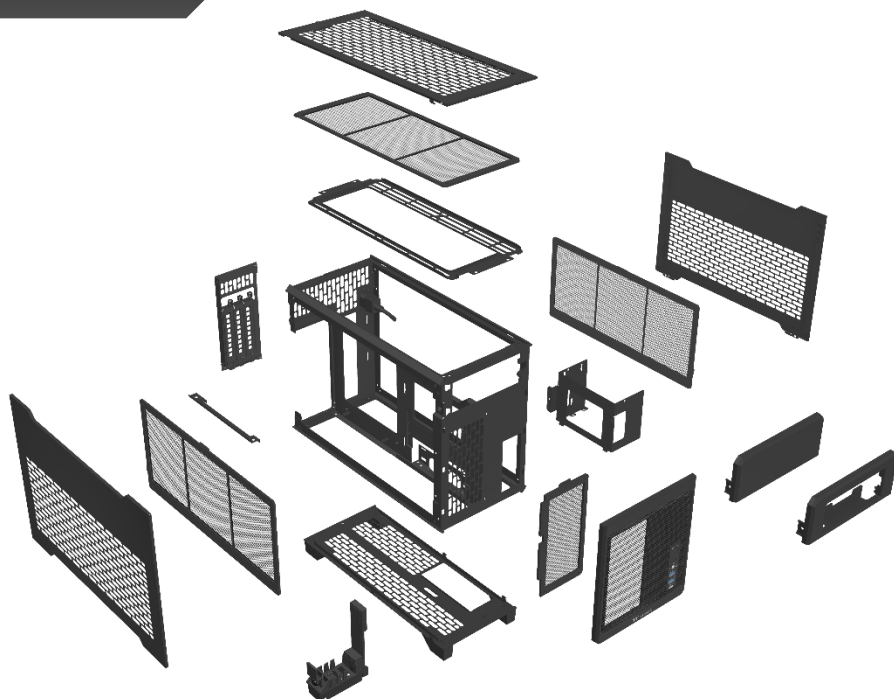

Exploded View

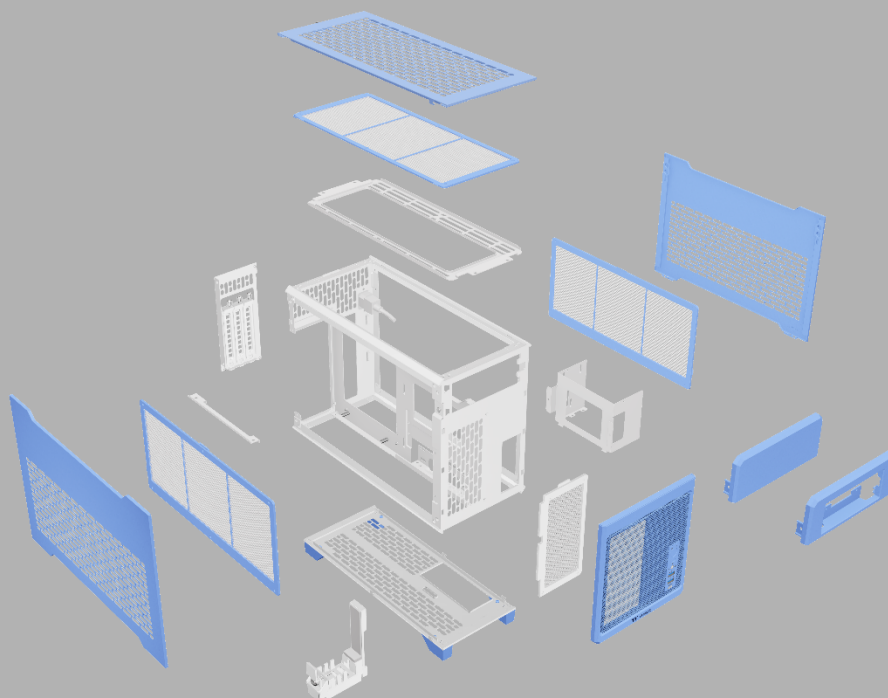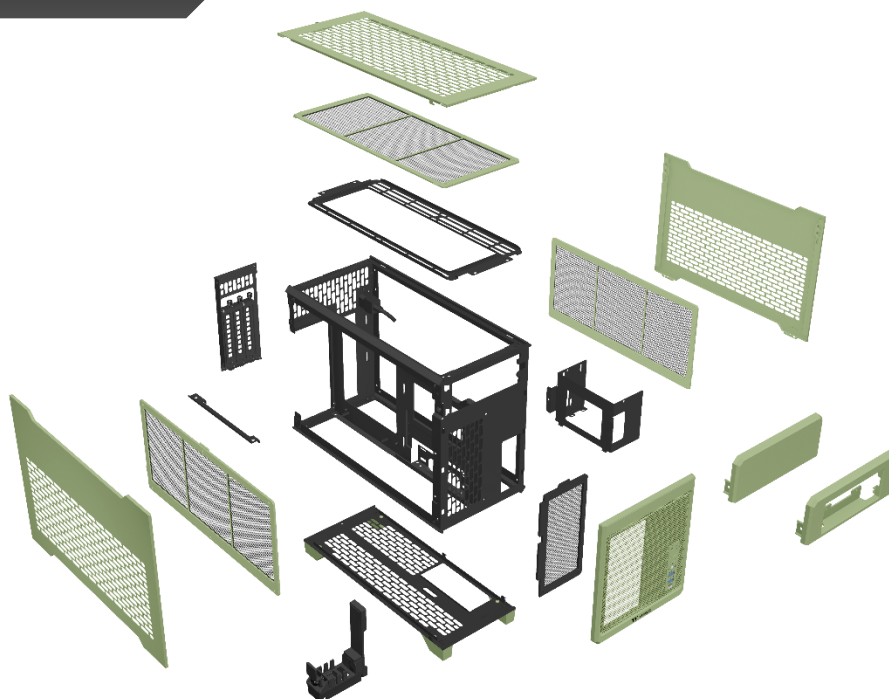

Unique Design



Two front panels for
customized installation.



✕ 3.9 inch LCD Screen Kit is not
included

Structure (External)




USB 3.2 (Gen 2) Type-C x 1

USB 3.0 x 2

HD Audio

Removable Top cover & Bottom cover

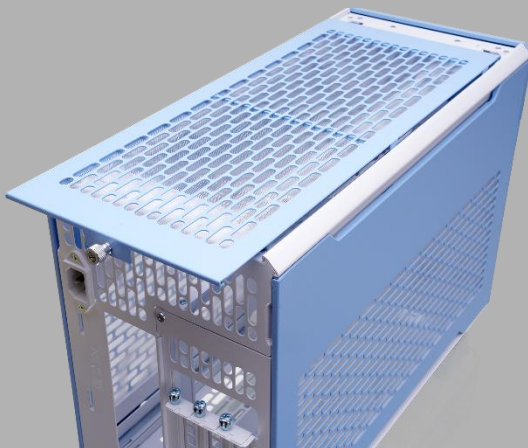

Clearance



Maximum support up to
140mm fan x 2 at Top

Maximum radiator support
up to 280mm at Top


(Clearance of Fan + Radiator:53mm)

Structure (Internal)




Maximum support up to **2.5" SSD x 2**

Structure (Internal)

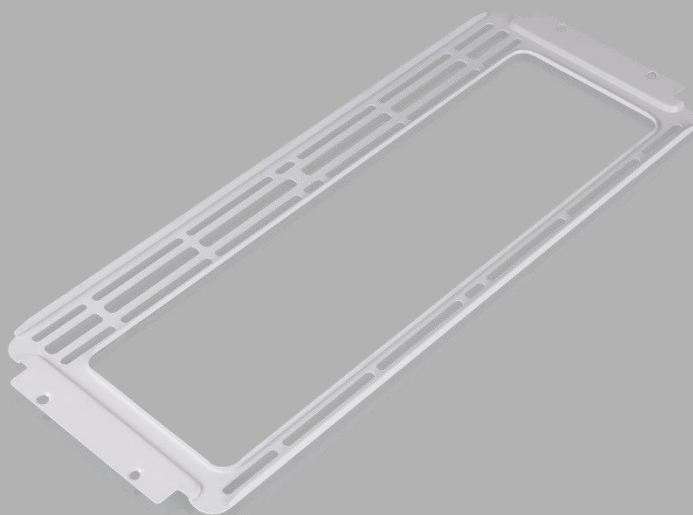


Removable Top
fan/radiator bracket

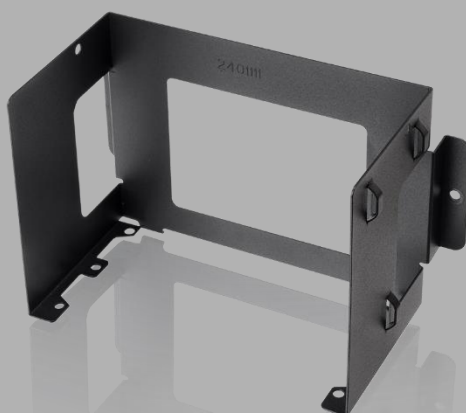


Removable PSU bracket

Structure (Internal)

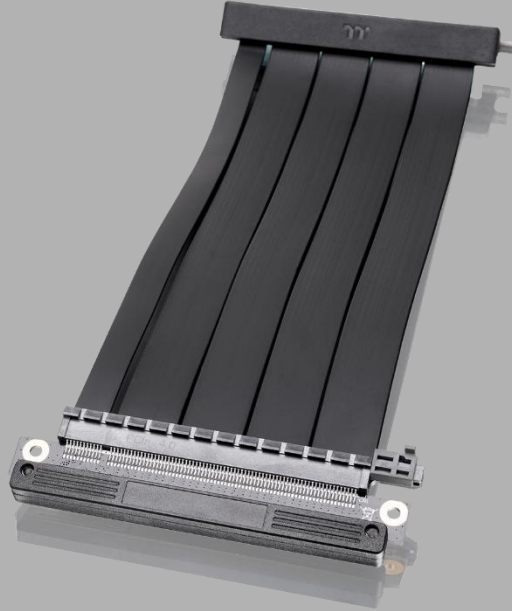


PCI-E 4.0 Riser Cable Included (220m)

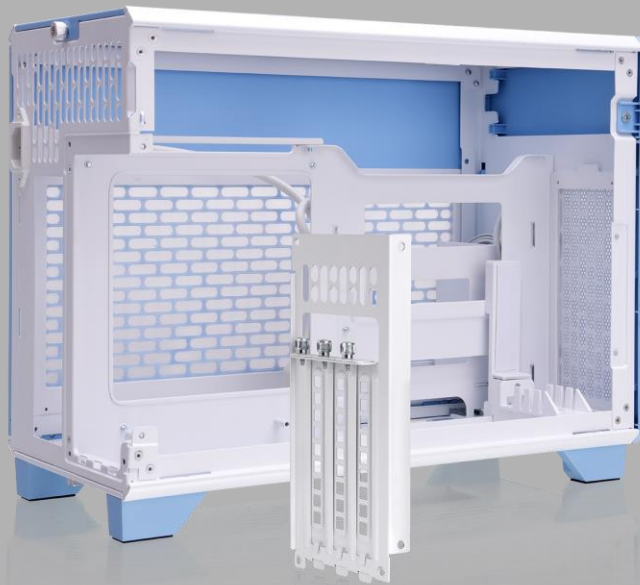


Removable VGA bracket

Structure (Internal)

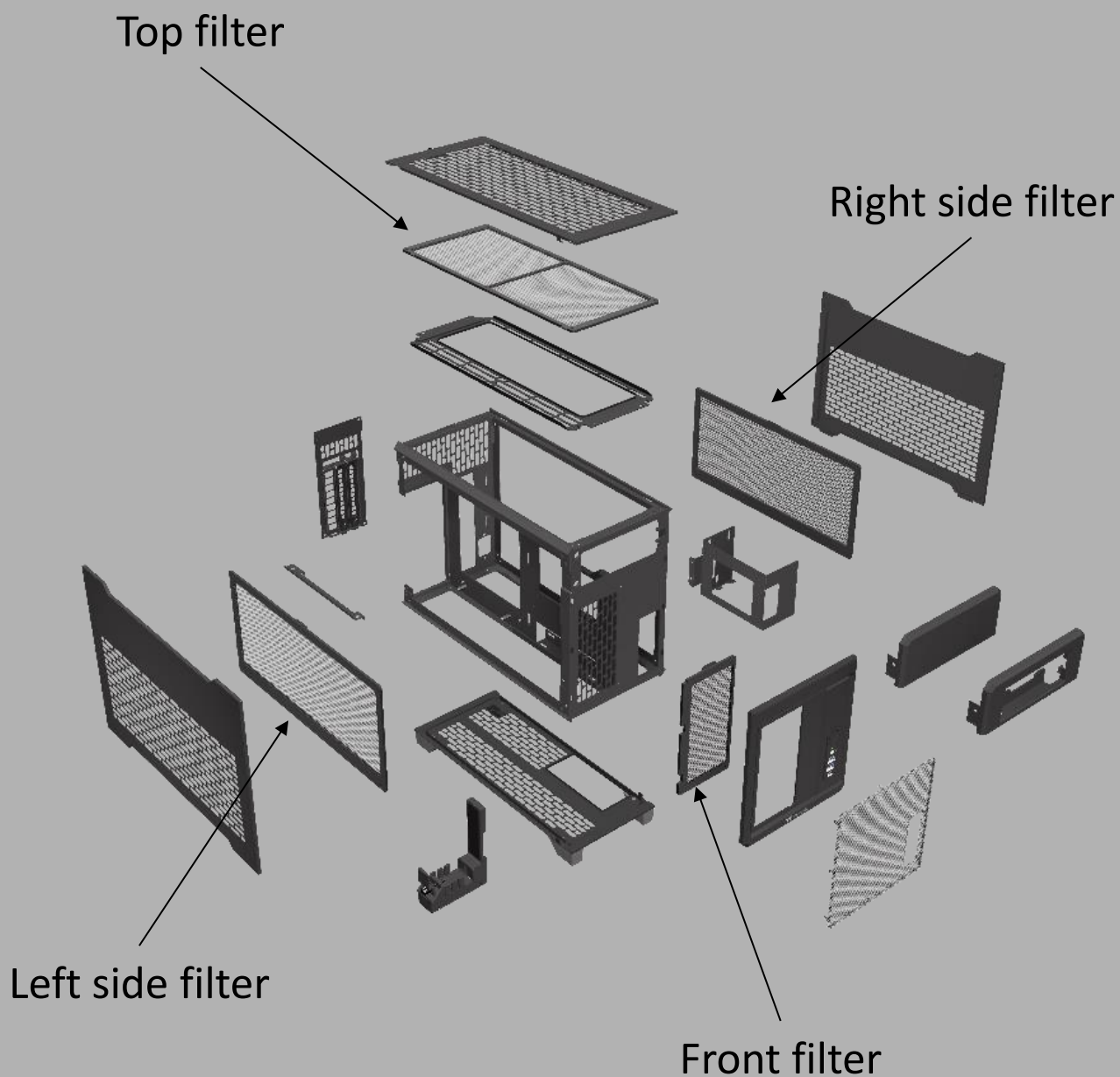

Compatibility List

Fan Compatibility List			
	120mm	140mm	200mm
Front	-	-	-
Top	2	2	-
Rear	-	-	-

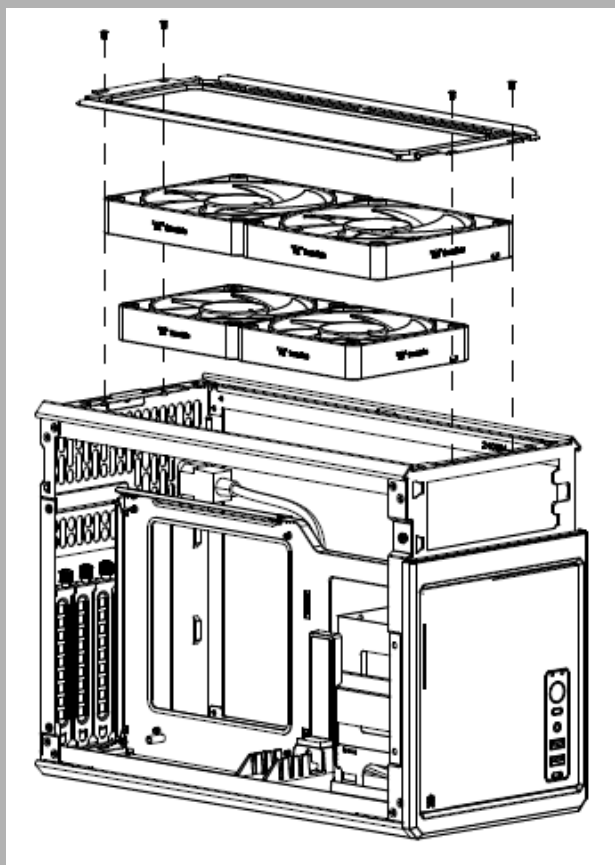

All-in-One Compatibility

All-in-One Compatibility List						
	120mm	240mm	360mm	140mm	280mm	420mm
Front	-	-	-	-	-	-
Top	●	●	-	●	●	-
Rear	-	-	-	-	-	-

