

- **Style: Simple**
- **Size: Mini case supports up to Mini-ITX MB**
- **Material: Steel & Tempered Glass**

Main Features

- **Connection** : Front I/O ports with 2 x USB 3.0 & 1 x USB 3.2
- **Cooling Solution** : Pre-installed 120mm CT120 Fan x 2
- **Support** : Supports 360mm AIO cooling solutions
- **Compatible Accessory: Chassis Stand Kit for the Tower 250 and 3.9" LCD Screen Kit**






Specification

Model	The Tower 250	The Tower 250 Snow	The Tower 250 Matcha Green	The Tower 250 Hydrangea Blue	The Tower 250 Mint Strawberry	The Tower 250 Butter Caramel
P/N	CA-1Z9-00S1WN-00	CA-1Z9-00S6WN-00	CA-1Z9-00SEWN-00	CA-1Z9-00SFWN-00	CA-1Z9-00SLWN-00	CA-1Z9-00SMWN-00
Case Type	Mini Tower					
Chassis Dimension (H*W*D)	506 x 300 x 281 mm (19.9 x 11.8 x 11.5 inch)					
Net Weight	7.1 kg / 15.65 lbs.					
Side Panel	3mm Tempered Glass x 3					
Color	Black	White	Matcha Green	Hydrangea Blue	Mint Strawberry	Butter Caramel
Material	SPCC					
Cooling System	Top(exhaust): 120 x 120 x 25 mm CT120 fan (2000rpm, 25.8 dBA) x 2					
Drive Bays	1 x 3.5", or 2 x 2.5"					
Expansion Slots	3					
Motherboards	6.7" x 6.7" (Mini ITX),					
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 2, HD Audio x 1					
PSU	Standard SFX or ATX PSU (optional)					
Fan Support	Top: 2 x 120mm, 1 x 120mm Right Side: 3 x 120mm, 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm Rear: 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm Power Cover: 1 x 120mm 1 x 140mm					
Radiator Support	Right Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm					
Clearance	CPU cooler height limitation: 210mm VGA length limitation: 245mm(With power cover) 360mm(Without power cover) PSU length limitation: 200mm					

Packaging

Package Information	The Tower 250	The Tower 250 Snow	The Tower 250 Matcha Green	The Tower 250 Hydrangea Blue	The Tower 250 Mint Strawberry	The Tower 250 Butter Caramel
EAN Code	4711475647213	4711475647220	4711475648265	4711475648272	4711475648876	4711475648883
UPC Code	841163097229	841163097236	841163098271	841163098288	841163098882	841163098899
N.W	7.1 kg / 15.65 lbs.					
G.W	8.6 kg / 18.96 lbs.					
Carton Size (L x W x H)	358 x 348 x 578 mm / 14.09 x 13.7 x 22.76 inch					
Cuft	2.54					
Container	w/o pallet, w/ spare parts					
20'	347 pcs					
40'	712 pcs					
40' HQ	833 pcs					

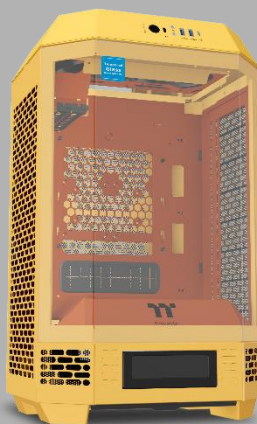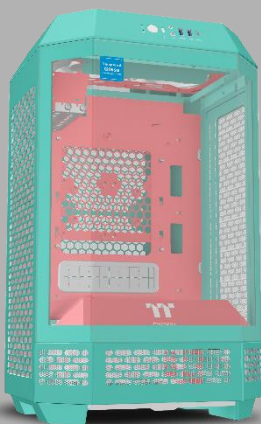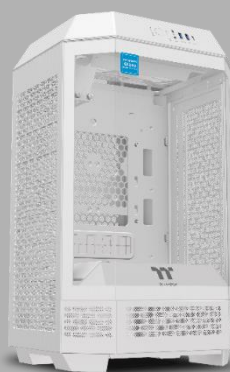

Appearance – Black version



Angle view



Left Side view



Front view




Right Side view



Internal Structure



Rear view

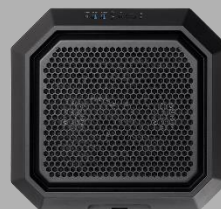

Top view



Bottom view

Appearance – Snow version



Angle view



Left Side view




Front view



Right Side view




Internal Structure

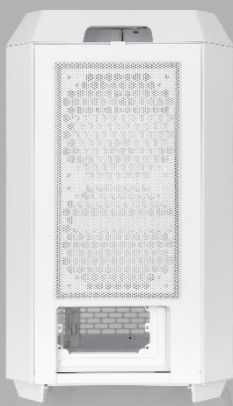

Rear view



Top view

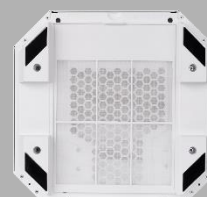


Bottom view

Appearance – Matcha Green



Angle view

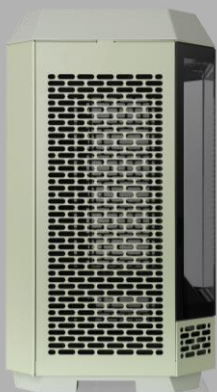

Left Side view



Front view



Right Side view




Internal Structure



Rear view



Top view

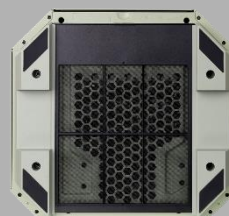


Bottom view

Appearance – Hydrangea Blue



Angle view

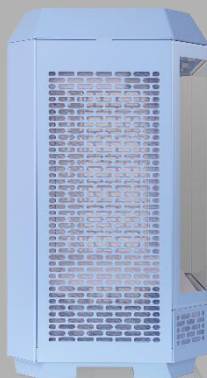

Left Side view




Front view



Right Side view




Internal Structure

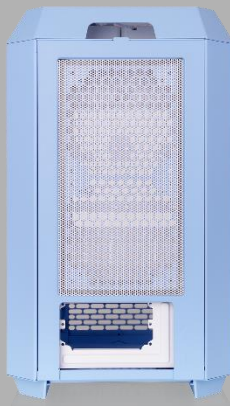

Rear view




Top view

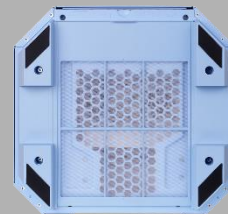

Bottom view

Appearance – Mint Strawberry

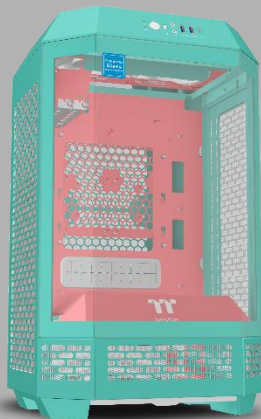

Angle view

Left Side view

Front view

Right Side view


Top view

Internal Structure

Rear view

Bottom view

Appearance – Butter Caramel

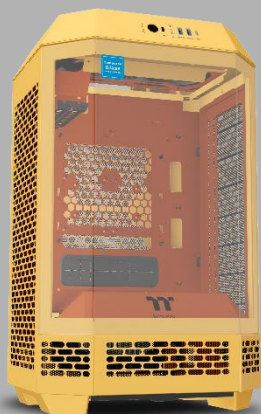

Angle view

Left Side view

Front view

Right Side view

Top view

Internal Structure

Rear view

Bottom view

Clearance



Maximum supports up
to **120mm fan x 8**

Maximum AIO radiator
supports up to **360mm**





Two front metal panels for customized installation.



✖ 3.9 inch LCD Screen Kit is not included

Structure (External)



USB 3.2 (Gen 2) Type-C

USB 3.0 x 2

HD Audio




Easy-to Remove

Structure (Internal)



Two **120mm** Top Fans

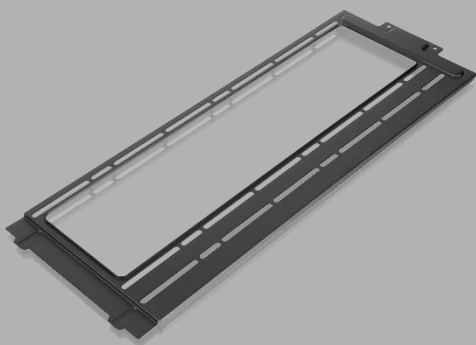


Right Side Bracket
for Radiator/Fan Installation



Structure (Internal)

Supports **ATX** and **SFX** PSU

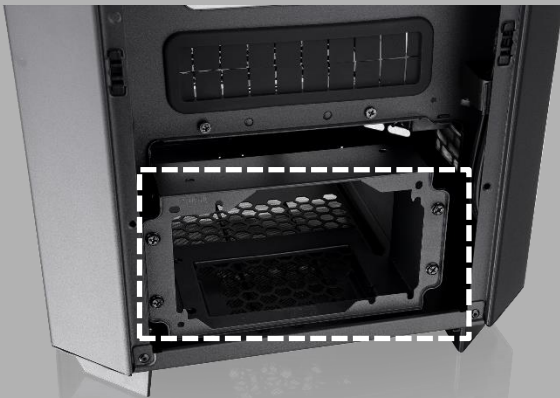


ATX Bracket



SFX Bracket

Structure (Internal)

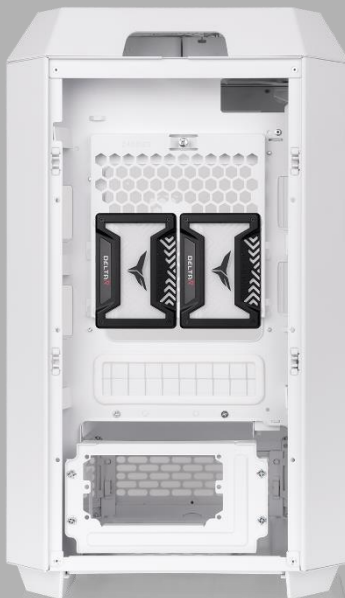


2 x 2.5"



1 x 3.5"

Structure (Internal)

Top filter

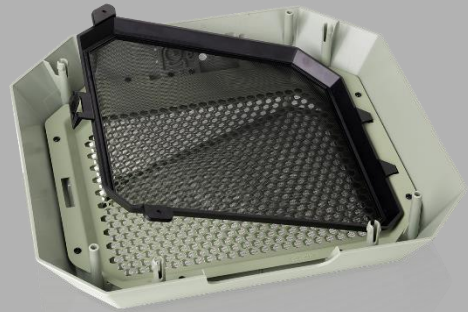

Front and Side filters

Bottom filter



Pre-installed CT120 Fan



Pre-installed two hydraulic bearing **120mm CT120** fans which can effectively lower the operation noise and enhance the thermal efficiency.



Black Version




Snow Version


SPEC for Case **CT120** fans

- Fan Speed: 500~2000 RPM
- Max. Fan Airflow: 57.05 CFM
- Max. Fan Air Pressure: 2.23 mm-H2O
- Fan Noise Level: 25.8 dBA
- Fan Bearing: Hydraulic bearing



Exploded View

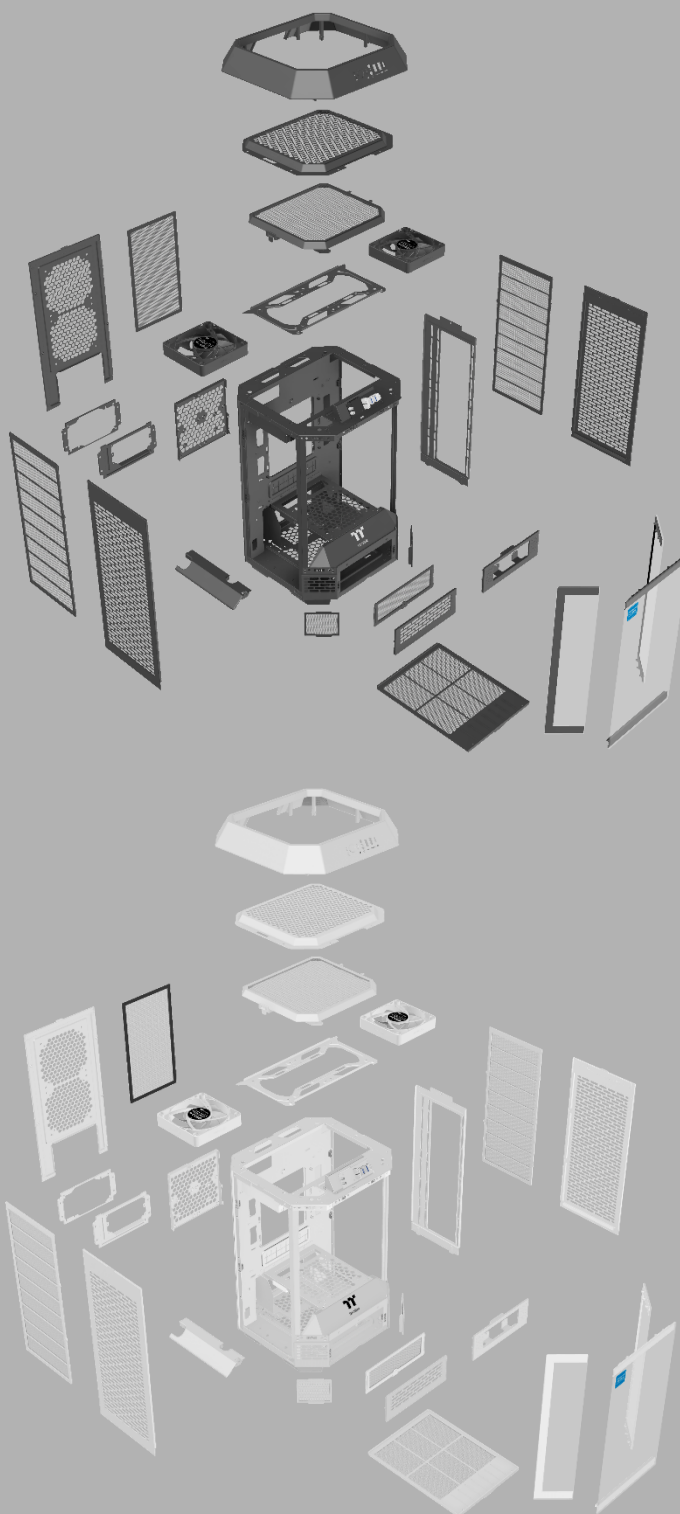

Exploded View

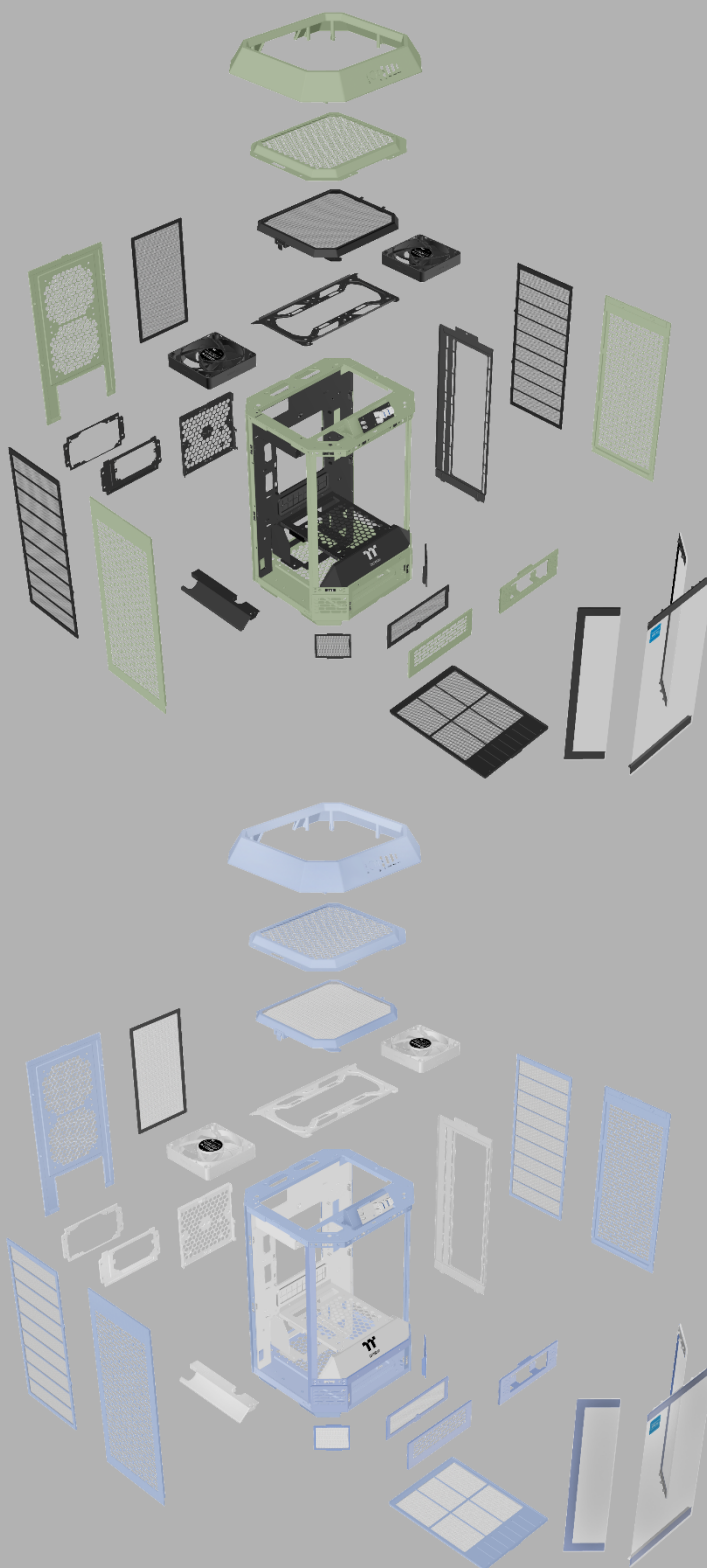


Exploded View

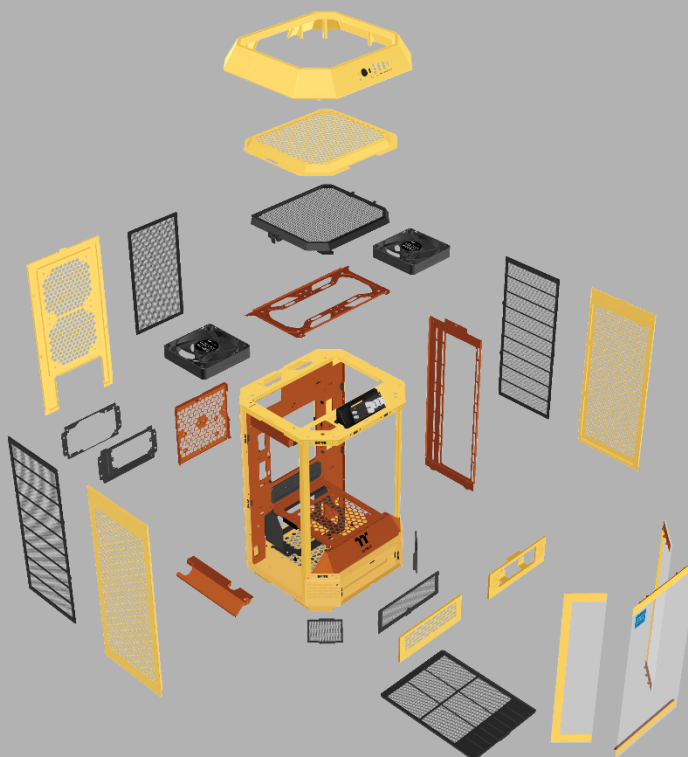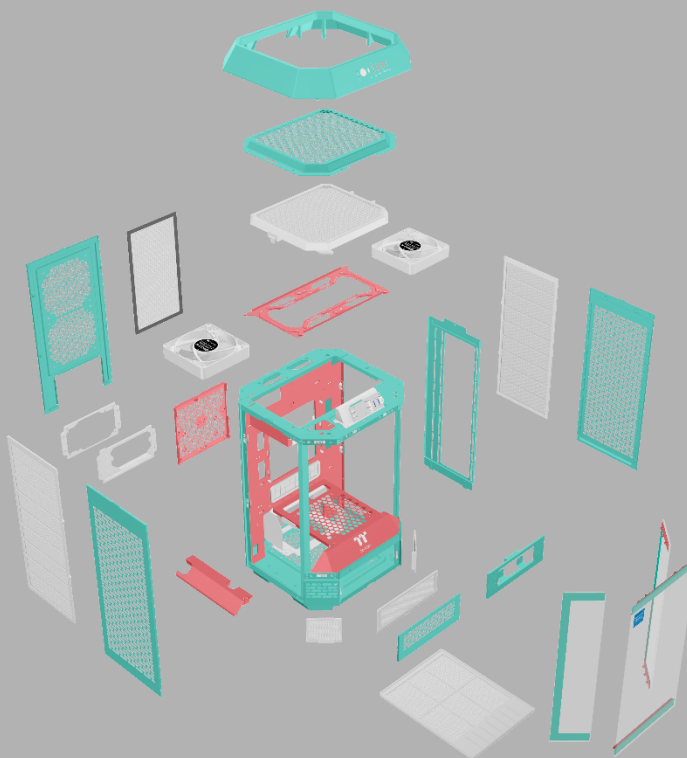

Fan Compatibility


Fan Compatibility List		
	120mm	140mm
Top	2	-
Right Side	3	2
Rear	2	2
PSU Cover	1	1

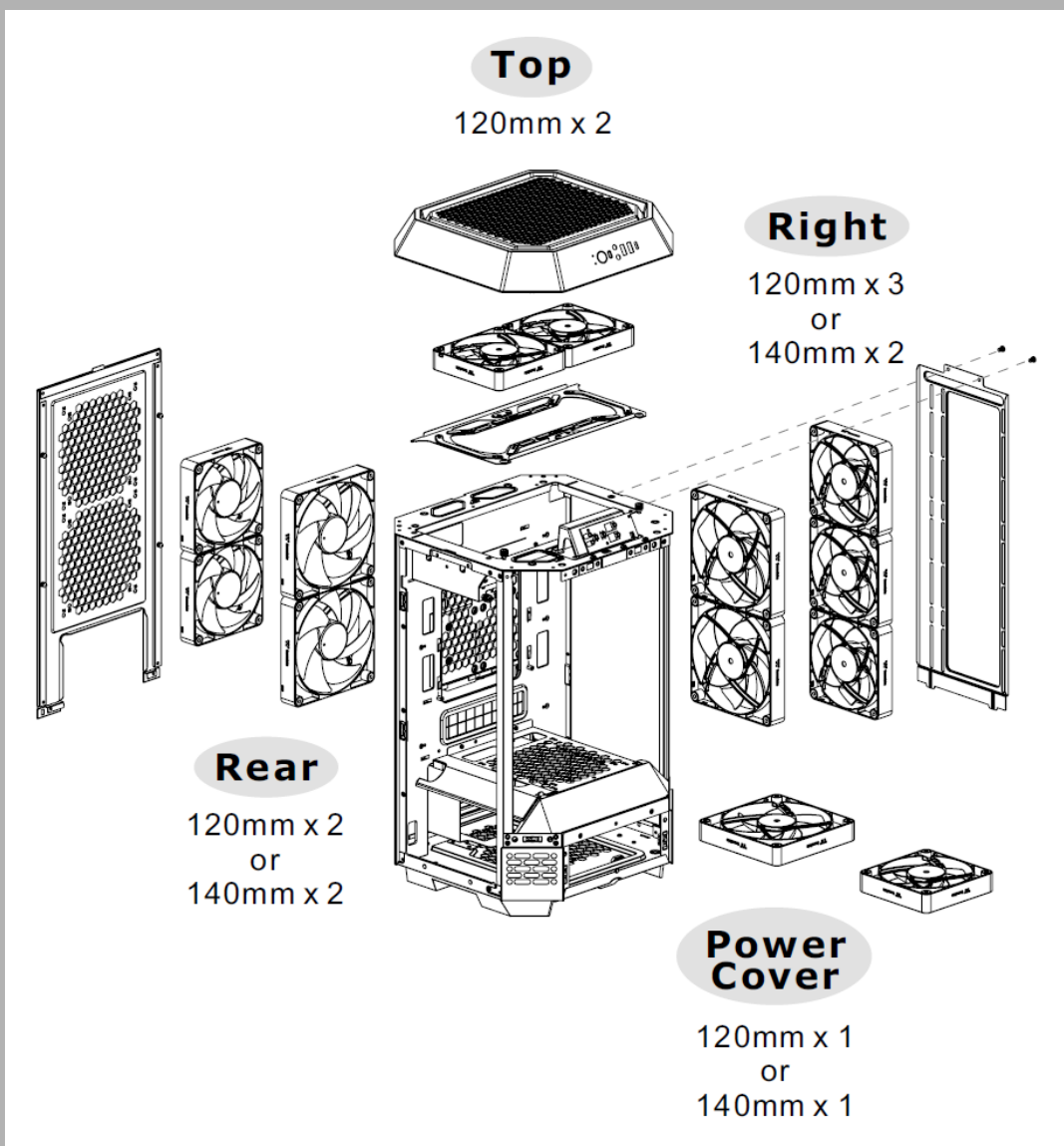

All-in-One Compatibility

All-in-One Compatibility List

	120mm	240mm	360mm	140mm	280mm	420mm
Top	-	-	-	-	-	-
Right Side	●	●	●	●	●	-
Rear	-	-	-	-	-	-

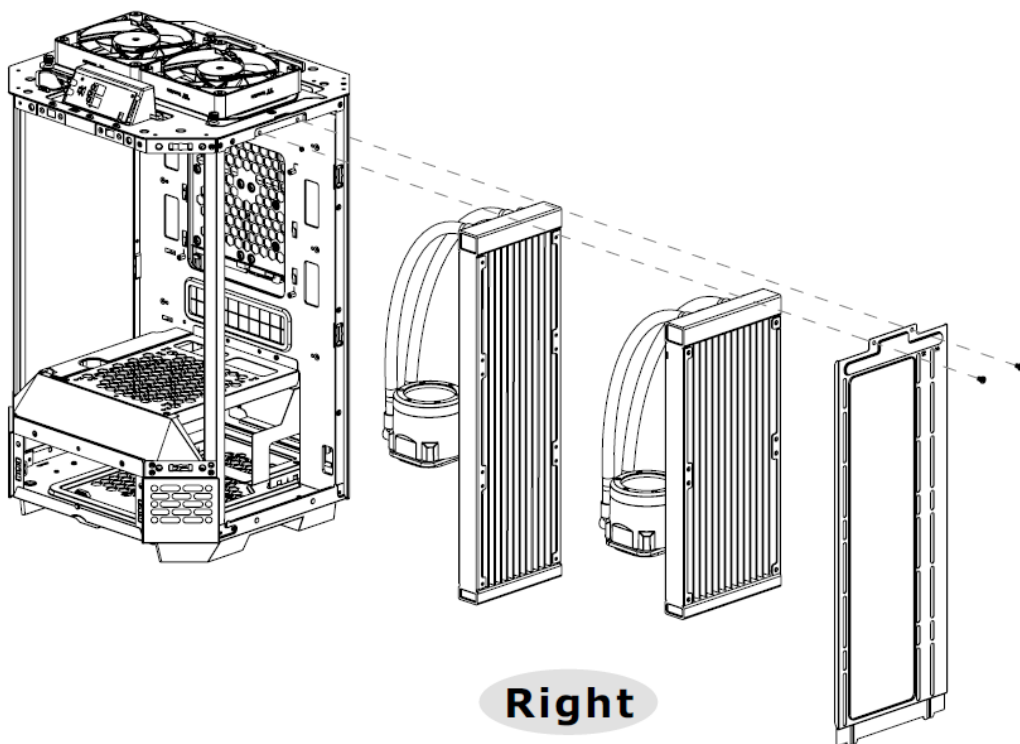

Right

360mm x 1
or
280mm x 1