


Pre-Datasheet

- **Style: Simple**
- **Size: Mid Tower case supports up to ATX MB**
- **Material: Steel & Tempered Glass**

Main Features

- **Connection :** Front I/O ports with 4 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Cooling Solution :** Pre-installed 140mm CT140 Fan x 2
- **Support:** 420mm AIO cooling solutions
- **Compatible Accessory:** Chassis Stand Kit for the Tower 600 and 3.9" LCD

Screen Kit

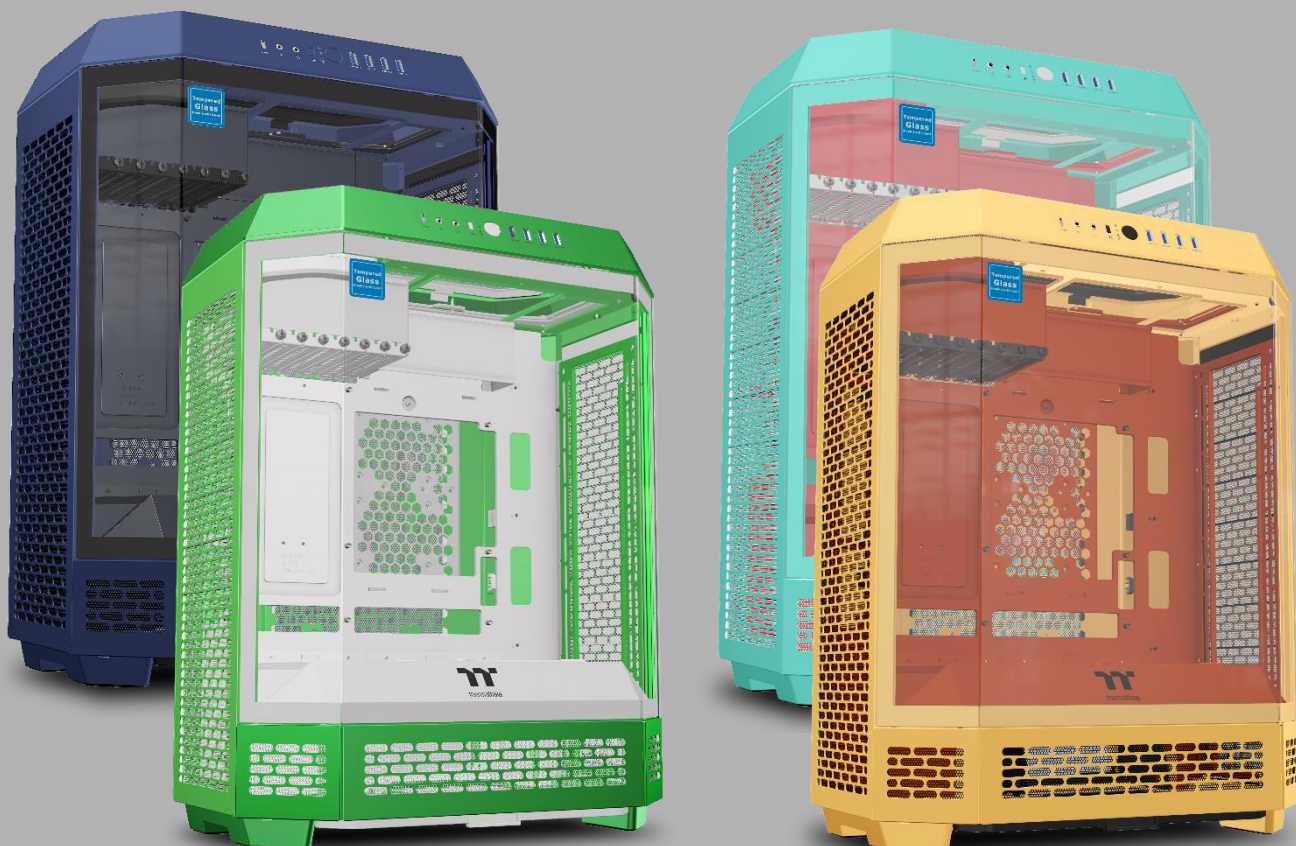

Pre-Datasheet

- **Style: Simple**
- **Size: Mid Tower case supports up to ATX MB**
- **Material: Steel & Tempered Glass**

Main Features

- **Connection :** Front I/O ports with 4 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Cooling Solution :** Pre-installed 140mm CT140 Fan x 2
- **Support:** 420mm AIO cooling solutions
- **Compatible Accessory:** Chassis Stand Kit for the Tower 600 and 3.9" LCD Screen Kit



Specification

Model	The Tower 600 Future Dusk	The Tower 600 Light-year Green	The Tower 600 Mint Strawberry	The Tower 600 Butter Caramel
P/N	CA-1Z1-00MNWN-00	CA-1Z1-00MOWN-00	CA-1Z1-00MLWN-00	CA-1Z1-00MMWN-00
Color	Future Dusk	Light-year Green	Mint Strawberry	Butter Caramel
Case Type	Mid Tower			
Chassis Dimension (H*W*D)	550 x 420 x 286.4 mm (21.65 x 16.54 x 11.28 inch)			
Side Panel	3mm Tempered Glass x 3			
Material	SPCC			
Cooling System	Top(exhaust): 140 x 140 x 25 mm CT140 fan (1500rpm, 30.5 dBA) x 2			
Drive Bays	1 x 3.5", 2 x 2.5" or 3 x 2.5"			
Expansion Slots	7			
Motherboards	6.7" x 6.7" (Mini ITX), 9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)			
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 4, HD Audio x 1			
PSU	Standard PS2 PSU (optional)			
Fan Support	Top: 3 x 120mm, 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm Right: 3 x 120mm, 2 x 120mm, 1 x 120mm 3 x 140mm, 2 x 140mm, 1 x 140mm Left: 3 x 120mm, 2 x 120mm, 1 x 120mm Rear: 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm Power Cover: 1 x 120mm, 1 x 140mm Bottom: 1 x 120mm, 1 x 140mm			
Radiator Support	Right Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 420mm, 1 x 280mm, 1 x 140mm Left Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm			
Clearance	CPU cooler height limitation: 210mm VGA length limitation: 280mm(With power cover) 400mm(Without power cover) PSU length limitation: 220mm			

Specification

Model	The Tower 600 Mocha Mousse			
P/N	CA-1Z1-00MUWN-00			
Color	Mocha Mousse			
Case Type	Mid Tower			
Chassis Dimension (H*W*D)	550 x 420 x 286.4 mm (21.65 x 16.54 x 11.28 inch)			
Side Panel	3mm Tempered Glass x 3			
Material	SPCC			
Cooling System	Top(exhaust): 140 x 140 x 25 mm CT140 fan (1500rpm, 30.5 dBA) x 2			
Drive Bays	1 x 3.5", 2 x 2.5" or 3 x 2.5"			
Expansion Slots	7			
Motherboards	6.7" x 6.7" (Mini ITX), 9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)			
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 4, HD Audio x 1			
PSU	Standard PS2 PSU (optional)			
Fan Support	Top: 3 x 120mm, 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm Right: 3 x 120mm, 2 x 120mm, 1 x 120mm 3 x 140mm, 2 x 140mm, 1 x 140mm Left: 3 x 120mm, 2 x 120mm, 1 x 120mm Rear: 2 x 120mm, 1 x 120mm 2 x 140mm, 1 x 140mm Power Cover: 1 x 120mm, 1 x 140mm Bottom: 1 x 120mm, 1 x 140mm			
Radiator Support	Right Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 420mm, 1 x 280mm, 1 x 140mm Left Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm			
Clearance	CPU cooler height limitation: 210mm VGA length limitation: 280mm(With power cover) 400mm(Without power cover) PSU length limitation: 220mm			


Packaging

Package Information	The Tower 600 Future Dusk	The Tower 600 Light-year Green
P/N	CA-1Z1-00MNWN-00	CA-1Z1-00MOWN-00
EAN Code	4711475649798	4711475649804
UPC Code	841163099803	841163099810
N.W	9.70 kg / 21.39 lbs.	
G.W	11.84 kg / 26.10 lbs.	
Carton Size (L x W x H)	488 x 358 x 640 mm / 19.22 x 14.10 x 25.2 inch	
Cuft	3.95	
Container	w/o pallet, w/ spare parts	
20'	259 pcs	
40'	539 pcs	
40' HQ	617 pcs	




Packaging

Package Information	The Tower 600 Mint Strawberry	The Tower 600 Butter Caramel
P/N	CA-1Z1-00MLWN-00	CA-1Z1-00MMWN-00
EAN Code	4711475649811	4711475649828
UPC Code	841163099827	841163099834
N.W	9.70 kg / 21.39 lbs.	
G.W	11.84 kg / 26.10 lbs.	
Carton Size (L x W x H)	488 x 358 x 640 mm / 19.22 x 14.10 x 25.2 inch	
Cuft	3.95	
Container	w/o pallet, w/ spare parts	
20'	259 pcs	
40'	539 pcs	
40' HQ	617 pcs	

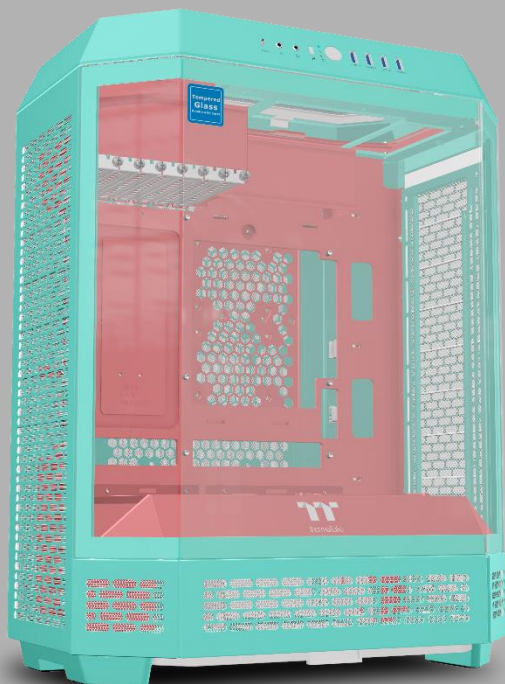

Packaging


Package Information	The Tower 600 Mocha Mousse	
P/N	CA-1Z1-00MUWN-00	
EAN Code	4711658544445	
UPC Code	840480304447	
N.W	9.70 kg / 21.39 lbs.	
G.W	11.84 kg / 26.10 lbs.	
Carton Size (L x W x H)	488 x 358 x 640 mm / 19.22 x 14.10 x 25.2 inch	
Cuft	3.95	
Container	w/o pallet, w/ spare parts	
20'	259 pcs	
40'	539 pcs	
40' HQ	617 pcs	

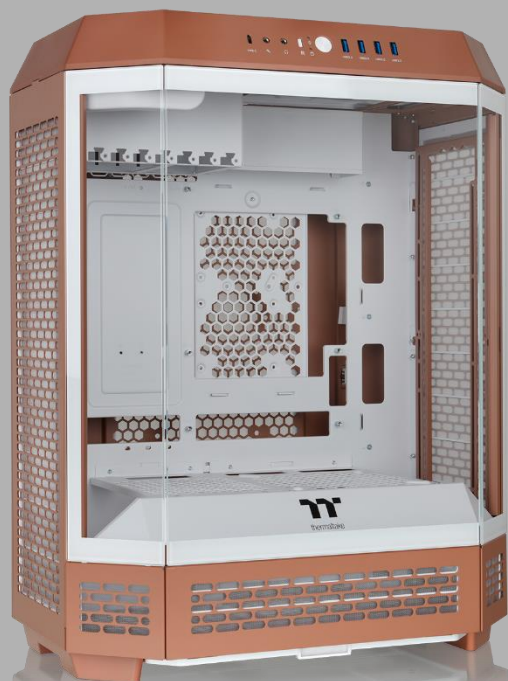


Appearance – Future Dusk version




Angle view

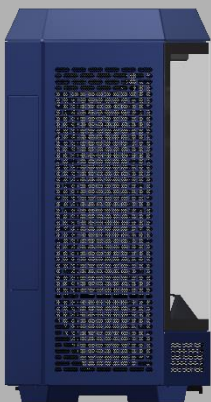

Left Side view

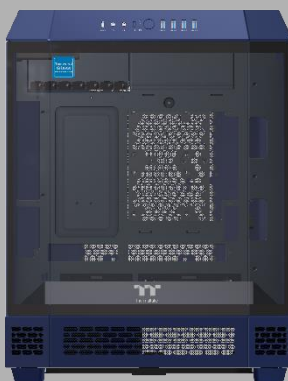

Front view

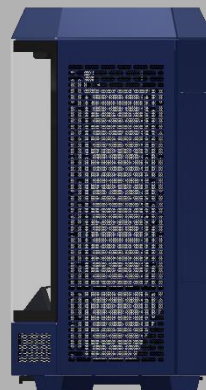

Right Side view



Internal Structure



Rear view



Top view




Bottom view


Appearance – Light-year Green version




Angle view

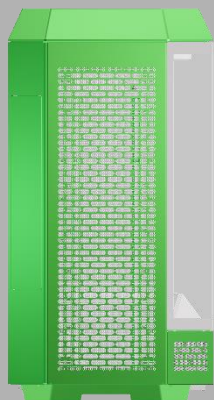


Left Side view

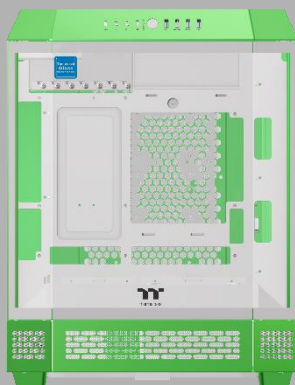


Front view

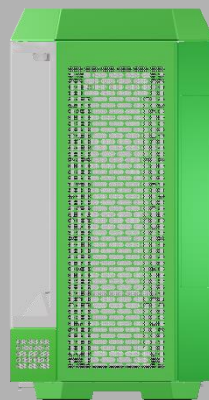


Right Side view

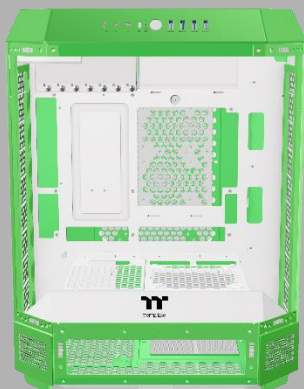


Internal Structure

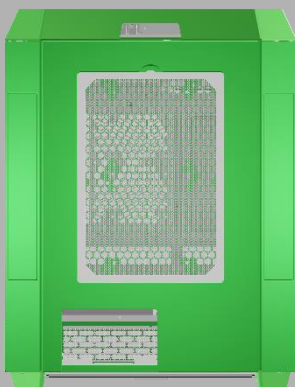

Rear view

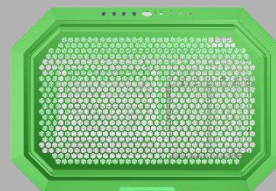

Top view

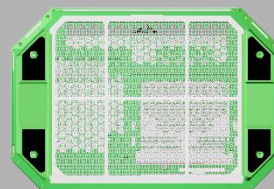


Bottom view


Appearance – Mint Strawberry version




Angle view

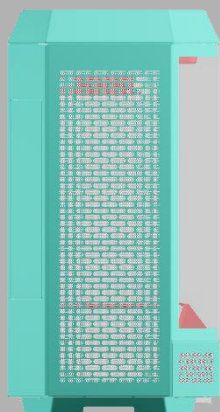


Left Side view

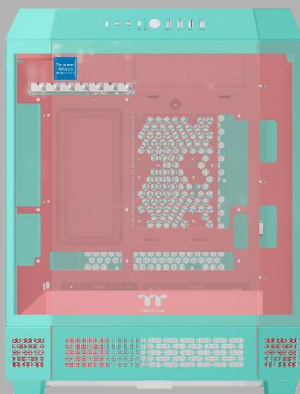


Front view

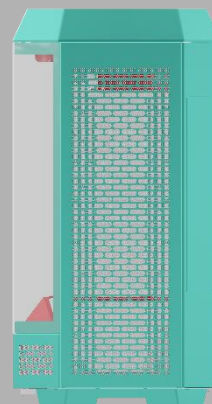


Right Side view

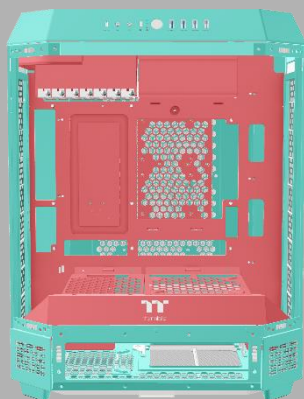


Internal Structure

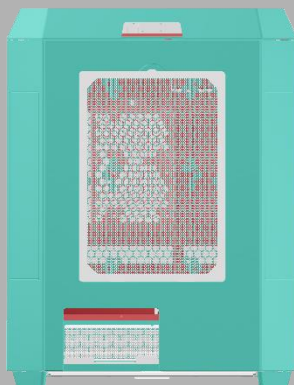

Rear view

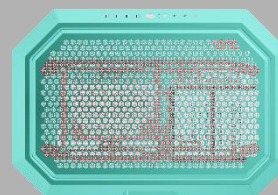


Top view

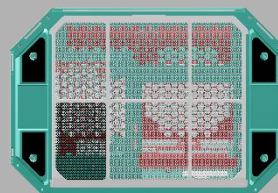

Bottom view


Appearance – Butter Caramel version

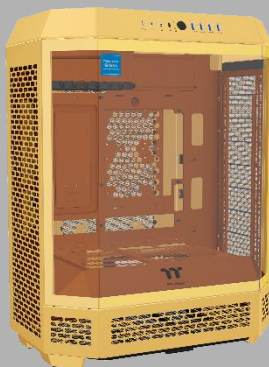


Angle view




Left Side view

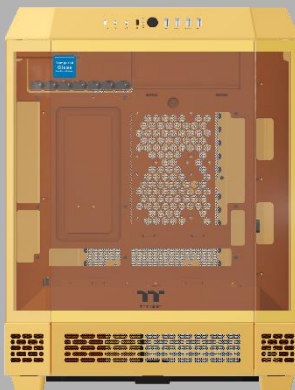

Front view

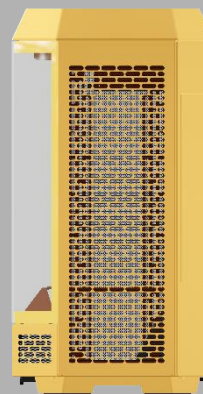


Right Side view

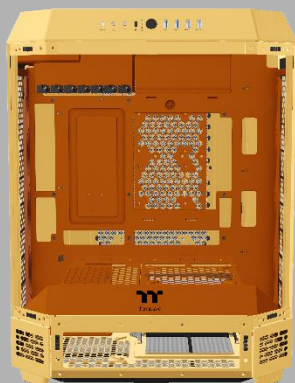


Internal Structure



Rear view

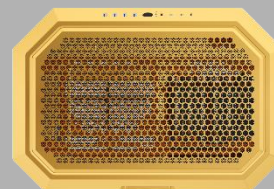

Top view

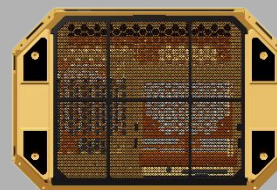

Bottom view


Appearance – Mocha Mousse version



Angle view



Left Side view

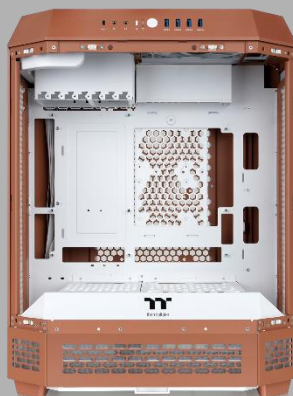


Front view



Right Side view



Internal Structure

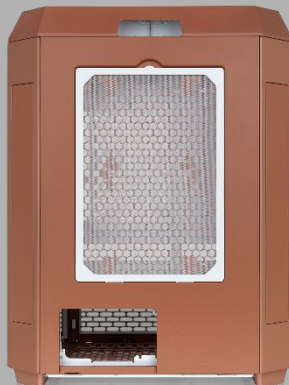

Rear view



Top view



Bottom view

Clearance



Maximum AIO radiator
supports up to 420mm

Maximum supports up
to 120mm fan x **13**



Unique Design



Two front metal panels for customized installation.



✕ 3.9 inch LCD Screen Kit is not included

Structure (External)



USB 3.2 (Gen 2) Type-C x 1

USB 3.0 x 4

HD Audio



Easy-to Remove


Structure (Internal)



Two 140mm Top Fans



Supports ATX PSU

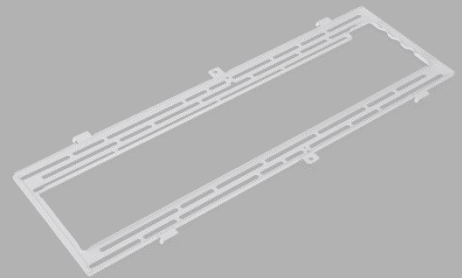

Right /Left Side Bracket
for Radiator/Fan Installation

Structure (Internal)




3 x 2.5"



1 x 3.5"

Structure (Internal)

Top filter

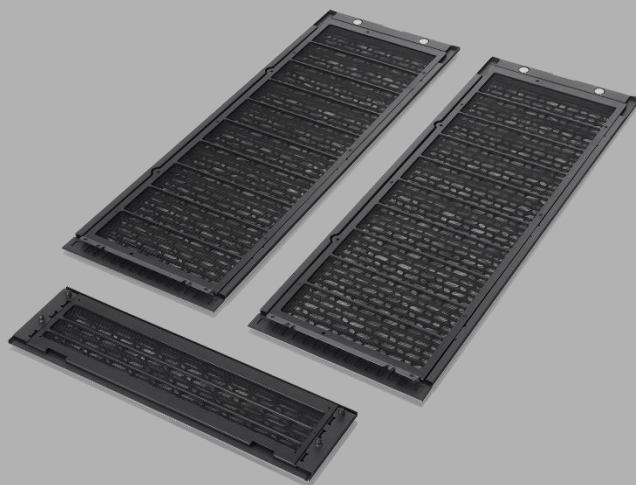

Front and Side filters

Bottom filter




Pre-installed CT140 Fan



Pre-installed two hydraulic bearing 140mm **CT140** fans which can effectively lower the operation noise and enhance the thermal efficiency.



Black Version


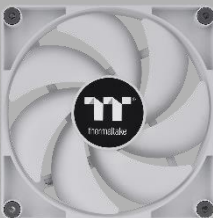


Snow Version

SPEC for Case **CT140** fans


- Fan Speed: 500~1500 RPM
- Max. Fan Airflow: 77.37 CFM
- Max. Fan Air Pressure: 2.3 mm-H2O
- Fan Noise Level: 30.5 dBA
- Fan Bearing: Hydraulic bearing

Exploded View

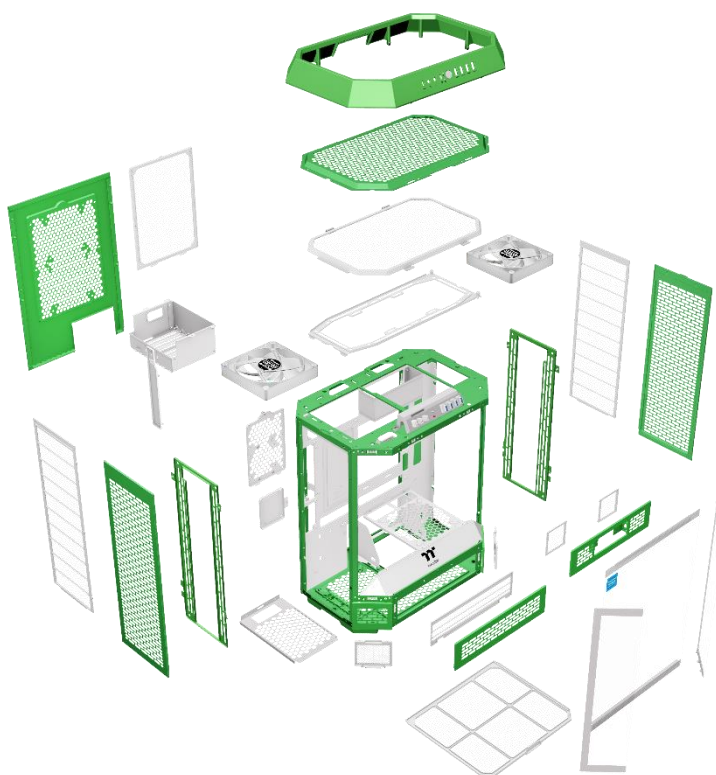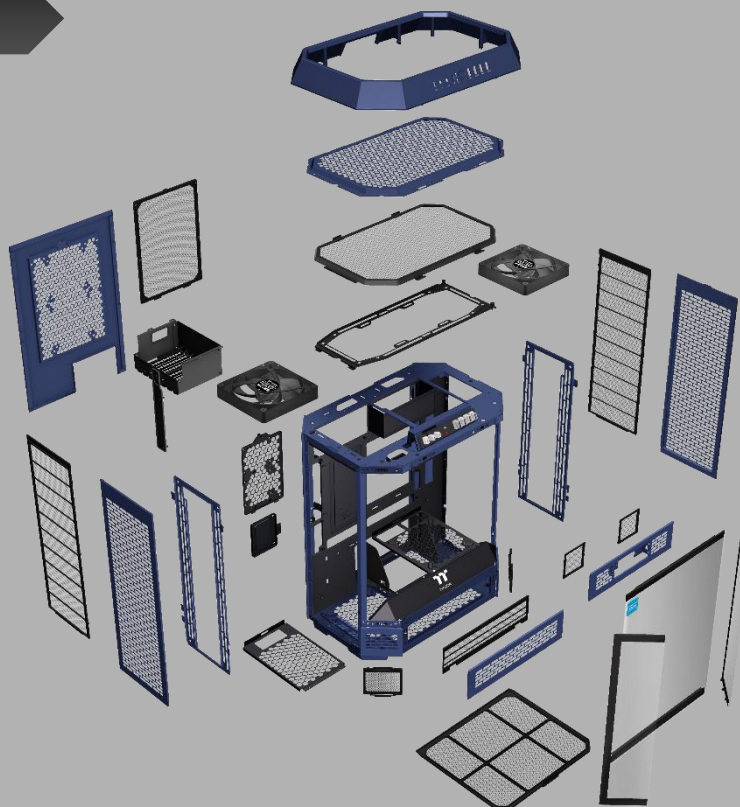




This exploded view diagram illustrates the assembly of the LEGO Technic 42110 Space Shuttle. The components are arranged in a way that shows their relative positions and how they fit together. The main parts include the orbiter (a red and white structure with a cockpit and landing gear), the external tank (a large white cylindrical structure), and the solid rocket boosters (two large white rectangular structures). Other visible parts include the nose cone, various panels, and smaller components like the landing gear and the shuttle's base. The diagram is set against a light gray background with a subtle grid pattern.

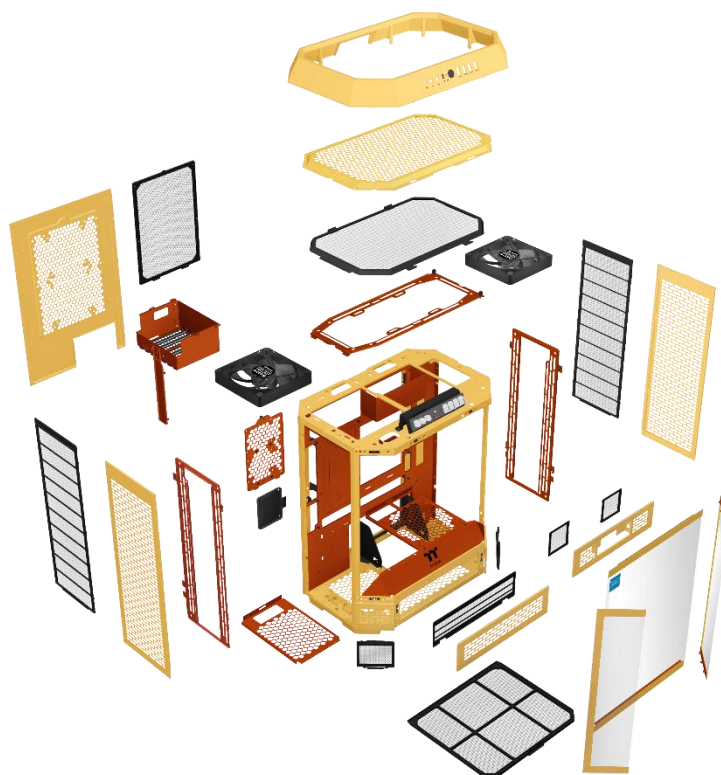

[illegible]

Compatibility List

Fan Compatibility List			
	120mm	140mm	200mm
Top	3	2	-
Right Side	3	3	-
Left Side	3	-	-
Rear	2	2	-
PSU Cover	1	1	-
Bottom	1	1	-

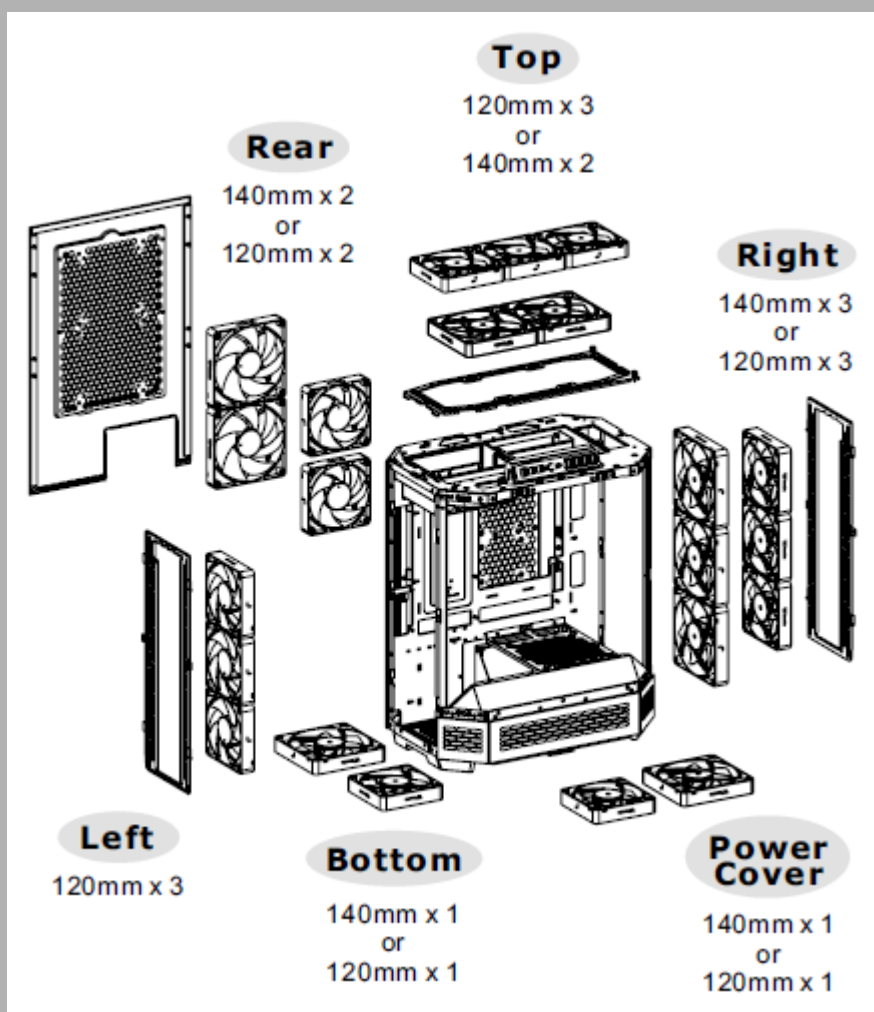

All-in-One Compatibility

All-in-One Compatibility List						
	120mm	240mm	360mm	140mm	280mm	420mm
Top	-	-	-	-	-	-
Right Side	●	●	●	●	●	●
Left Side	●	●	●	-	-	-
Rear	-	-	-	-	-	-

