

Datasheet

- **Style: Simple**
- **Size: Mid Tower supports up to ATX MB**
- **Material: Steel & Tempered Glass**

Main Features

- **Connection** : Front I/O ports with 2 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Ventilation** : Pre-installed 4 x 120mm ARGB Lite fan
- **Supports** : Supports AIO cooling solutions





Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Specification

Model	View 380 XL TG ARGB	View 380 XL TG ARGB Snow	View 380 XL TG ARGB Bumblebee	View 380 XL TG ARGB Gravel Sand
P/N	CA-11E-00M1WN-00	CA-11E-00M6WN-00	CA-11E-00M4WN-00	CA-11E-00MGWN-00
Case Type	Mid Tower			
Chassis Dimension (H*W*D)	471 x 288 x 469 mm (18.54 x 11.34 x 18.46 inch)			
Panel	4mm Tempered Glass x 2			
Color	Black	White	Bumblebee	Gravel Sand
Material	SPCC			
Cooling System	Right(intake): 120 x 120 x 25 mm ARGB Lite Reverse fan (1000rpm, 21.9 dBA) x 3 Rear(exhaust): 120 x 120 x 25 mm ARGB Lite fan (1000rpm, 22.3 dBA) x 1			
Drive Bays	1 x 3.5", 2 x 2.5" or 3 x 2.5"			
Expansion Slots	8			
Motherboards	6.7" x 6.7" (Mini ITX), 9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)			
Hidden- Connector Motherboard	9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)			
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 2, HD Audio x 1			
PSU	Standard PS2 PSU (optional)			
Fan Support	Top: 3 x 120mm, 2 x 120mm, 1 x 120mm, 2 x 140mm, 1 x 140mm Right: 3 x 120mm, 2 x 120mm, 1 x 120mm Rear: 1 x 120mm Bottom: 3 x 120mm, 2 x 120mm, 1 x 120mm			
Radiator Support	Top: 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm Right: 1 x 360mm, 1 x 240mm, 1 x 120mm Rear: 1 x 120mm			
Clearance	CPU cooler max height: 160mm VGA max length: 420mm PSU max length: 180mm			

Packaging

Package Information	View 380 XL TG ARGB	View 380 XL TG ARGB Snow	View 380 XL TG ARGB Bumblebee	View 380 XL TG ARGB Gravel Sand
P/N	CA-11E-00M1WN-00	CA-11E-00M6WN-00	CA-11E-00M4WN-00	CA-11E-00MGWN-00
EAN Code	4711475649675	4711475649682	4711475649699	4711475649705
UPC Code	841163099681	841163099698	841163099704	841163099711
N.W	8.85 kg /19.51lbs.			
G.W	10.82 kg / 23.85 lbs.			
Carton Size (L x W x H)	547 x 372 x 558 mm / 21.54 x 14.65 x 21.97 inch			
Cuft	4.01			
Container	w/o pallet, w/ spare parts			
20'	240 pcs			
40'	512 pcs			
40' HQ	600 pcs			





Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Appearance – Black version



Angle view



Left Side view



Front view




Right Side view




Internal Structure



Rear view

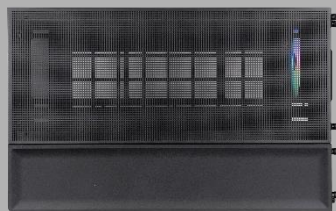

Top view

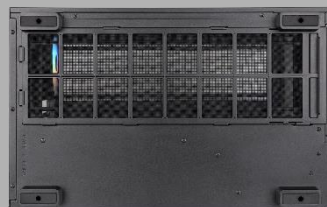

Bottom view



Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Appearance – Snow version




Angle view



Left Side view



Front view

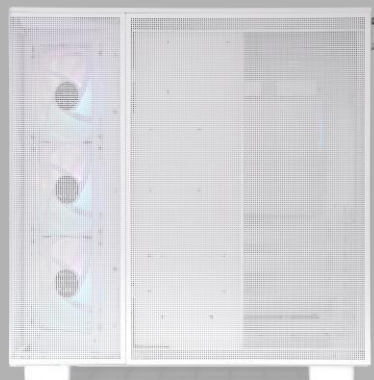


Right Side view



Internal Structure



Rear view

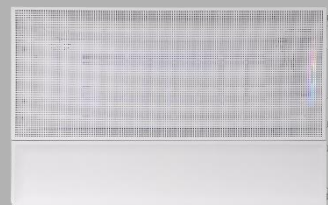

Top view



Bottom view



Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Appearance – Bumblebee version




Angle view



Left Side view



Front view

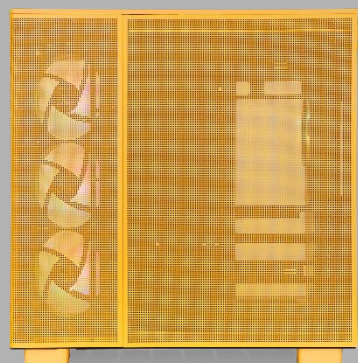


Right Side view



Internal Structure



Rear view

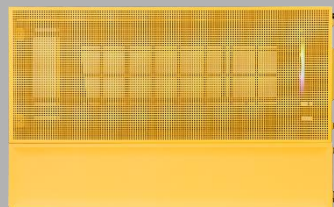

Top view



Bottom view



Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Appearance – Gravel Sand version



Angle view



Left Side view



Front view




Right Side view



Internal Structure



Rear view

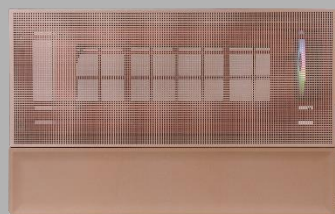

Top view



Bottom view



Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Clearance



Supports up to
10 x 120 mm fan



Supports up to **360 mm radiator on the
top and the right side**



Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Structure (External)



USB 3.2 (Gen 2) Type-C x 1

USB 3.0 x 2

HD Audio



4mm Tempered Glass
Window x 2



Bottom filter



Accessory Organizer

Structure (Internal)

3 x 2.5"



1 x 3.5"



Supports up to **3 x 2.5"** SSD and **1 x 3.5"** HDD



SSD & HDD Bracket

Structure (Internal)



Built-in **GPU Bracket** to hold the graphic card



Two-pieces-structure provides enough flexibility for various graphic card



Thermaltake View 380 XL TG ARGB Mid Tower Chassis

Pre-installed ARGB Lite Fans



Pre-installed one hydraulic bearing ARGB **Lite** fan and three ARGB **Lite Reverse** fans which can effectively lower the operation noise and enhance the thermal efficiency.



Black



Snow

SPEC for Case ARGB **Lite** fan

-Fan Speed: 1000 +/- 200 RPM

-Fan Airflow: 35.25 CFM

-Fan Air Pressure: 0.54 mm-H2O

-Fan Noise Level: 22.3 dBA

-Fan Bearing: Hydraulic bearing

SPEC for Case ARGB **Lite Reverse** fan

-Fan Speed: 1000 +/- 200 RPM

-Fan Airflow: 32.25 CFM


-Fan Air Pressure: 0.39 mm-H2O

-Fan Noise Level: 21.9 dBA

-Fan Bearing: Hydraulic bearing


Compatibility List

Fan Compatibility List			
	120mm	140mm	200mm
Top	3	2	-
(M/B Side)Right	3	-	-
Rear	1	-	-
Bottom	3	-	-

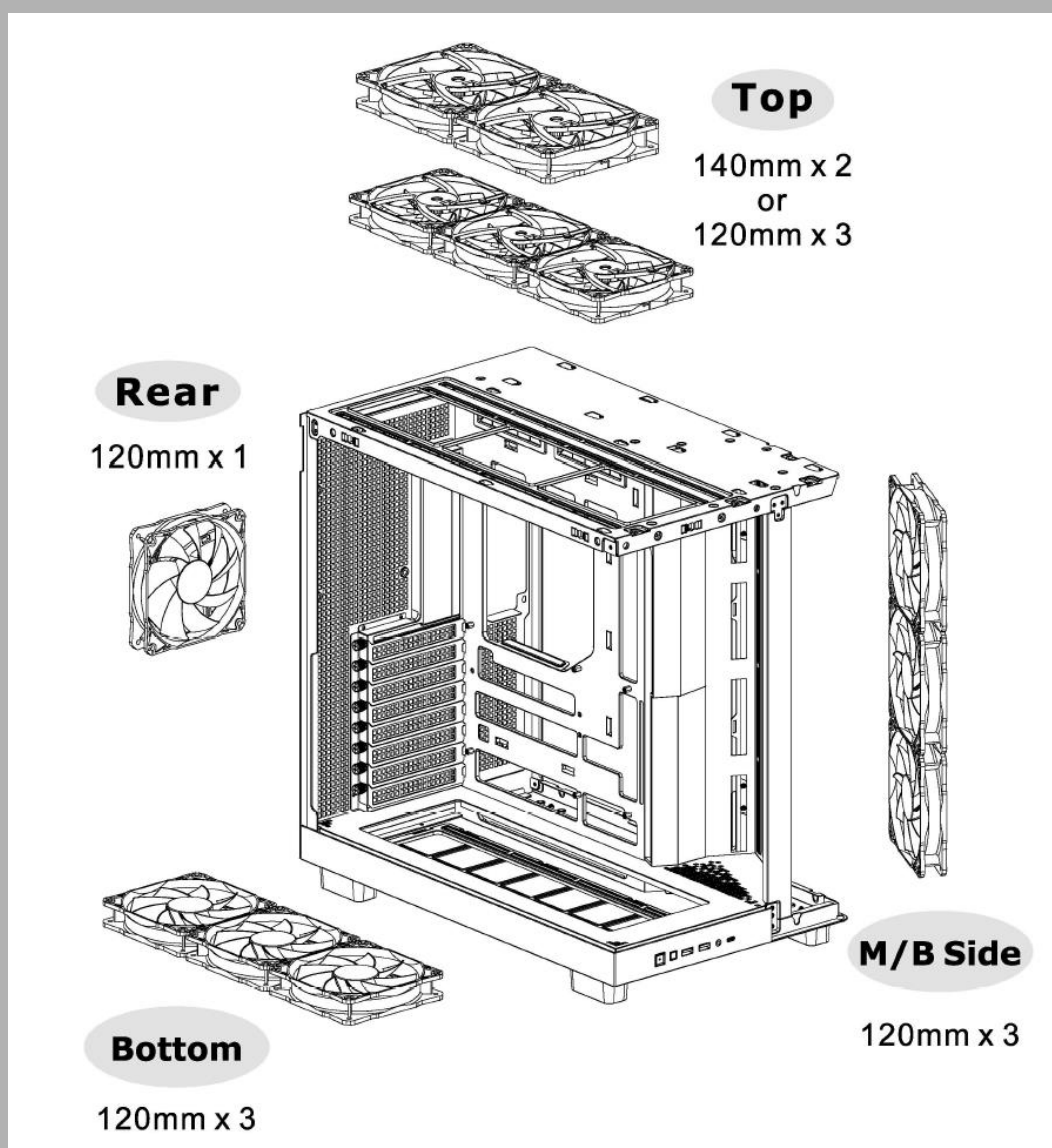

All-in-One Compatibility

All-in-One Compatibility List						
	120mm	240mm	360mm	140mm	280mm	420mm
Front	-	-	-	-	-	-
Top	●	●	●	●	●	-
Right	●	●	●	-	-	-
Rear	●	-	-	-	-	-
Bottom	-	-	-	-	-	-

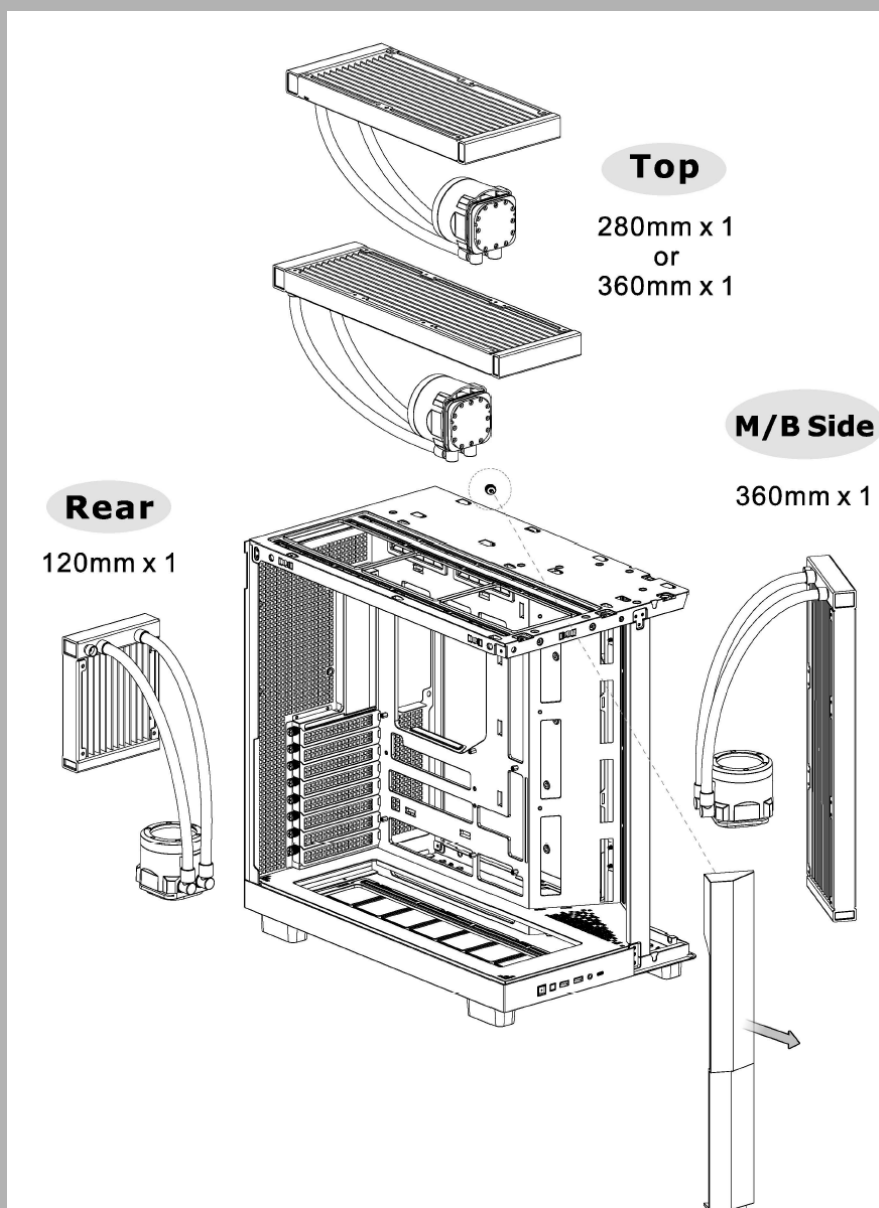

DIY Liquid Cooling Compatibility

DIY Liquid Cooling Compatibility						
	120mm	240mm	360mm	140mm	280mm	420mm
Front	-	-	-	-	-	-
Top	●	●	●	●	●	-
Right	●	●	●	-	-	-
Rear	●	-	-	-	-	-
Bottom	-	-	-	-	-	-

