

Pre-Datasheet

- **Style: Simple**
- **Size: Mid Tower case supports up to ATX MB**
- **Material: Steel & Tempered Glass**

Main Features

- **Connection :** Top I/O ports with 2 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Cooling Solution :** CT 120mm Fan x 2
- **Support:** 360mm AIO cooling solutions
- **Compatible Accessory:** 3.9" / 6" LCD Screen Kit

Specification

Model	View 390 Air	View 390 Air Snow	View 390 Air Future Dusk	View 390 Air Butter Caramel
P/N	CA-11F-00M1WN-00	CA-11F-00M6WN-00	CA-11F-00MNWN-00	CA-11F-00MMWN-00
Color	Black	White	Future Dusk	Butter Caramel
Case Type	Mid Tower			
Chassis Dimension (H*W*D)	503 x 287 x 485mm (19.80 x 11.30 x 19.1inch)			
Side Panel	4mm Tempered Glass x 1			
Material	SPCC			
Cooling System	Rear (exhaust): 120 x 120 x 25 mm CT120 fan (500~2000rpm, 25.8 dBA) x 2	Rear (exhaust): 120 x 120 x 25 mm CT120 white fan (500~2000rpm, 25.8 dBA) x 2	Rear (exhaust): 120 x 120 x 25 mm CT120 fan (500~2000rpm, 25.8 dBA) x 2	Rear (exhaust): 120 x 120 x 25 mm CT120 fan (500~2000rpm, 25.8 dBA) x 2
Drive Bays	2 x 3.5" , 1 x 2.5" or 3 x 2.5"			
Expansion Slots	7(Rotatable Patented Design)			
Motherboards	6.7" x 6.7" (Mini ITX), 9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)			
Hidden-Connector Motherboard	9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)			
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 2, HD Audio x 1			
PSU	Standard PS2 PSU (optional)			
Fan Support	Front: 3 x 120mm 2 x 140mm 2 x 200mm Right: 3 x 120mm Rear: 2 x 120mm Bottom: 3 x 120mm			
Radiator Support	Front Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm Right Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm			
Clearance	CPU cooler height limitation: 160mm VGA length limitation: 390mm with Radiator /420mm without Radiator PSU length limitation: 200mm (with 2.5" SSD) 260mm (without 2.5" SSD)			

Packaging


Package Information	View 390 Air	View 390 Air Snow	View 390 Air Future Dusk	View 390 Air Butter Caramel
P/N	CA-11F-00M1WN-00	CA-11F-00M6WN-00	CA-11F-00MNWN-00	CA-11F-00MMWN-00
EAN Code	4711475648845	4711658540010	4711658544391	4711658544407
UPC Code	841163098851	840480300012	840480304393	840480304409
N.W				
G.W				
Carton Size (L x W x H)	551 x 374 x 588 mm / 21.69 x 14.73 x 23.15 inch			
Cuft	4.28			
Container				
20'				
40'				
40' HQ				




Appearance – Black version




Angle view

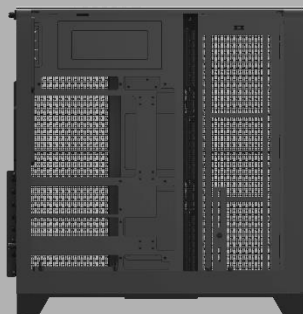


Left Side view

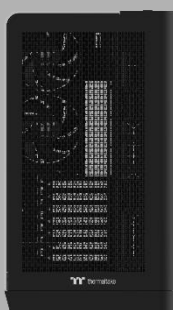


Front view

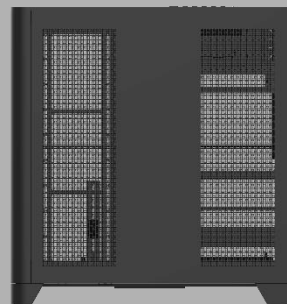


Right Side view

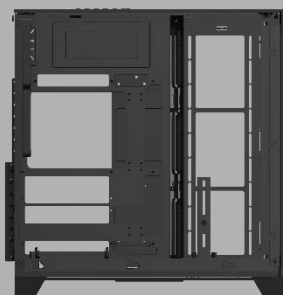

Internal Structure

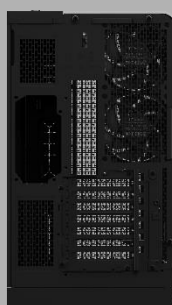

Rear view

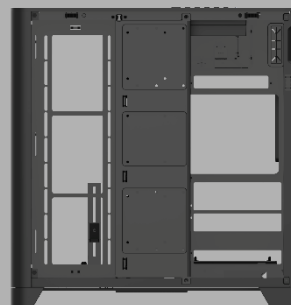

Internal Structure



Top view




Bottom view


Appearance – Snow version




Angle view

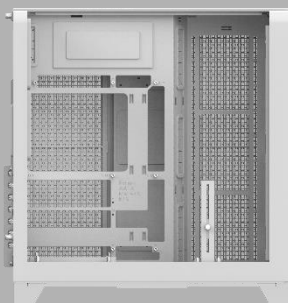


Left Side view

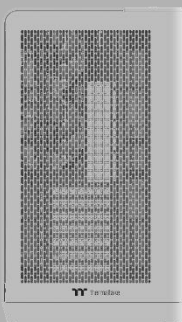


Front view

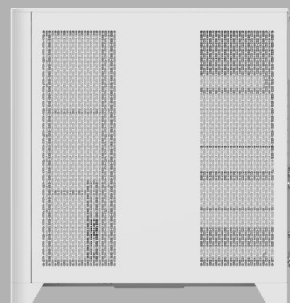

Right Side view

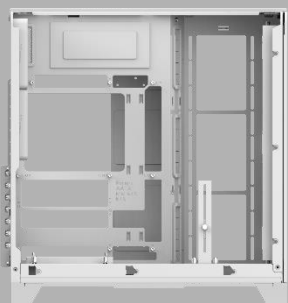

Internal Structure

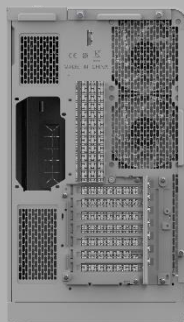

Rear view



Internal Structure



Top view




Bottom view

Appearance – Black version




Angle view

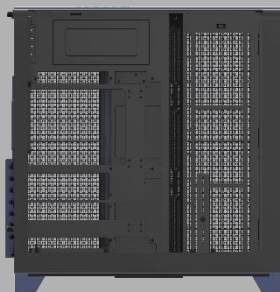


Left Side view




Front view

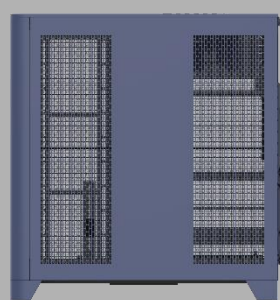


Right Side view

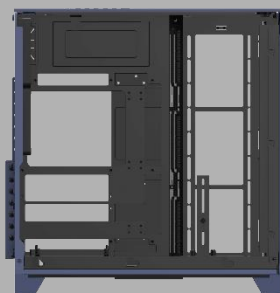

Internal Structure

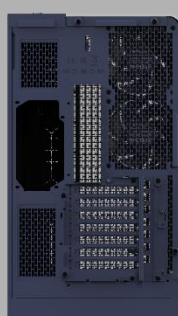

Rear view

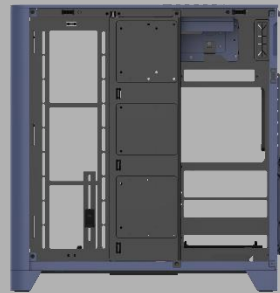

Internal Structure



Top view




Bottom view


Appearance – Snow version




Angle view

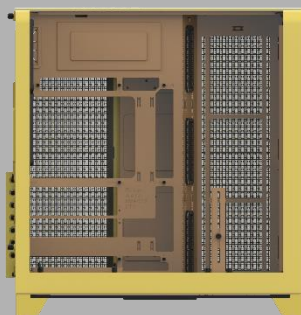


Left Side view

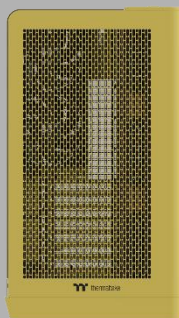


Front view

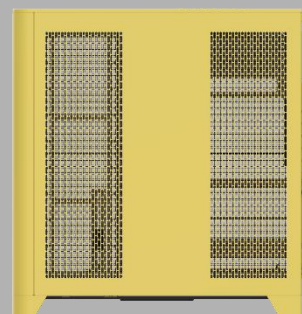


Right Side view

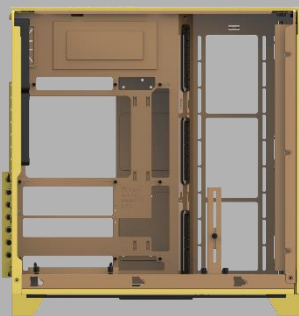

Internal Structure

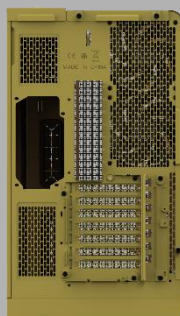

Rear view

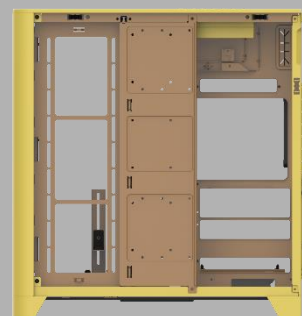

Internal Structure




Top view



Bottom view

Clearance

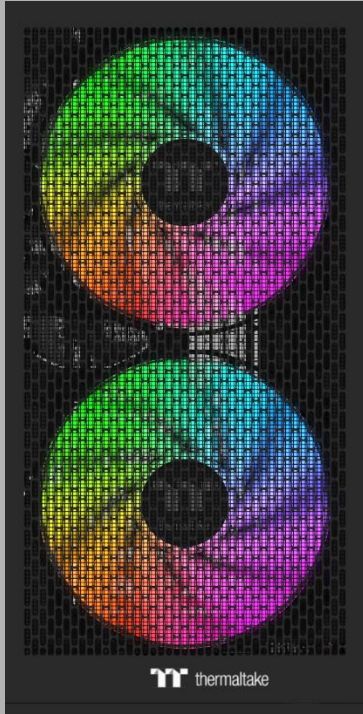

Maximum supports up
to 200mm fan x 2

Maximum AIO radiator
supports up to 360mm




Clearance



Seamless 90°
Curved TG Panel

Unique Design

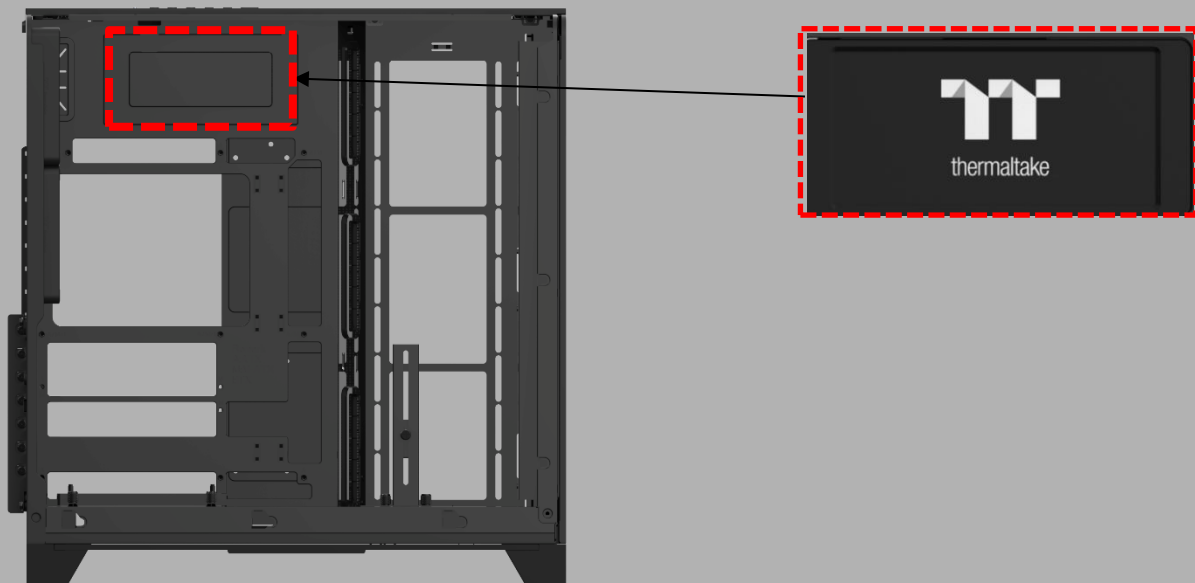

plastics panels for customized installation.



✕ 3.9inch, 6 inch LCD Screen Kit is not included



Structure (External)



USB 3.2 (Gen 2) Type-C x 1


USB 3.0 x 2

HD Audio

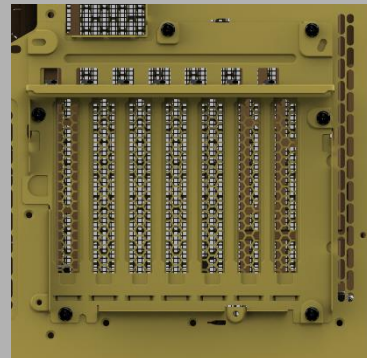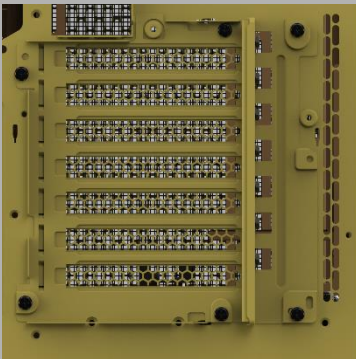


Rotational VGA bracket design

Structure (Internal)

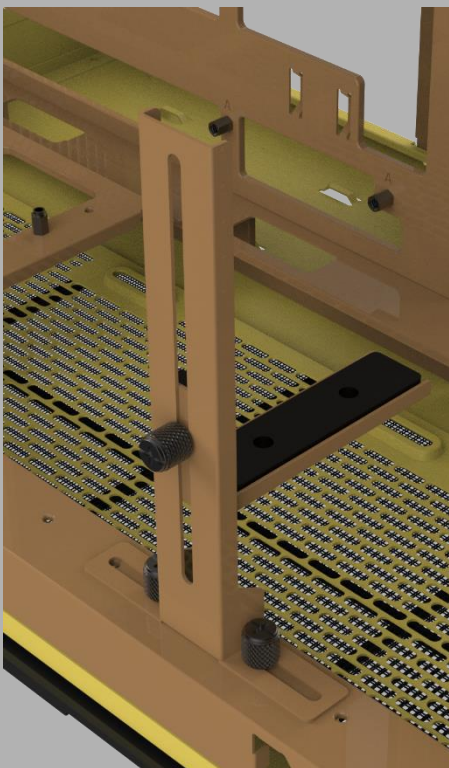


VGA Holder



HDD Back Cover

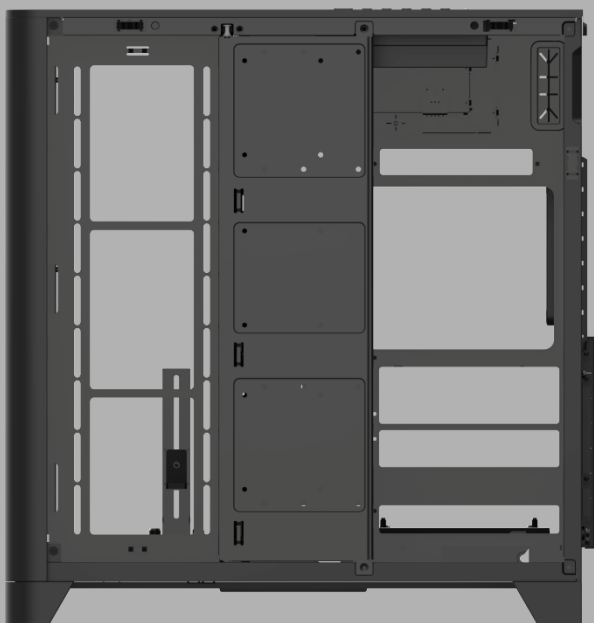


Structure (Internal)

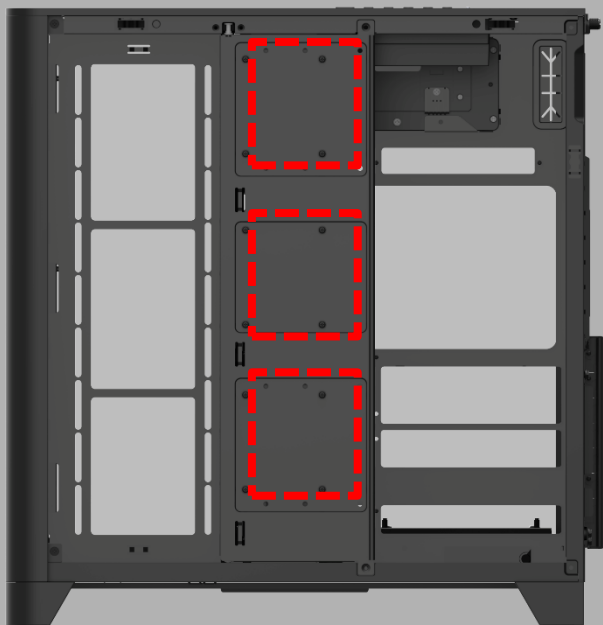

3 x 2.5"

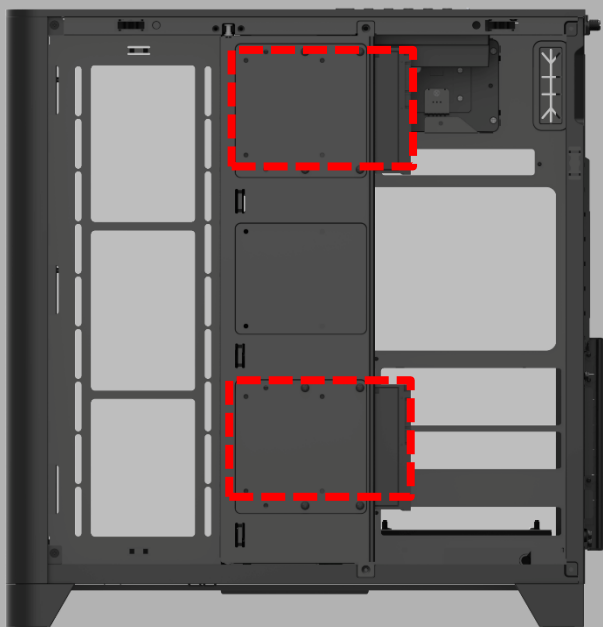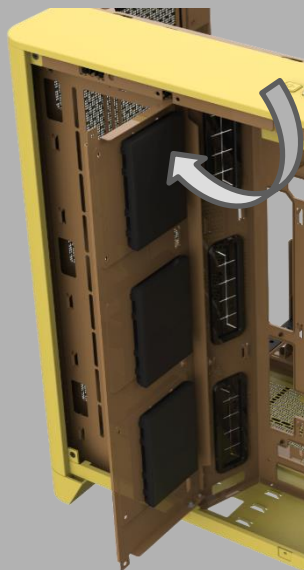

2 x 3.5"

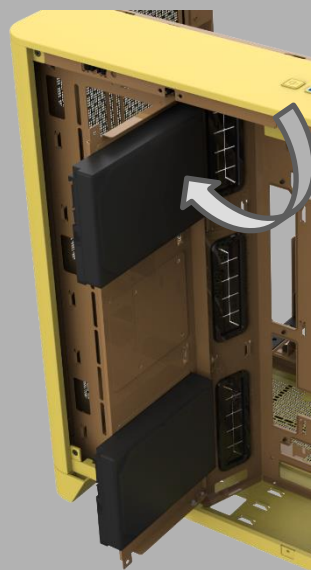

Pre-installed CT120 Fan



Pre-installed two hydraulic bearing CT120 fans which can effectively lower the operation noise and enhance the thermal efficiency.



Black Version




Snow Version



SPEC for Case CT120 fans

- Fan Speed: 500~2000 RPM
- Max. Fan Airflow: 57.05CFM
- Max. Fan Air Pressure: 2.23 mm-H2O
- Fan Noise Level: 25.8 dBA
- Fan Bearing: Hydraulic bearing

Structure (Internal)

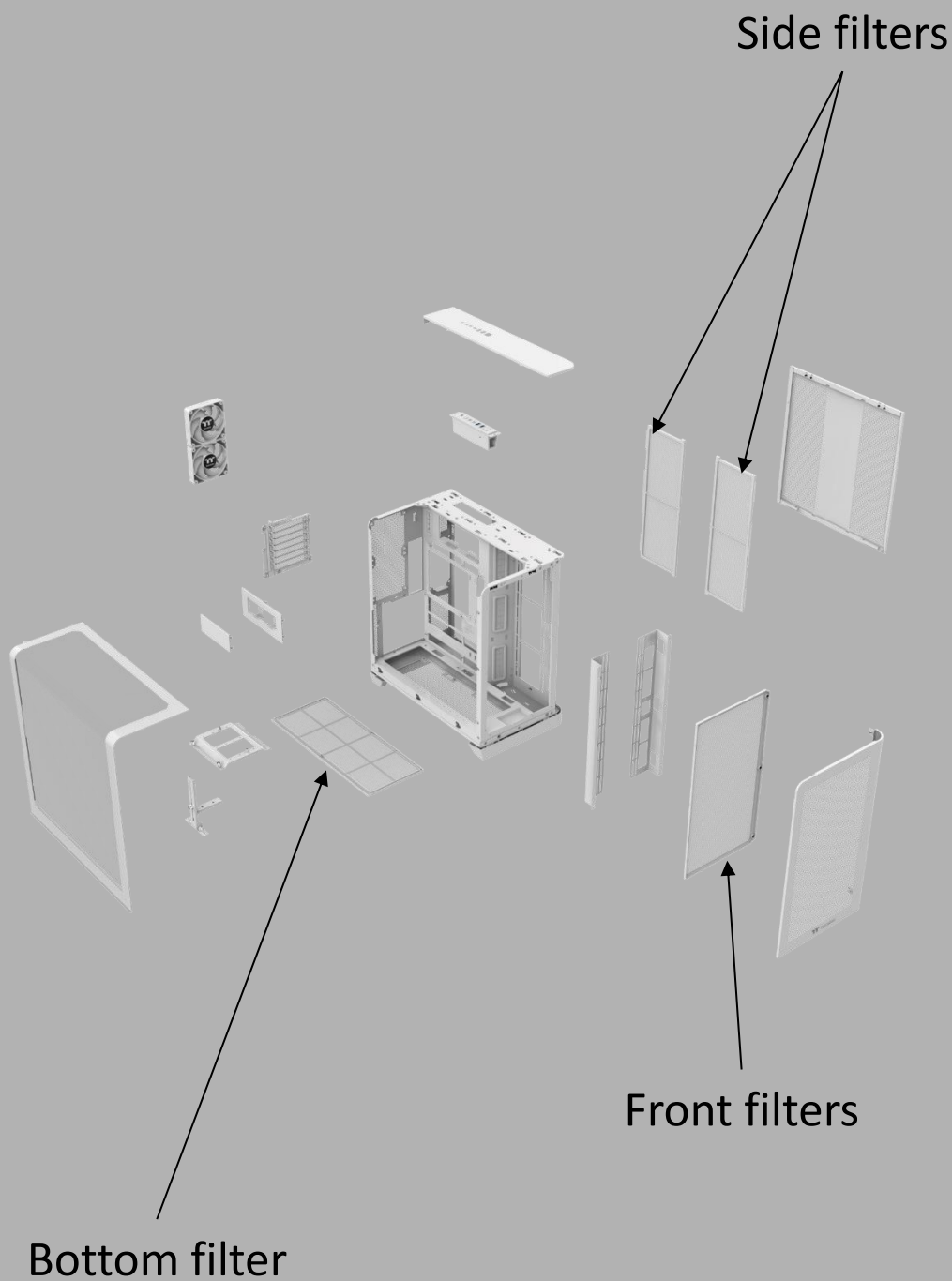


Exploded View

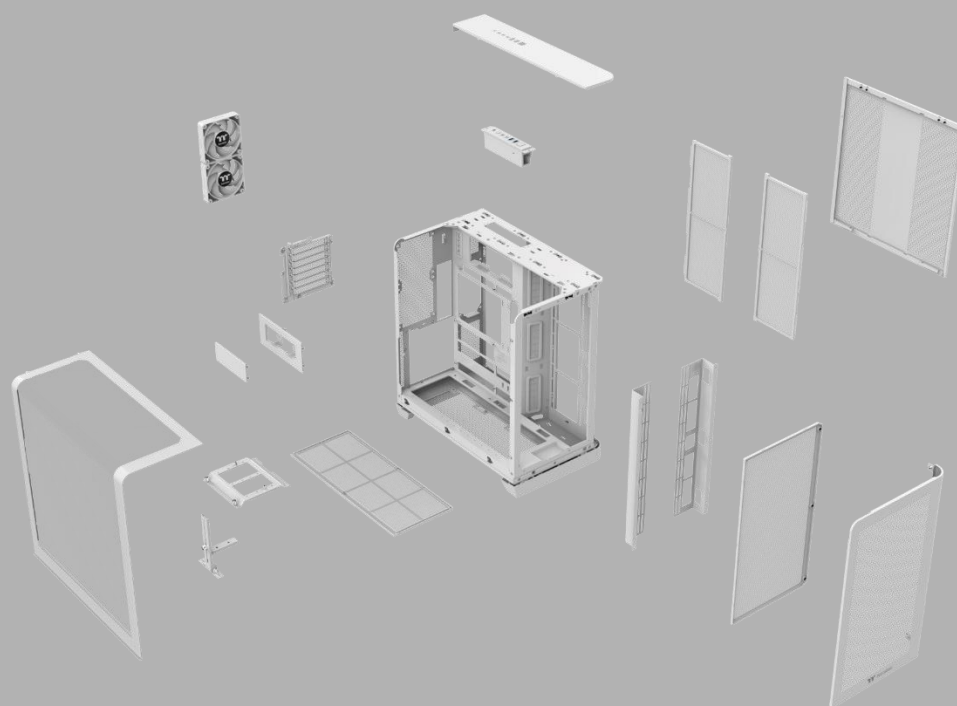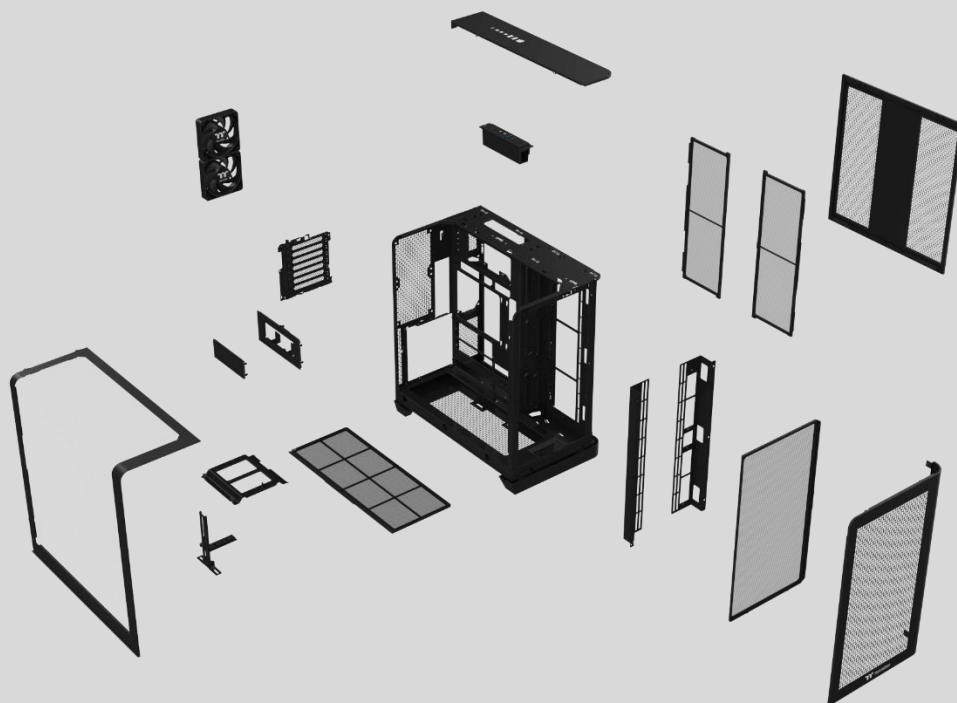




This exploded view diagram illustrates the components of the HP Z840 G2 workstation. The central component is the main chassis frame. Surrounding it are various accessories and internal parts, including:

- Top Panel:** A large, light-colored rectangular panel with a mesh grille.
- Front Panel:** A large, light-colored rectangular panel with a mesh grille.
- Drive Bays:** Several vertical and horizontal bays for storage drives, including a 3.5-inch bay and a 5.25-inch bay.
- Cooling Fans:** Two black fans, one for the front and one for the rear.
- Internal Components:** Various internal parts like the power supply, motherboard, and RAM modules.
- Accessories:** A mouse, a keyboard, and a docking station.

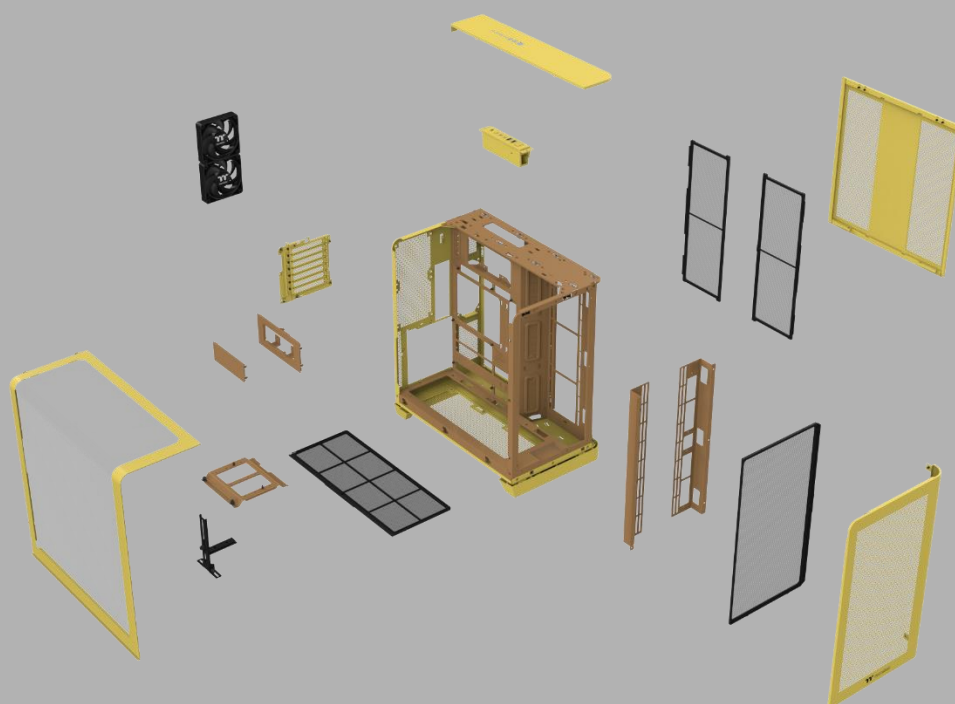

Compatibility List

Fan Compatibility List			
	120mm	140mm	200mm
Front	3	2	2
Right Side	3	-	-
Left Side	-	-	-
Rear	2	-	-
Bottom	3	-	-

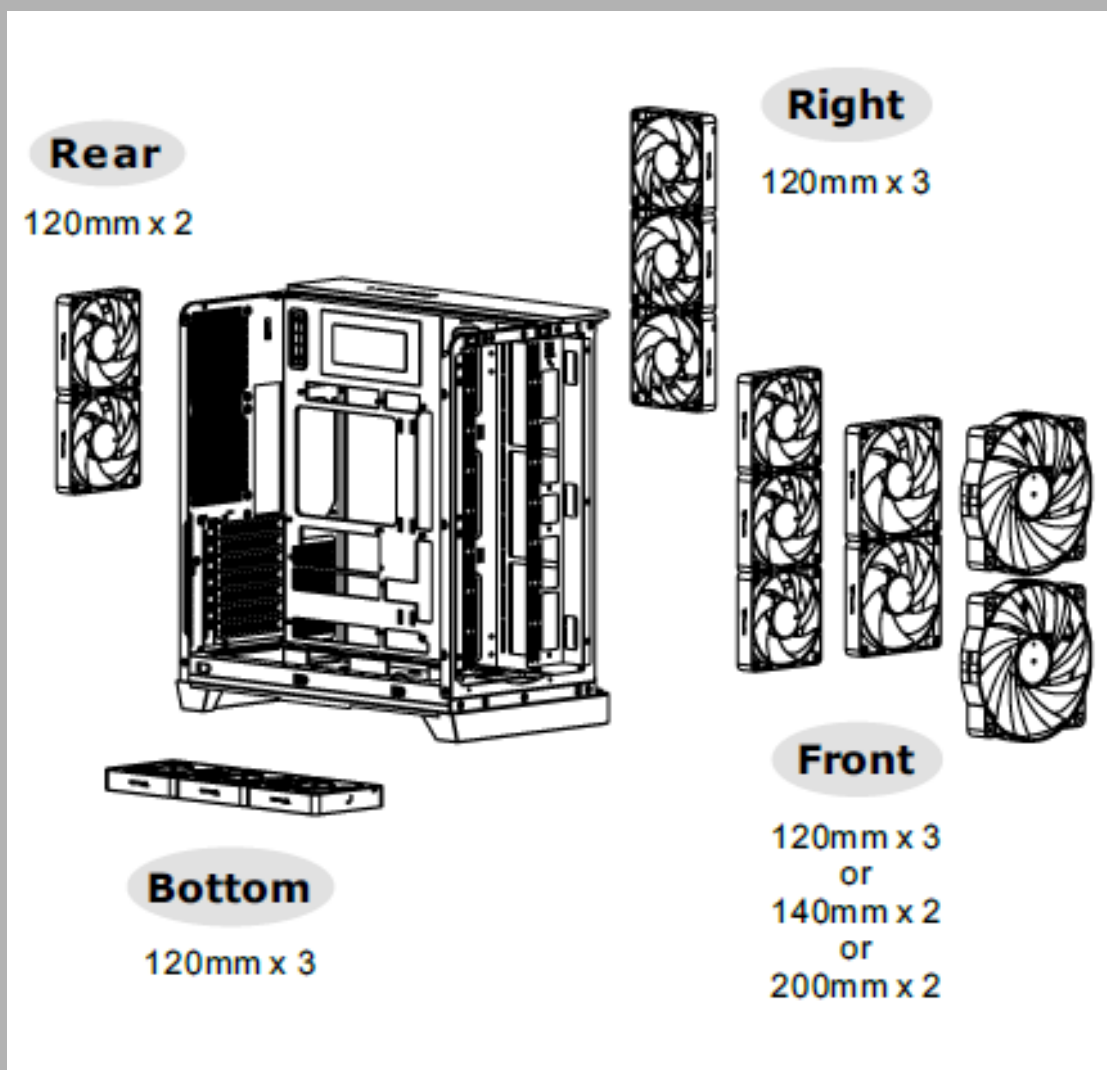

All-in-One Compatibility

All-in-One Compatibility List						
	120mm	240mm	360mm	140mm	280mm	420mm
Front	●	●	●	●	●	-
Right Side	●	●	●	-	-	-

