


Datasheet – TRU Components

Item no.: 3436424 – 33436429, 3758677 - 3758722



Rubber Buffer


- Type A

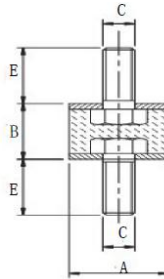

Item No.	A (mm)	B (mm)	C	E (mm)	Max. static load kgs	Hardness
3758683	15	25	M4	15	18	60 Shore A
3758684	25	30	M6	18	41	60 Shore A
3758685	30	40	M8	23	50	60 Shore A
3758686	40	40	M8	23	72	60 Shore A
3758687	50	40	M10	28	85	60 Shore A

Item No.	A (mm)	B (mm)	C	E (mm)	Max. static load kgs	Hardness
3758688	15	25	M4	15	25	75 Shore A
3758689	25	30	M6	18	48	75 Shore A
3758690	30	40	M8	23	60	75 Shore A
3758691	40	40	M8	23	80	75 Shore A
3758692	50	40	M10	28	93	75 Shore A

- Type B

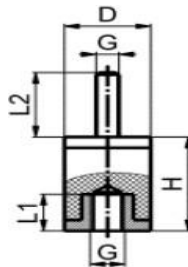

Item No.	D (mm)	H (mm)	G	L1 (mm)	L2 (mm)	Max. static load kgs	Hardness
3436424	15	25	M4	4	15	8	43 Shore A
3436425	25	30	M6	6	18	20	43 Shore A
3436426	30	40	M8	9.5	21	31	43 Shore A
3436427	40	40	M8	8	23	60	43 Shore A
3436428	50	40	M10	10	28	86	43 Shore A
3436429	50	50	M10	10	28	95	43 Shore A

Item No.	D (mm)	H (mm)	G	L1 (mm)	L2 (mm)	Max. static load kgs	Hardness
3758677	15	25	M4	4	15	18	65 Shore A
3758678	25	30	M6	6	18	41	65 Shore A
3758679	30	40	M8	9.5	21	50	65 Shore A
3758680	40	40	M8	8	23	72	65 Shore A
3758681	50	40	M10	10	28	85	65 Shore A
3758682	50	50	M10	10	28	85	65 Shore A

Datasheet – TRU Components

Item no.: 3436424 – 33436429, 3758677 - 3758722



Rubber Buffer

- Type C



Item No.	A (mm)	B (mm)	C	F (mm)	Max. static load kgs	Hardness
3758693	15	25	M4	4	10	43 Shore A
3758694	25	30	M6	8	21	43 Shore A
3758695	30	40	M8	10	28	43 Shore A
3758696	40	40	M8	8	38	43 Shore A
3758697	50	40	M10	10	45	43 Shore A

Item No.	A (mm)	B (mm)	C	F (mm)	Max. static load kgs	Hardness
3758698	15	25	M4	4	18	65 Shore A
3758699	25	30	M6	8	41	65 Shore A
3758700	30	40	M8	10	50	65 Shore A
3758701	40	40	M8	8	72	65 Shore A
3758702	50	40	M10	10	85	65 Shore A

- Type D



Item No.	A (mm)	B (mm)	C	E (mm)	Max. static load kgs	Hardness
3758703	15	25	M4	15	13	50 Shore A
3758704	25	30	M6	18	26	50 Shore A
3758705	30	40	M8	20	35	50 Shore A
3758706	40	40	M8	23	44	50 Shore A
3758707	50	40	M10	27	57	50 Shore A

Item No.	A (mm)	B (mm)	C	E (mm)	Max. static load kgs	Hardness
3758708	15	25	M4	15	18	60 Shore A
3758709	25	30	M6	18	41	60 Shore A
3758710	30	40	M8	20	50	60 Shore A
3758711	40	40	M8	23	72	60 Shore A
3758712	50	40	M10	27	85	60 Shore A

Datasheet – TRU Components

Item no.: 3436424 – 33436429, 3758677 - 3758722

Rubber Buffer

- Type E



Item No.	A (mm)	B (mm)	C	F (mm)	Max. static load kgs	Hardness
3758713	15	25	M4	4	19	50 Shore A
3758714	25	30	M6	8	26	50 Shore A
3758715	30	40	M8	10	35	50 Shore A
3758716	40	40	M8	8	44	50 Shore A
3758717	50	40	M10	10	57	50 Shore A

Item No.	A (mm)	B (mm)	C	F (mm)	Max. static load kgs	Hardness
3758718	15	25	M4	4	18	60 Shore A
3758719	25	30	M6	8	41	60 Shore A
3758720	30	40	M8	10	50	60 Shore A
3758721	40	40	M8	8	72	60 Shore A
3758722	50	40	M10	10	85	60 Shore A