


UX150-L

ARGB Lighting CPU Cooler

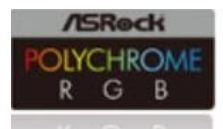

***Requires Motherboard Sync for ARGB lighting effect**

UX150-L


Features

ARGB Lighting CPU Cooler

- 130mm fan in 7-bladed design with LED lighting
- Supports up to 130W
- Features a circular infinity mirror at the fan's center
- 16 addressable RGB LED lighting on the outer ring
- Supports Motherboard sync software
- Supports the new Intel Socket LGA 1851

***Requires Motherboard Sync for ARGB lighting effect**

Dimension

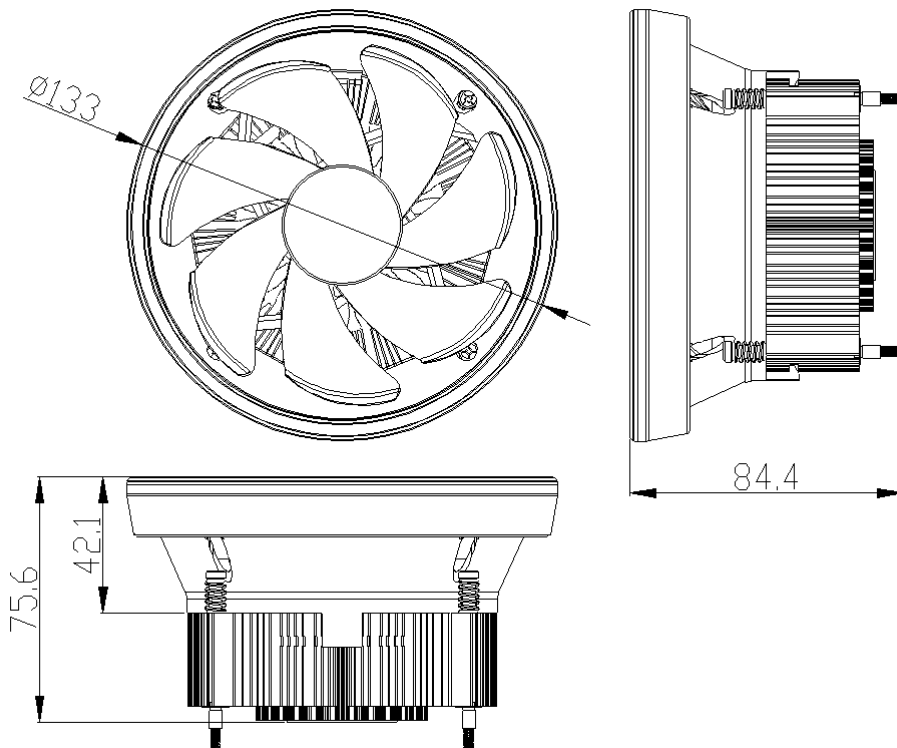



UX 150-L

ARGB Lighting CPU Cooler



Specification

Unit :mm

P/N	CL-P146-CA13SW-A
Compatibility (CPU Socket)	Intel LGA 1851/1700/1200/1156/1155/1151/1150
Dimension	133 x 133 x 75.6 mm(L x W x H)
Heatsink Material	Aluminum Fins
Fan Dimension	130 x 130 x 42 mm(L x W x H)
Fan Quantity	1pcs
Fan Speed	PWM 500~2400 RPM
Rated Voltage	12V & 5v
Start Voltage	7.0 V
Rated Current	0.36 A & 0.78 A
Power Input	4.32 W & 3.9 W
Air Flow	59.2 CFM
Air Pressure	2.9 mm-H ₂ O
Acoustical Noise.	35 dBA
Life Time	40,000 hours
Fan Pin Connect	5V RGB header 2510 - 3Pin
Cooling Power	130 W

***Requires Motherboard Sync for ARGB lighting effect**

Thermaltake Air Cooler UX150

Pictures



Top view



Bottom view



Side view



**Support Intel
1851/1700/1200**

Sync 5V ARGB

Support ASUS, MSI, GIGABYTE and ASROCK 5V RGB motherboard Sync.

***Caution: the motherboard signal connector only supports 5V header.**



Aura Addressable Header



JRAINBOW Header




Addressable RGB LED Header



Digital Pin Header


Limited height DRAM

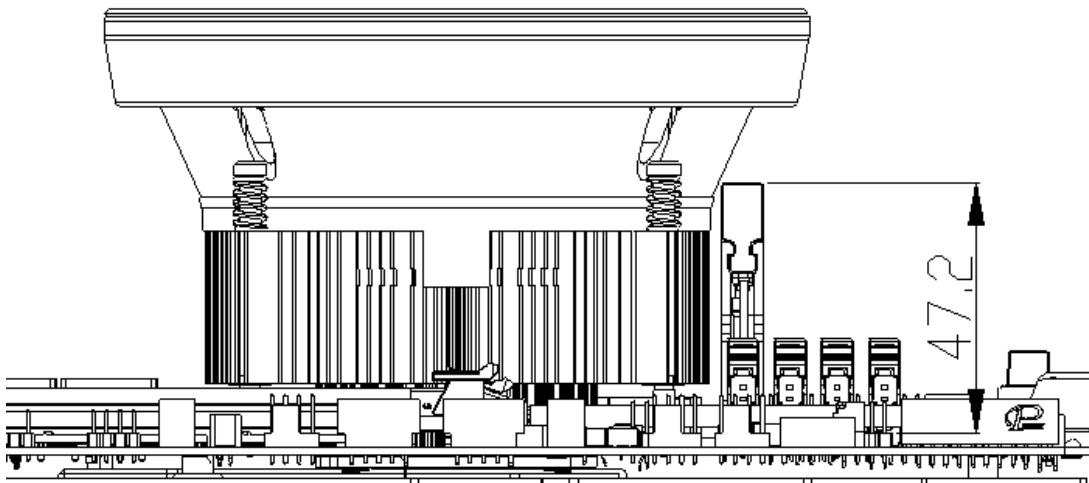

***Caution : Only support shorter than 48.0 mm DRAM**

UX150-L

ARGB Lighting CPU Cooler

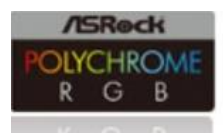

***Requires Motherboard Sync for ARGB lighting effect**