

MAGFloee 360 & 420 Ultra ARGB CPU AIO Liquid Cooler

P/N: CL-W432-PL12SW-A CL-W433-PL12SW-A

CL-W451-PL14SW-A CL-W452-PL14SW-A

MAGFloee 360 & 420 Ultra **ARGB** CPU AIO Liquid Cooler *Release the full CPU Horsepower*



thermaltake

**Requires motherboard sync for ARGB lighting effect*

MAGFloe 360 Ultra ARGB CPU AIO Liquid Cooler

•Specification

MAGFloe 360 Series

Product	P/N	CL-W432-PL12SW-A (Black) CL-W433-PL12SW-A (Snow Edition)
Compatibility	CPU Socket	Intel LGA 2066/2011-3/2011/1851/1700/ 1200/1156/1155/1151/1150 AMD AM5/AM4/AM3+/AM3/AM2+/AM2/FM2/FM1
Water Block	Material	Copper
Pump	Motor Speed	PWM 1500~3300 RPM
	Rated Voltage	12V
	Rated Current	0.43A
	Power Input	5.16W
CPU Display	Rated Voltage	5V
	Rated Current	0.26A
	Power Input	1.3W
	Display Type	3.95." TFT-LCD
	Display Resolution	480x480 (RGB) px
Display Support	Interface	Micro USB to USB (9PIN)
	System Compatibility	Windows 10 / 11
Fan	Dimension	120 x 120 x 25 mm
	Fan Speed	PWM 500~2000 R.P.M
	Rated Voltage	12V/5V
	Rated Current	0.27 A & 0.72 A (one fan)
	Power Input	3.24 W & 3.6 W (one fan)
	Air Flow.	Standard Fan Blade : 57.11 CFM (one fan) Reverse Fan Blade : 56.26 CFM (one fan)
	Static Pressure.	Standard Fan Blade : 2.39 mm-H2O (one fan) Reverse Fan Blade : 2.02 mm-H2O (one fan)
	Noise Level.	Standard Fan Blade : 30.6 dB-A (one fan) Reverse Fan Blade : 32.5 dB-A (one fan)
Radiator	Dimension	396 x 120 x 27 mm
	Material	Aluminum
Tube	Length	460mm
	Material	Rubber

***Requires motherboard sync for ARGB lighting effect**

MAGFloer 420 Ultra ARGB CPU AIO Liquid Cooler

•Specification

MAGFloer 420 Series

Product	P/N	CL-W451-PL14SW-A (Black) CL-W452-PL14SW-A (Snow Edition)
Compatibility	CPU Socket	Intel LGA 2066/2011-3/2011/1851/1700 1200/1156/1155/1151/1150 AMD AM5/AM4/AM3+/AM3/AM2+/AM2/FM2/FM1
Water Block	Material	Copper
Pump	Motor Speed	PWM 1500~3300 RPM
	Rated Voltage	12V
	Rated Current	0.43A
	Power Input	5.16W
CPU Display	Rated Voltage	5V
	Rated Current	0.26A
	Power Input	1.3W
	Display Type	3.95." TFT-LCD
	Display Resolution	480x480 (RGB) px
Display Support	Interface	Micro USB to USB (9PIN)
	System Compatibility	Windows 10 / 11
Fan	Dimension	140 x 140 x 25 mm
	Fan Speed	PWM 500~2000 R.P.M
	Rated Voltage	12V/5V
	Rated Current	0.32A & 0.72A (one fan)
	Power Input	3.84W & 3.6W (one fan)
	Air Flow.	Standard Fan Blade : 81.6 CFM (one fan) Reverse Fan Blade : 79.3 CFM (one fan)
	Static Pressure.	Standard Fan Blade : 3.17 mm-H2O (one fan) Reverse Fan Blade : 2.73 mm-H2O (one fan)
	Noise Level.	Standard Fan Blade : 34.5 dB-A (one fan) Reverse Fan Blade : 38.8 dB-A (one fan)
Radiator	Dimension	456 x 139 x 27 mm
	Material	Aluminum
Tube	Length	460mm
	Material	Rubber

*Requires motherboard sync for ARGB lighting effect

MAGFloe 360 & 420 Ultra ARGB CPU AIO Liquid Cooler

• Detailed Features :

- Large 3.95" Square LCD Display
- First AIO with Swappable Fan Blades
- SWAFAN + MAGForce 2.0 Quick Connection Design
- High-Efficiency Pump & Powerful Cooling Performance
- Supports TT RGB Plus Software and Motherboard Sync Software

• Appearance



3.95" TFT LCD
Monitor Water Block Design

Built-in 3.95" LCD display



Temperature



Weather



MP4



GIF File


MAGFloe 360 & 420 Ultra ARGB CPU AIO Liquid Cooler

• Appearance

Black



High Performance
Water Block

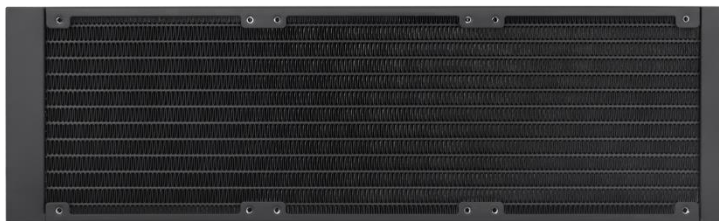

High Efficiency Radiator




MAGForce 2.0 Cable




Powerful Cooling Fan

• Airflow Direstion

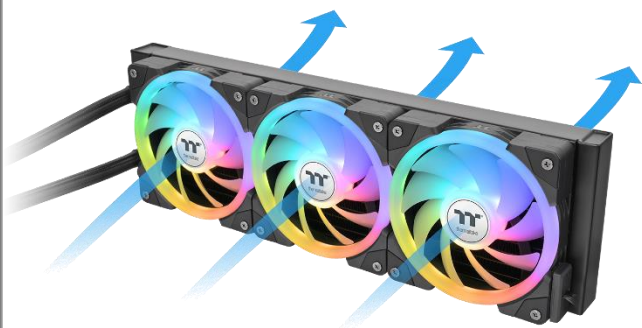

Standard Fan Blade
Air Exhaust

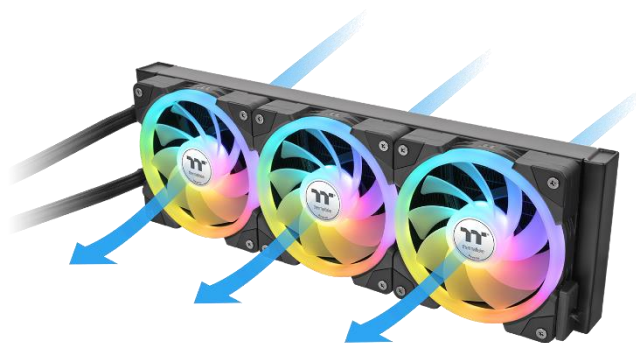


Reverse Fan Blade
Air Intake


MAGFloer 360 & 420 Ultra ARGB CPU AIO Liquid Cooler

• Appearance

Snow Edition

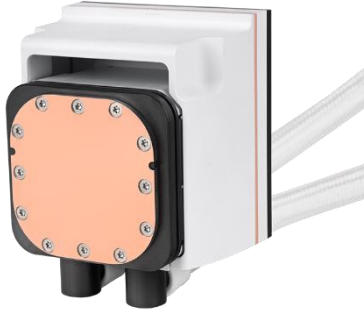

High Performance
Water Block

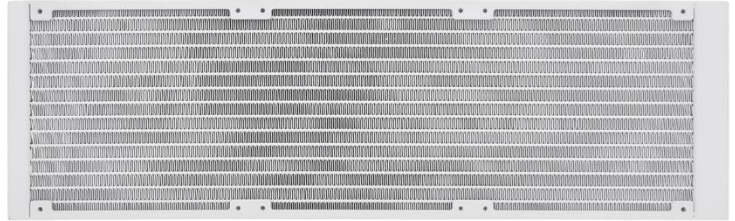

High Efficiency Radiator




MAGForce 2.0 Cable



Powerful Cooling Fan

• Airflow Direstion

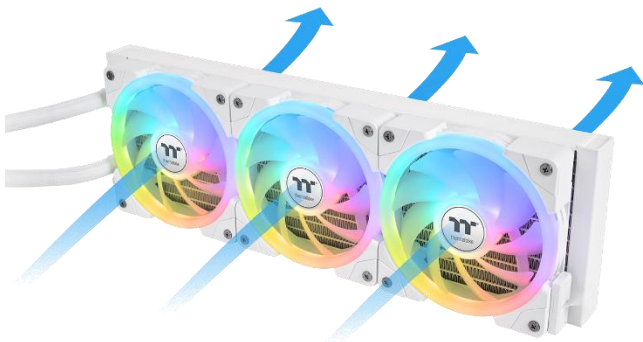

Standard Fan Blade
Air Exhaust




Reverse Fan Blade
Air Intake

MAGFloe 360 & 420 Ultra ARGB CPU AIO Liquid Cooler

• Appearance

Black

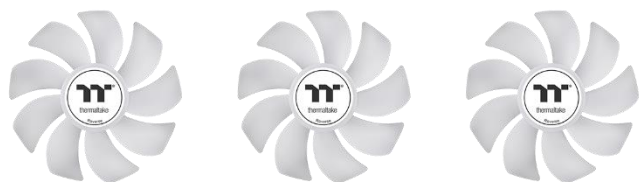

SWAFAN EX ARGB Sync

MAGForce 2.0 Connection



**Universal Socket
Compatible**

Support LGA1851





Application

MAGFloe 360 & 420 Ultra ARGB CPU AIO Liquid Cooler

• Appearance

Snow Edition

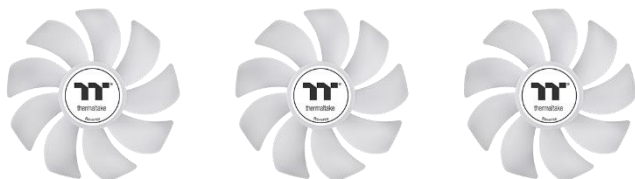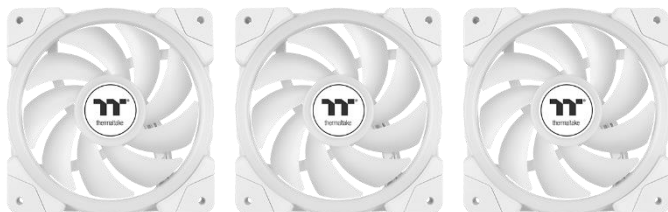

SWAFAN EX ARGB Sync

MAGForce 2.0 Connection

Universal Socket Compatible

Support LGA1851



Application

MAGFloee 360 & 420 Ultra ARGB CPU AIO Liquid Cooler

P/N: CL-W432-PL12SW-A CL-W433-PL12SW-A

CL-W451-PL14SW-A CL-W452-PL14SW-A

MAGFloee 360 & 420 Ultra **ARGB** CPU AIO Liquid Cooler

Release the full CPU Horsepower



thermaltake

*Requires motherboard sync for ARGB lighting effect