


DATASHEET

M8 60 V socket, straight, 3-pole, IP67

Item No. 3438016

Overview

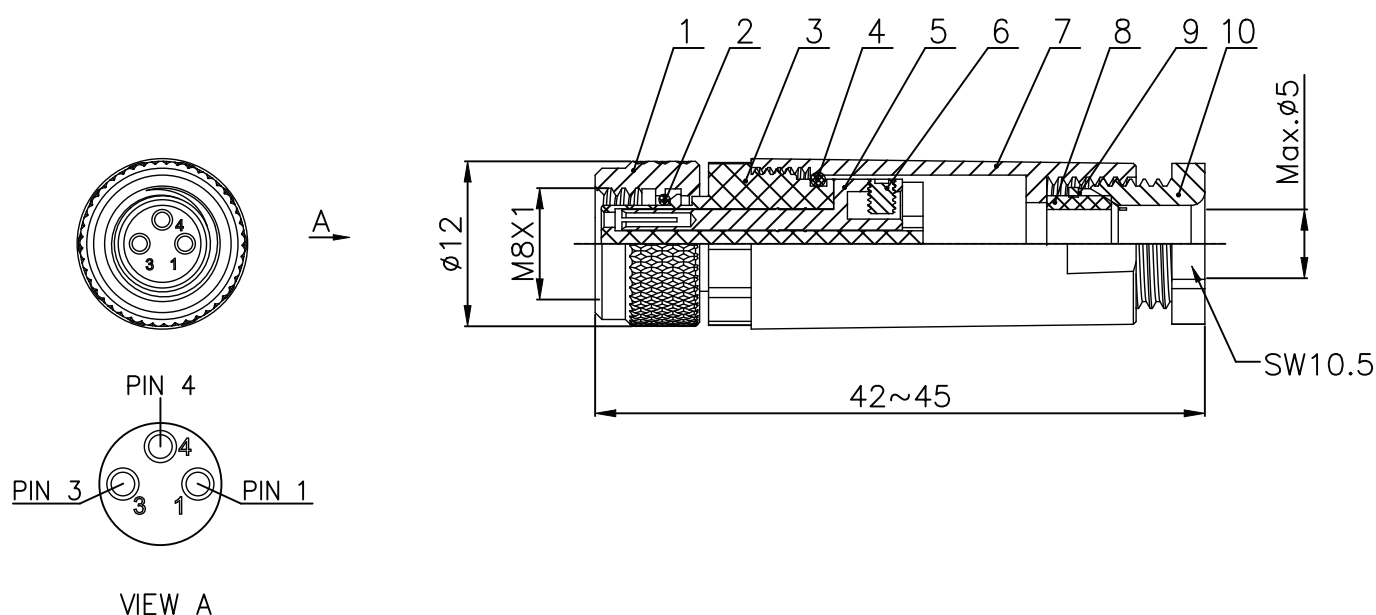

- | | | | |
|---|--|----|--|
| 1 | M8 Assembled coupling nuts | 6 | Wire locking screw |
| 2 | Nitrile butadiene rubber $\phi 7 \times \phi 5.4 \times 0.8$ black | 7 | M8 Straight body plastic case |
| 3 | M8 Female Insulator 3 core A code ,black | 8 | Waterproof rubber plug Silicone Rubber black |
| 4 | Nitrile butadiene rubber $\phi 10 \times \phi 8 \times 1$ black | 9 | Tail paw PA66 black |
| 5 | M8 Female contact pin Gold Plated OD:1.0 | 10 | Lock cable nut, plastic case |

Technical specifications:		Materials:	
Coupling:	Threaded coupling	Shell material:	Nylon black
Termination:	Screw locking	Contact material:	Copper gold plated
Coding:	A	Insert material:	PA+GF UL94 black
Pollution degree:	3	Sealing:	NBR black
Temperature range:	-40 to +80°C		
Degree of protection:	IP67		
Mating cycles:	≥500		
Rated voltage:	60V AC/DC		
Rated current:	3A		
Contact resistance:	≤5 mΩ		
Insulation resistance:	≥100 MΩ		

Dimensions in mm