


Big Digit Hygro-Thermometer

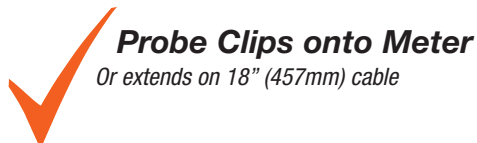

Probe Clips onto Meter

Or extends on 18" (457mm) cable

Features:

- Max/Min with reset function
- Rear calibration adjustment pot
- Humidity: 10 to 99% RH
- Temperature: 14 to 140°F (-10 to 60°C)
- Optional RH calibration bottles
- Accuracy: $\pm 4\%$ RH; $\pm 1^\circ\text{C}/1.8^\circ\text{F}$
- Dimensions: 4.3 x 3.9 x 0.78" (109 x 99 x 20mm)
- Weight: 6oz (169g)
- Complete with built-in stand, mounting bracket, sensor, and 1 AAA battery; optional calibration salt bottles



RH300-CAL Optional calibration salt bottles

Ordering Information:

445715 Big Digit Remote Probe Hygro-Thermometer
445715-NIST 445715 with Calibration Traceable to NIST.
RH300-CAL Optional 33% and 75% RH calibration standards