

29421199	DATA SHEET
Valid from: 24.05.2018	GOF Adapter Duplex ST-SC Multimode BE

Description

- GOF Optical fiber adapter ST-Duplex on SC-Duplex
- Singlemode- and multimode-type



General characteristics

Type of coupling	ST-Duplex (ST-D) SC-Duplex (SC-D)
Flange	Yes
Attenuation	< 0.2 dB
Temperature range	-40 °C to +85 °C (-40 °F to 185 °F) (Operation)


Variation

Article	Description	For fiber-type
29421199	GOF Adapter Duplex ST-SC Multimode BE	Multimode (MM)
29421999	GOF Adapter Duplex ST-SC Singlemode BL	Singlemode (SM)

Mechanical properties

Flame retardant acc. to UL 94	V-0
Housing, material	C3604
Guide sleeve, material	Zirconia
Mating cycles (min.)	1000

Technical drawing

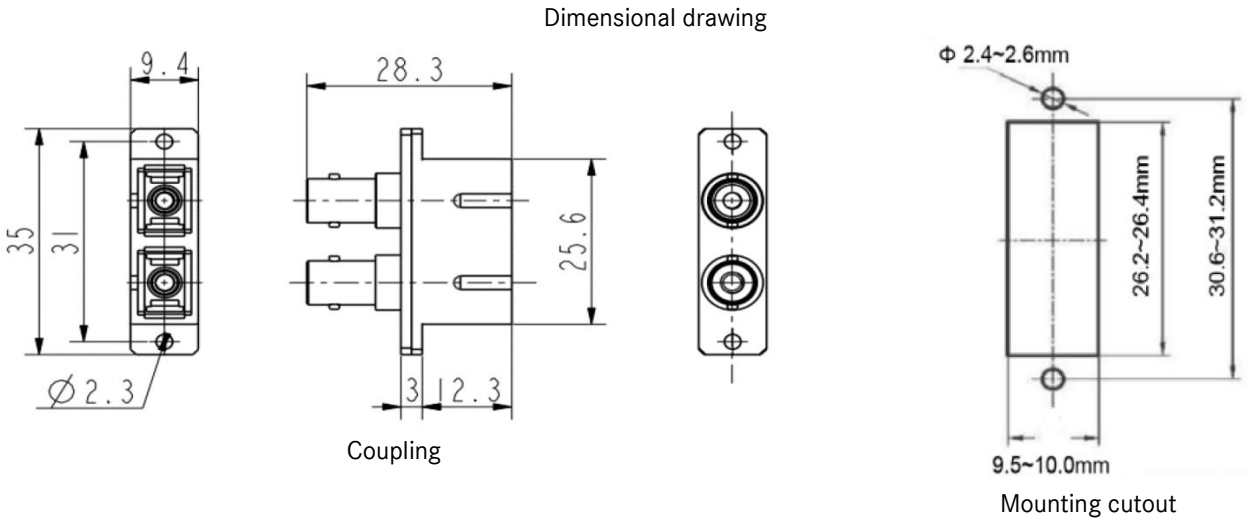

29421199	DATA SHEET
Valid from: 24.05.2018	GOF Adapter Duplex ST-SC Multimode BE

Standard

Fibre optic connector interfaces – Part 4: Type SC

IEC 61754-4

Fibre optic connector interfaces – Part 2: Type BFOC/2,5

IEC 61754-2

Application range

Office, Data centers, Industry

Note

Photographs are not true to scale and do not represent detailed images of the respective products.