

29130198	DATA SHEET
Valid from: 27.09.2018	GOF Connector LC Multimode BE /50PC

Description

- GOF Optical fiber Connector LC-Simplex
- Suitable for multimode optical fibers
- Ideal for assembling



General characteristics

Connector, Type	LC-Simplex (LC-S)
Connector, colour	Beige
Suitable optical fibers	Multimode (MM)
Suitable core-Ø (max.)	2.8 mm
Temperature range	-40 °C to +80 °C (-40 °F to +176 °F) (Operation) -40 °C to +85 °C (-40 °F to +185 °F) (Storage)


Variation

Article	Description	Color of bend-protection	Packing unit [PCS]
29130198	GOF Connector LC Multimode BE /50PC	Red (50%), black (50%)	50
29130199	GOF Connector LC Multimode BE /4PC	Red (50%), black (50%)	4
29130197	GOF Stecker LC Multimode BE-BK /50ST	Black (100%)	50

Mechanical properties

Flame retardant acc. to UL 94	V-0
Housing, material	PEI
Ferrule, material	Zirconia
Ferrule-Ø	1.25 mm
Tensile strength after assembly	70 N

Technical drawing

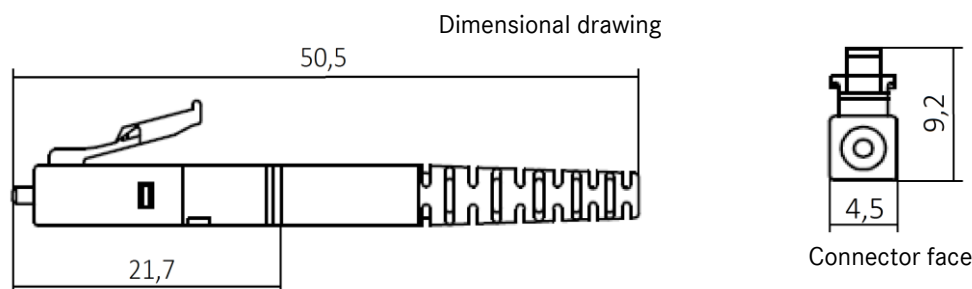

Standards / Approvals

Fibre optic connector interfaces – Part 20: Type LC

IEC 61754-20

Application range

Office, Data centers, Industry

Note

Photographs are not true to scale and do not represent detailed images of the respective products.