

29120198	DATA SHEET
Valid from: 24.05.2018	GOF Connector ST Multimode /50PC

Description

- GOF Optical fiber Connector ST-Simplex
- Suitable for multimode optical fibers
- Ideal for assembling



General characteristics

Connector, Type	ST-Simplex (ST-S)
Suitable optical fibers	Multimode (MM)
Suitable core-Ø (max.)	2.8 mm
Temperature range	-40 °C to +80 °C (-40 °F to +176 °F) (Operation) -40 °C to +85 °C (-40 °F to +185 °F) (Storage)

Variation


Article	Description	Packing unit [PCS]
29120198	GOF Connector ST Multimode /50PC	50
29120199	GOF Connector ST Multimode /4PC	4

Mechanical properties

Flame retardant acc. to UL 94	V-0
Housing, material	Hpb59-1
Ferrule, material	Zirconia
Ferrule-Ø	2.5 mm
Tensile strength after assembly	100 N

Technical drawing

Dimensional drawing

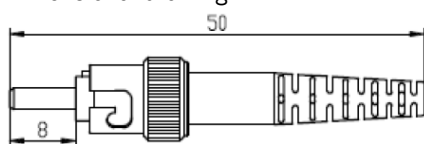

Standards / Approvals

Fibre optic connector interfaces – Part 2: Type BFOC/2,5 IEC 61754-2

Application range

Office, Data centers, Industry

Note

Photographs are not true to scale and do not represent detailed images of the respective products.

Document: DB29120198EN Version: 00	Page 1 of 1
---------------------------------------	-------------