

DATA SHEET	CE9914
LWL-Splicingassette	Valid from: 26.03.2018

Description

- Optical fiber splice cassette
- Standard mounting point
- Easy for fixing and maintenance




General characteristics

Splice capacity (max.)	24 (crimped splices) alternatively: 12 (heat shrunk splices)
Adhered fiber bending radius (min.)	40mm
Temperature range	-40°C to +80°C
Colour	white
Material	ABS

Technical drawing

Dimensional drawing

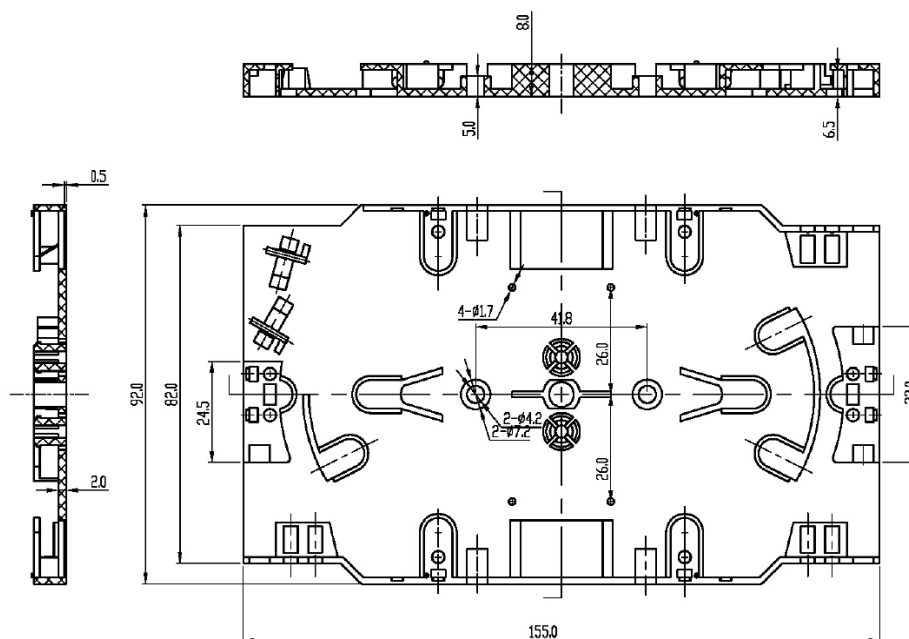

Application range

Office, industrial machinery and plant engineering

Note

Photographs are not true to scale and do not represent detailed images of the respective products.