

61721305	DATA SHEET
Valid from: 18.09.2020	SCHIRMKLEMME EMC-GUARD MOUNT

The shield clamp for direct assembly can be screwed directly, for example, onto the mounting plate. Simply push the cable shield into the shield clamp in order to achieve secure contact. The strain relief clasp offers the possibility of reducing strain on the cable sheath by using a cable tie.

Material:

spring steel,
Galvanic plated

Technical features:

Mounting
Clamping range

35mm DIN rail
3 - 18mm


Features:

Strain relief
Attenuation of conductance

with cable tie acc. to DIN 62444
up to 35dB by 30 MHz



Technical drawing

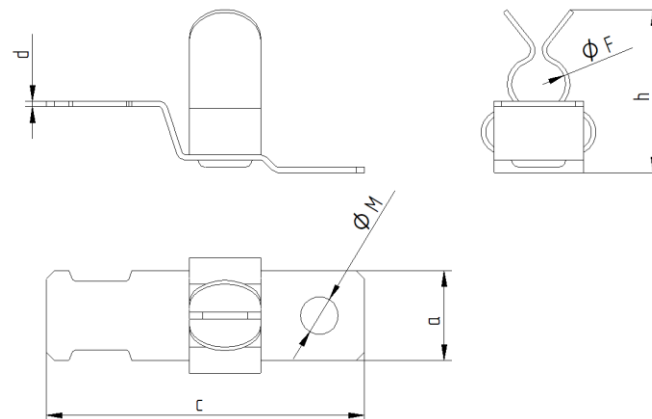

Maßtabelle:

Artikel Nr.	Breite a mm	Länge c mm	Dicke d mm	Höhe h mm	Klemmbereich Ø F mm	Montagebohrung Ø M mm
6172 1305	10	35,4	0,6	18,1	3 - 6	4,2
6172 1306	10	35,4	0,6	20,8	6 - 8	4,2
6172 1307	10	35,4	0,6	22,5	8 - 11	4,2
6172 1308	10	35,4	0,6	25,6	3 - 12	4,2
6172 1309	10	35,4	0,6	34,4	7 - 18	4,2