


Data Sheet - TRU Components

BN 3444038

LED signal lamp with 20LEDs

Model no.: TC-13776152

Drawing:

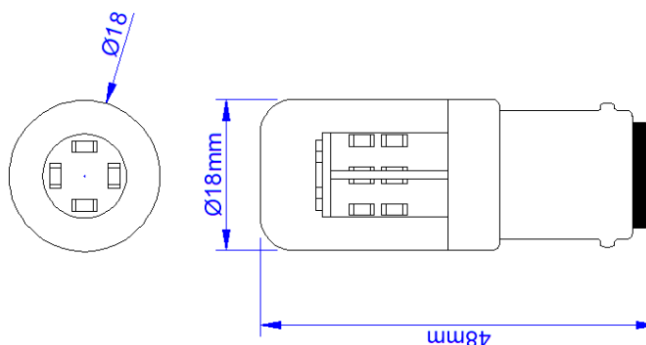

Technical Specifications:

Rated Voltage	10-30V DC
Power	1.5W
Radiation angle	360°
Luminous flux	200lm
Light color	White
White color temp.	6000-6500k
Cover material	PC
LED chips	SMD3014
Base	Ba15d
Life time	30000h
Bulb size	D18x48mm
Working temp.	−30°C~+60°C
Working humidity	20%~95%RH