


Data Sheet - TRU Components

BN 3444045

LED signal lamp with 39LEDs

Model no.: TC-13776180

Drawing:

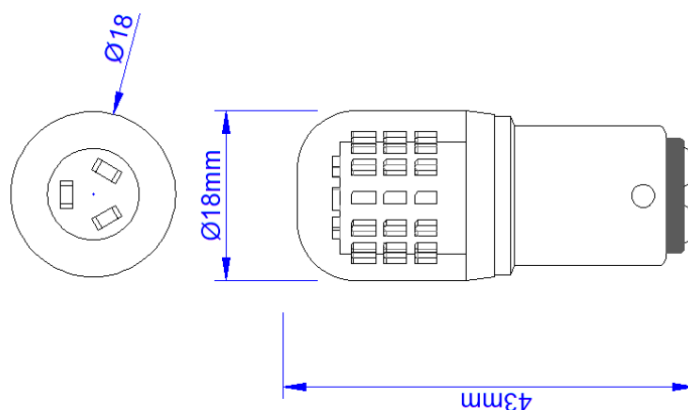

Technical Specifications:

Rated Voltage	10-30V DC
Power	2.5W
Radiation angle	360°
Luminous flux	250lm
Light color	White
White color temp	6000-6500K
Cover material	PC
LED chips	SMD3014 x39Leds
Base	Ba15d
Lifetime	30000h
Bulb size	D18x43mm
Working temp.	−30°C~+60°C
Working humidity	10%~95%RH