



MARAUDER Mini

A Mini Beast with Everything: Flood, Spot, and RGB.

MAX OUTPUT	MAX RUNTIME	MAX THROW
		
7,000 lumens	43.5 hours	600 meters

* This information is for market reference only. Please do not make it public.



Orange



Black



Midnight Blue

MARKET APPLICATIONS



Outdoors
Search and rescue
Law enforcement

UPC:

697549800049 5 (Black)
697549800053 2 (Orange)
697549800054 9 (Midnight Blue)

DESCRIPTION

The Marauder mini is a miniature version of Olight's Marauder series of flashlights. It's a powerful rechargeable dual beam LED flashlight with both flood and throw. Following the Marauder 2's lens design and composed of 9 LEDs surrounding the center, it enables seven brightness levels that provide 200-7000 lumens. A large round LED has been added to the center, offering a 600-meter spotlight beam. Three RGB color LEDs are uniformly distributed around the converging lens, making it suitable for use during any occasion. The toggle switch in the middle of the body allows quick access to select either spotlight or floodlight, while the upper rotary knob is intuitive to adjust brightness levels. Surrounding the rotary knob switch are indicators that reveal the brightness level, battery level, and three RGB light colors. The flashlight features a thermal sensor that automatically downshifts the light to achieve a body temperature below 50 degrees when there is continuous high output use. Powered by a customized 24Wh 32650 rechargeable lithium battery, it offers extended runtime and is compatible with Olight's MCC3 magnetic charging cable. Wrapped by 270-degree silicone, the flashlight's body surface provides a more comfortable and stable grip. The hidden lanyard hole design quickly manifests for ease of storage, carrying, and daily use. Smaller in size but still powered like a beast, the Marauder mini is a must have for search & rescue, hunters, and all outdoor enthusiasts.

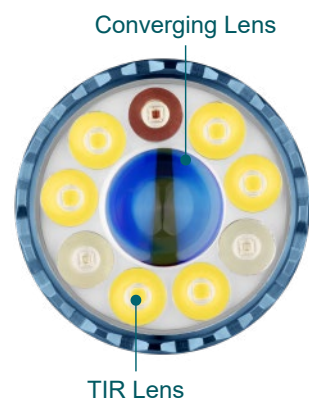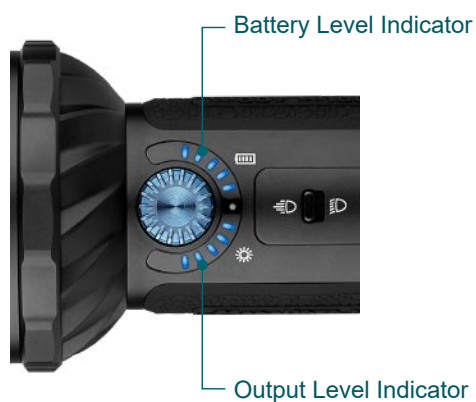

FEATURES

- **Smaller in size, yet powerful:** A smaller size than the previous Marauder series flashlights but with all power and function.
- **Dual-beam with flood and spot:** Features a 600-meter round spotlight beam from the central LED and a 7,000 lumens floodlight beam from 9 surrounding LEDs.
- **Uniformly distributed RGB color LEDs:** Three RGB color LEDs are uniformly distributed around the converging lens, making it suitable for use during any occasion.
- **Easy toggle switch & 3D rotary knob switch operation:** A simple toggle switch to select either spotlight or floodlight; an intuitive rotary knob switch to activate the light and circle through 7 output levels. (Note: Rotate the knob switch quickly over 90 degrees to unlock it)
- **Safest in its class:** A built-in thermal sensor and cooling fins to ensure safety in case of overheating and lens obstruction.
- **Large battery capacity:** Customized 24Wh 32650 rechargeable lithium battery ensures extended runtime. Now compatible with Olight's MCC3 magnetic charging cable.
- **Aesthetical and durable surface:** A silicone surface and hidden lanyard hole design enhance the portability for storage and daily use. It is also IPX8 waterproof rated and 1.5m impact resistant.

OUTPUT

Light Mode	Specifications	Mode 1	Mode 2	Mode 3	Mode 4	Mode 5	Mode 6	Mode 7	
Floodlight		100 lumens	200 lumens	400 z 180 z 90 lumens	800 z 400 z 200 lumens	1,600 z 800 z 400 lumens	3,200 z 1,300 z 450 lumens	7,000 z 1,600 z 900 lumens	
		35.5 hours	21 hours	10h30 + 10 + 10 minutes	320 + 5 + 15 minutes	160 + 10 + 15 minutes	10 + 170 + 10 minutes	2 + 160 + 10 minutes	
		40 meters	50 meters	80 meters	100 meters	150 meters	200 meters	310 meters	
		N/A							24,000 cd
		13Hz at 3,200 lumens							
Spotlight		50 lumens	100 lumens	200 lumens	300 z 100 lumens	500 z 300 z 100 lumens	700 z 500 z 105 lumens	900 z 500 z 330 lumens	
		43.5 hours	21.5 hours	11.5 hours	420 + 20 minutes	220 + 30 + 20 minutes	40 + 175 + 45 minutes	10 + 200 + 40 minutes	
		140 meters	200 meters	290 meters	350 meters	450 meters	500 meters	600 meters	
		N/A							90,000 cd

LIGHT MODE	SPECIFICATIONS	MODE 1	MODE 2	MODE 3	MODE 4
Red light		50 lumens	100 lumens	150 z 135 z 90 z 45 lumens	200 z 180 z 120 z 80 z 40 lumens
		30 hours	16.5 hours	100+430+10+10 minutes	5+305+10+10+10 minutes
		40 meters	60 meters	70 meters	90 meters
Green light		100 lumens	140 lumens	180 z 170 z 90 lumens	220 z 200 z 120 z 90 lumens
		22.5 hours	14 hours	490+10+10 minutes	30+250+10+10 minutes
		60 meters	70 meters	80 meters	90 meters
Blue light		55 lumens	80 lumens	100 z 40 lumens	120 z 40 lumens
		17 hours	10.5 hours	420+10 minutes	260+40 minutes
		40 meters	50 meters	60 meters	70 meters

* All data above are test results according to ANSI/NEMA FL 1-2009 standards.

LIGHT SOURCE

High Performance Cool White LED

DIMENSIONS

Length: 5.12in/130mm

Head Diameter: 2.58in/65.6mm

Body Diameter: 1.73in/44mm

WEIGHT

16.3oz/462g (Battery Included)

BODY MATERIAL

A6061-T6 Aluminum Alloy

POWERED BY

Customized 6500mAh 3.7V 24Wh 32650
Rechargeable Lithium Battery

WARRANTY

Olight's 5-Year Warranty

Visit: <https://olightworld.com/olight-warranty>

IN THE BOX

Marauder mini (Battery Included) x 1


MCC3 Magnetic Charging Cable x 1

Lanyard x 1

Holster x 1

User Manual x 1

WATERPROOF IPX8

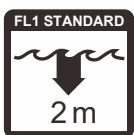

DROP TEST



COMPLIANCE



olightworld.com © OLIGHT 11/05/22 V1

Made in China

Note: There are slight differences between the picture and the real item caused by light color temperature. All the pictures are for reference only.