

PRODUCT SPECIFICATIONS

DOC NO. 230619XS01WXEU

X-SENSE

Your Trusted Home Safety Innovator

Key Features:

- ◆ Control the XS01-WX smart smoke alarm remotely via the mobile app and get quick app notifications for alarms, faults, and low battery warnings.
- ◆ The smoke detector can be connected to the X-Sense Home Security app via the Wi-Fi without a base station.
- ◆ This smoke alarm comes equipped with a photoelectric sensor that detects slow-burning and smoldering fires and has a long lifespan of up to 10 years.
- ◆ This smoke alarm is compact and ultra-slim, making it easy to take along when you travel
- ◆ Device Sharing Feature: Using the X-Sense Home Security app, you can share your devices with up to 12 different app accounts so the shared users can receive real-time push notifications.



Wi-Fi Smoke Alarm XS01-WX

Technical Specifications

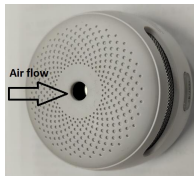


Sensor Type	Photoelectric
Operating Life	10 years
Power Supply	Replaceable 3 V CR123A lithium battery
Battery Life	1 year
Coverage Area	20-40 m ²
Alarm Volume	≥ 85 dB at 3m @ 3.2 ± 0.3 kHz pulsing alarm
Operating Temperature	4-38 ° C
Operating Relative Humidity	≤85%(non-condensing)
Silence Duration	About 9 minutes
Wireless Frequency	2.4 GHz (Incompatible with 5 GHz Wi-Fi network)
Wireless Protocol	IEEE 802.11b/g/n
Transmission Power	17 dBm
Product Weight	92g
Product Dimensions	78 x 78 x 48mm
Package Contents	1x Smoke Alarm (Pre-installed Battery) + 1 × Mounting bracket + 2 x Screws + 2 x Anchor Plugs + 1 × User Manual

Working Modes

Standby Mode	Flashes red once every 60 seconds.
Wi-Fi Connection	Flashes blue.
Device Test	Flashes red three times, then blue, with three short beeps.
Smoke Alarm	Flashes red once every seconds with constant short beeps.
Silence Function	Flashes red once every five seconds.
Low Battery Warning	Flashes red once every 60 seconds with one beep every 60 seconds.
Malfunction	Flashes red twice every 40 seconds with two beeps every 40 seconds.

Sensitivity

Smoke Sensitivity	Test Direction	Air Flow	Sensitivity
	180 ° from the LED	0.02m/s	0.092-0.195dB/m
			

Ordering Information

Part Number	Pack Quantity	Dimension (mm)	Weight	Units/Carton
XS01-WX (1-pack)	1 pack	79 x 79 x 58mm	140g	125 units
XS01-WX (3-pack)	3 units	155 x 58 x 84mm	420g	48 sets