


DATASHEET

PV Solar Extension Cable, Male to Female

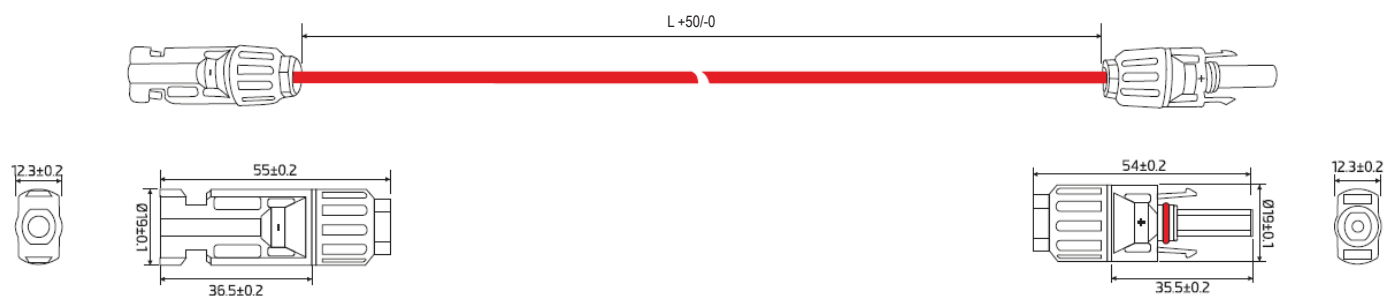

Item no	Color	Cable length (L)
3451433	Red	1 m
3451434	Black	1 m
3451436	Red	2 m
3451437	Black	2 m
3451550	Red	5 m
3451551	Black	5 m

Rated Voltage 1000 V/DC
 Rated Current 30 A max.
 Contact Resistance <4.0 mΩ
 Insulation Resistance >500 MΩ
 Connector Housing Polycarbonate (PC)
 Terminal Contact Tin Plated Copper

Cable Cross Section 6.0 mm²
 Cable Conductor Tin Plated Copper
 Cable Jacket XLPE
 Flame Retardant Grade UL 94V-0
 Operating Temperature -20 to +85°C
 Protection Level IP 67