


- **Style: Alternated Fish-Tank**
- **Size: Mid Tower supports up to ATX MB**
- **Material: Steel & Tempered Glass**

Main Features

- **Connection :** I/O ports with 2 x USB 3.0 & 1 x USB 3.2 (Gen 2) Type C
- **Ventilation :** Pre-installed 2 x CT120 Fan
- **Supports :** Supports AIO cooling solutions

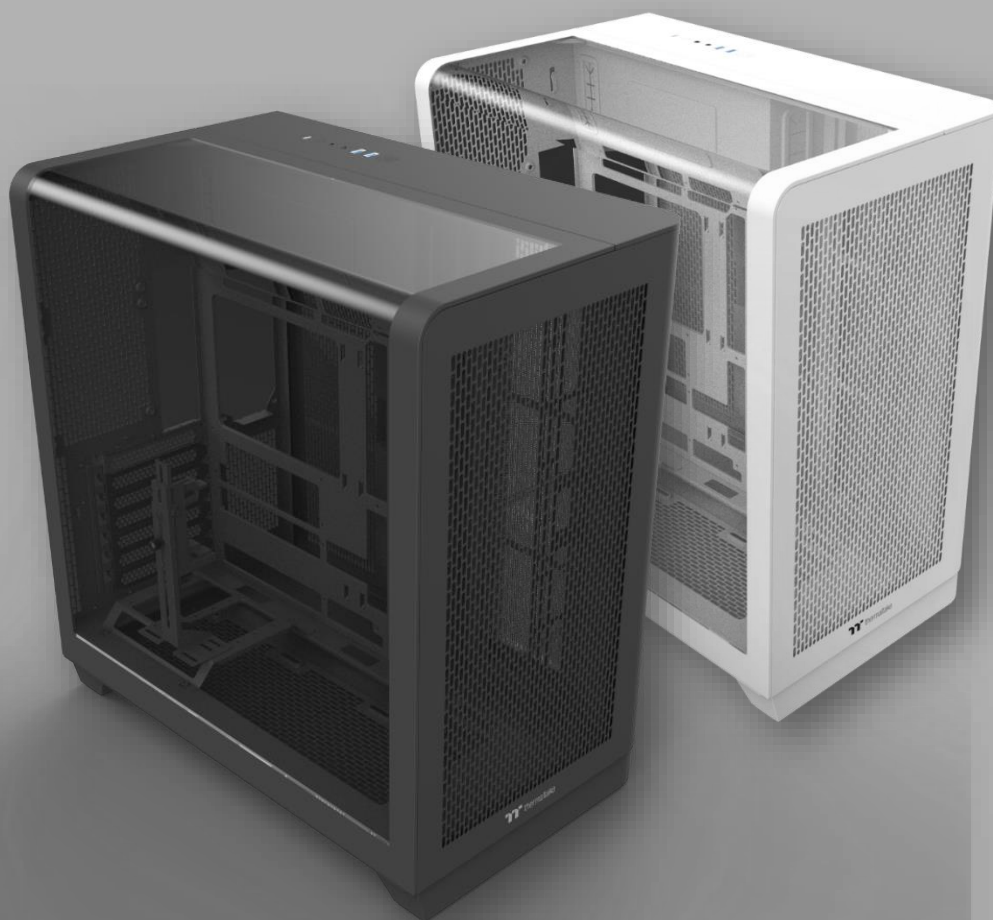

Specification

Model	View 390 Air	View 390 Air Snow
P/N	CA-11F-00M1WN-00	CA-11F-00M6WN-00
Color	Black	White
Case Type	Mid Tower	
Chassis Dimension (H*W*D)	502 x 287.2 x 485mm	
Side Panel	4mm Tempered Glass x 1	
Material	SPCC	
Cooling System	-	
Drive Bays	1 x 3.5" or 2 x 2.5"	
Expansion Slots	7	
Motherboards	6.7" x 6.7" (Mini ITX), 9.6" x 9.6" (Micro ATX), 12" x 9.6" (ATX)	
I/O Port	USB 3.2 (Gen 2) Type-C x 1, USB 3.0 x 2, HD Audio x 1	
PSU	Standard PS2 PSU (optional)	
Fan Support	Front: 3 x 120mm 2 x 140mm 2 x 200mm Right: 3 x 120mm Rear: 2 x 120mm Bottom: 3 x 120mm	
Radiator Support	Front Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm 1 x 280mm, 1 x 140mm Right Side(AIO): 1 x 360mm, 1 x 240mm, 1 x 120mm	
Clearance	CPU cooler height limitation: 160mm VGA length limitation: 390mm With Radiator /420mm Without Radiator PSU length limitation: 200mm	