

Indicator Lights Neon, LED and Filament Lamp

Colours and voltages:

-  **Neon** Available with Red, Amber, Green or Clear lenses
100/130V (marked 110V), 200/250V (marked 230V)
-  **LED - DC** Red, Yellow, Green, Blue, White
2.0/2.2V Resistors for other voltages available.
-  **LED - AC** Red, Yellow, Green, Blue, White
110-230V ac operation.
-  **Filament lamp** Available with Red, Amber, Green, Clear or Blue lenses
6V, 12/14V, 24/28V.

- ▶ Neon, LED, mains LED or filament lamp
- ▶ Bezel sizes from 6.7 to 16.3mm diameter
- ▶ Red, amber, green, blue and clear lenses
- ▶ Red, yellow, green, blue and white LEDs
- ▶ Wide choice of styles



UL file E63363

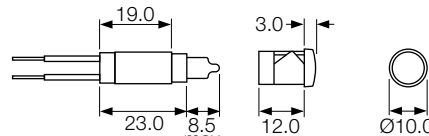
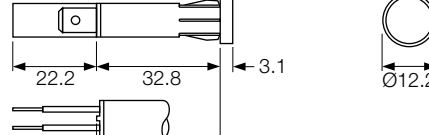
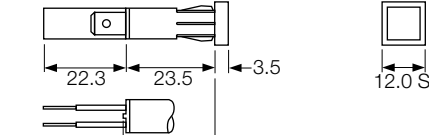
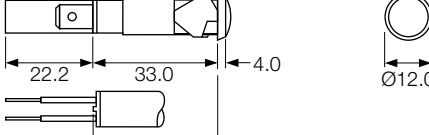
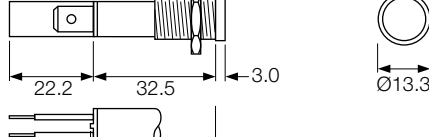
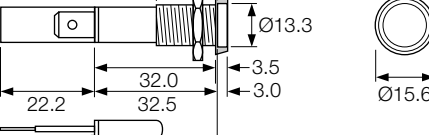
Approvals shown for neon versions only

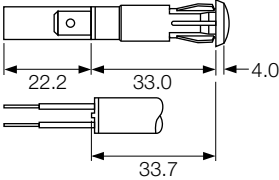
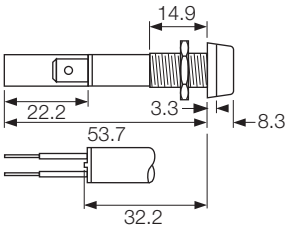
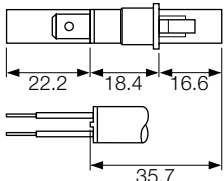
 
 
 


RoHS compliant

To create a catalogue number:

Refer to the 2 columns below (terminal and type), then state: Lens colour, voltage and whether neon, LED or filament lamp

TERM	TYPE	PANEL & °C	ILLUMINATION OPTIONS	DIMENSIONS (mm)
L	(L) 0569 AW	 9.0  0.8-2.5  Call sales	   	
L	(C) 0273 00	 9.0  2.0 max  page 6	   	
K 2.8				
H 4.8				
C 6.3				
L	(C) 0278 00	 9.0  2.0 max  page 6	   	
K 2.8				
H 4.8				
C 6.3				
L	(C) 0276 AA	 9.5  0.8-2.8  page 6	   	
K 2.8				
H 4.8				
C 6.3				
L	(C) 0275 00	 10.0  12.0 max  page 6	   	
K 2.8				
H 4.8				
C 6.3				
L	(C) 0275 00 Chrome bezel	 10.0  11.5 max  page 6	   	
K 2.8				
H 4.8				
C 6.3				

TERM	TYPE	PANEL & °C	ILLUMINATION OPTIONS	DIMENSIONS (mm)
L  K 2.8  H 4.8  C 6.3 	(C) 0276 00 	 10.0  2.8 max  page 6	  	  Ø12.0
L  K 2.8  H 4.8  C 6.3 	(C) 0277 00 Chrome bezel 	 10.0  12.0 max  page 6	  	  Ø14.6
L  K 2.8  H 4.8  C 6.3 	(C) 0273 LL 	 10.0  0.6-2.0  page 6	  	For sub-panel mounting, behind a facia.   Ø8.8
L  K 2.8  H 4.8  C 6.3 	(C) 2820 00 	 12.0  0.75-2.0  page 6	  	  Ø13.6
L  K 2.8  H 4.8  C 6.3 	(C) 2821 00 	 12.0 or 12.7  Ø12.0 = 0.8-2.5  Ø12.7 = 1.1-2.5  page 6	  	  Ø14.5
L  K 2.8  H 4.8  C 6.3 	(C) 0586 00 	 12.5  0.8-1.5  page 6	  	  15.5 Sq