

Indicator Lights Neon, LED and Filament Lamp

 
 
 
 
 
 
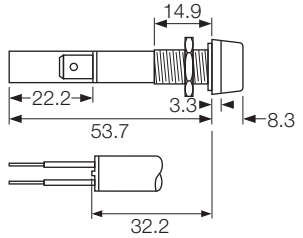
 
 
 
 
Colours and voltages:

 
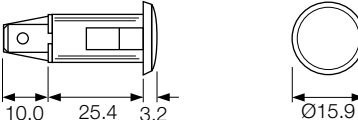
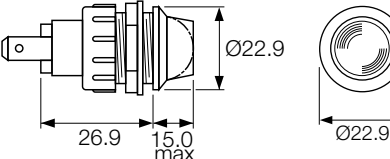
	Neon	Available with Red, Amber, Green or Clear lenses 100/130V (marked 110V), 200/250V (marked 230V)
	LED - DC	Red, Yellow, Green, Blue, White 2.0/2.2V Resistors for other voltages available.
	LED - AC	Red, Yellow, Green, Blue, White 110-230V ac operation.
	Filament lamp	Available with Red, Amber, Green, Clear or Blue lenses 6V, 12/14V, 24/28V.

- ▶ Neon, LED, mains LED or filament lamp
- ▶ Bezel sizes from 6.7 to 16.3mm diameter
- ▶ Red, amber, green and clear lenses
- ▶ Red, yellow, green, blue and white LEDs
- ▶ Wide choice of styles

To create a catalogue number:

Refer to the 2 columns below (terminal and type), then state: Lens colour, voltage and whether neon, LED or filament lamp

TERM	TYPE	PANEL & °C	ILLUM'N OPTIONS	APPROVAL	DIMENSIONS (mm)
L K 2.8 H 4.8 C 6.3	(C) 2870 00 	12.7 0.75-2.0 page 6	   	     	 9.9 22.8 5.0  Ø13.6
L K 2.8 H 4.8 C 6.3	(C) 0589 00 	12.7 0.8-1.5 page 6	   	     	 10.5 21.6 3.2  Ø15.9
L	L 0081 00 Chrome bezel 	12.7 9.5 page 6	   	     	 Ø16.0 18.0 11.4  Ø18.3
L K 2.8 H 4.8 C 6.3	(C) 0177 00 Chrome bezel 	12.7 12.0max page 6	   	     	 14.9 22.2 3.3 8.3 53.7 32.2  Ø14.6
L K 2.8 H 4.8 C 6.3	(C) 0067 00 Chrome bezel 	12.7 1.14max page 6	   	     	 38.1 5.1  Ø16.0
L C 6.3	(C) 0180AA 	12.7 19.0max page 6	   	    	 10.4 22.3 5.1  21.3  1.3 Starlock fixing

▶ TERM	▶ TYPE	▶ PANEL & °C	ILLUM'N OPTIONS	APPROVAL	▶ DIMENSIONS (mm)
L  C 6.3 	(C) 0180BB Chrome bezel 	 13.5  0.9-1.14  page 6	  	 	 10.4 22.3 5.1 Ø16.3
L  K 2.8  H 4.8  C 6.3  C 6.3 	(C) 0579 00 	 14.0  2.5max  page 6	   	  	 10.0 25.4 3.2 Ø15.9
C 6.3 	(C) 1092 	 19.0  4.0max  page 6	 		 26.9 15.0 max Ø22.9