



Datasheet – TRU Components


Item no.: 3461427, 3461428



Filter Regulator + Lubricator with auto drain



- Symbol

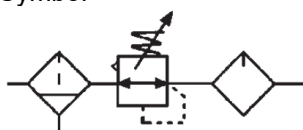

- Specification

Item No.	3461427	3461428
Port size (G)	G 1/4	G 1/2
Gauge Thread (G)	G 1/8	G 1/4
Fluid	Compressed air	
Operating pressure range (bar)	12 bar	
Max. Flow rate (L/min)	1700	3500
Ambient temperature (°C)	-10 to +60	
Filter precision	40 µm	
Cup material	Polycarbonate	



Datasheet – TRU Components


Item no.: 3461427, 3461428



Filter Regulator + Lubricator with auto drain

- Dimensions drawing

Item No.: 3461427

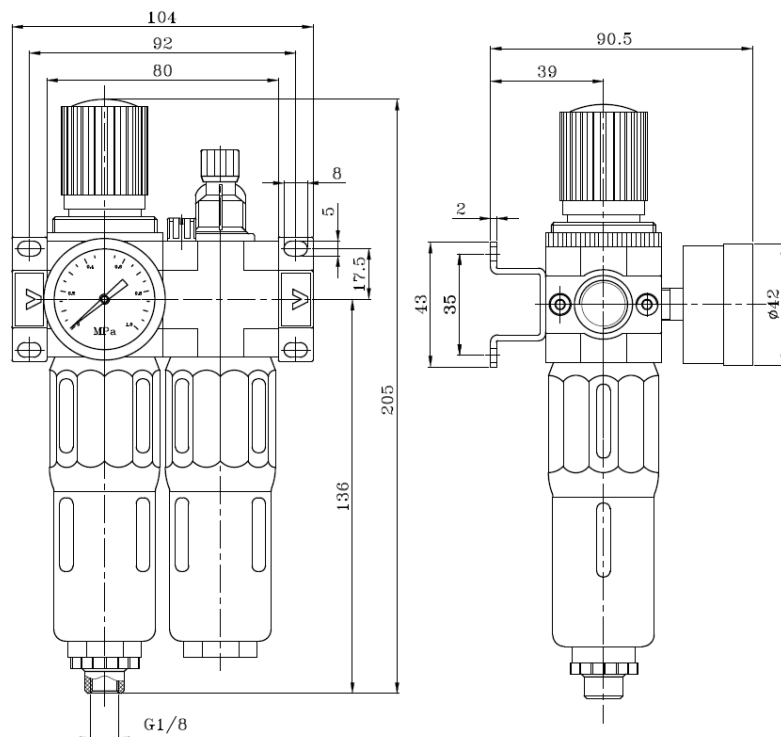

Item No.: 3461428

