



Datasheet – TRU Components

Item no.: 3461429 - 431



Filter with auto drain



- Symbol



- Specification

Item No.	3461429	3461430	3461431
Port size (G)	G 1/4	G 1/2	G 3/4
Fluid	Compressed air		
Operating pressure range (bar)	12 bar		
Max. Flow rate (L/min)	2000	4000	4000
Ambient temperature (°C)	-10 to +60		
Filter precision	40 µm		
Cup material	Polycarbonate		



Datasheet – TRU Components


Item no.: 3461429 - 431



Filter with auto drain

- Dimensions drawing

Item No.: 3461429

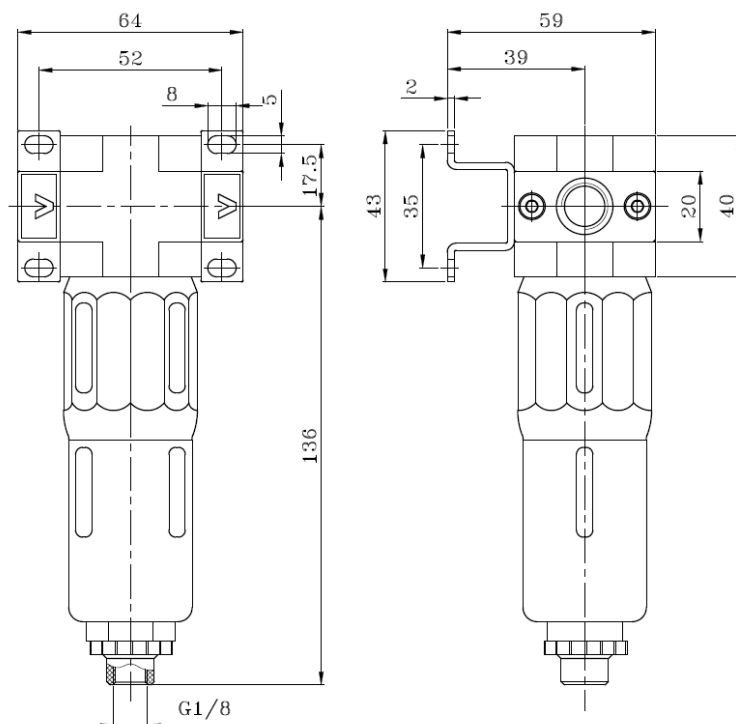

Item No.: 3461430, 3461431

