



Datasheet – TRU Components


Item no.: 3461432 - 434



Regulator



- Symbol

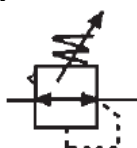

- Specification

Item No.	3461429	3461430	3461431
Port size (G)	G 1/4	G 1/2	G 3/4
Gauge Thread (G)	G 1/8	G 1/4	G 1/4
Fluid	Compressed air		
Operating pressure range (bar)	12 bar		
Max. Flow rate (L/min)	1700	3500	3500
Ambient temperature (°C)	-10 to +60		

Datasheet – TRU Components


Item no.: 3461432 - 434



Regulator

- Dimensions drawing

Item No.: 3461432

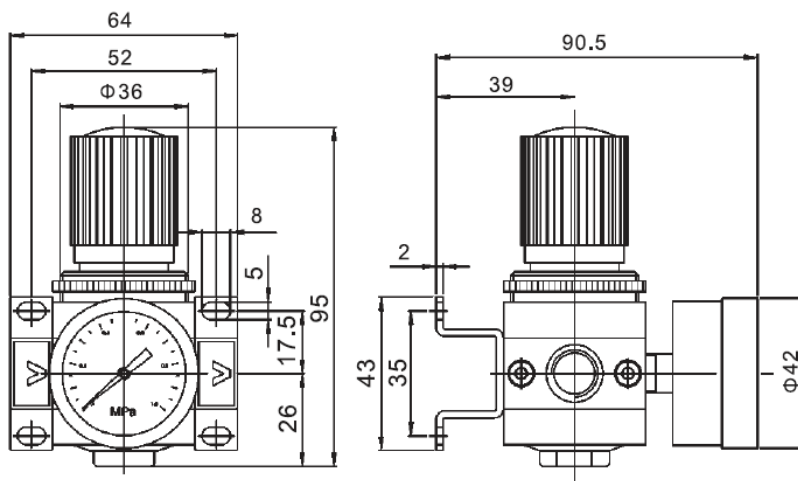

Item No.: 3461433, 3461434

