


Technical Datasheet

EasyLan[®] I-V(ZN)HH LED Duplex FO patch and adapter cables

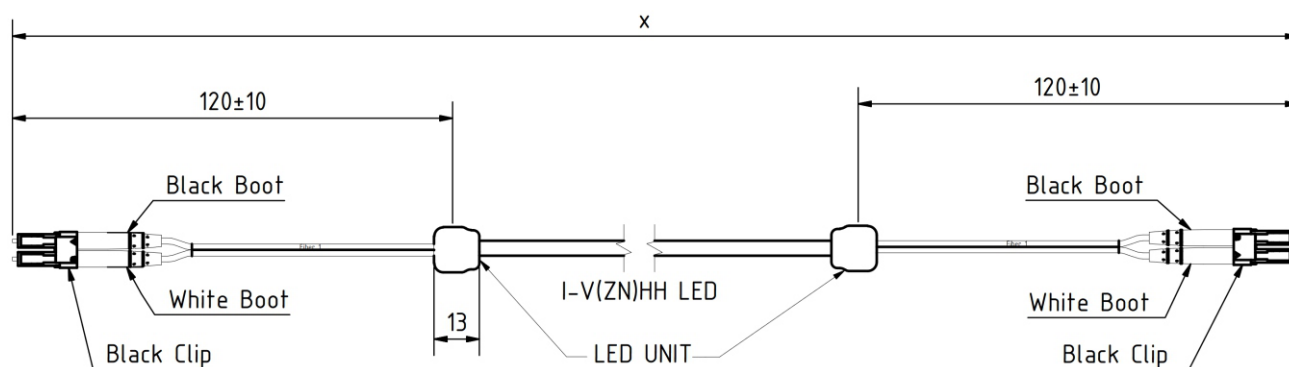

Length tolerances

X < 5m	- 0,00 m + 0,07 m
X > 5m	- 1% + 1%

a	Neuerstellung	25.04.2018	ZK	drawn	25.04.2018	ZK	 EasyLan® ...for a better connectivity
				appr.	25.04.2018	FG	
				Titel: EasyLan® I-V(ZN)HH LED Duplex FO patch and adapter cabels			
				Drawing number:			
Index	Revision code	Date	Name	ZN-FO181353			Dimensions: mm Original: DIN A4 Sheet 1 of 2

Technical Data

OS2	
Fiber	OS2 E09/125
Outer Jacket	LSZH
Color Jacket	yellow
Cable structure	I-V(ZN)HH-1,8
Temperature during operating	-20°C to +70°C

OM3	
Fiber	OM3 G50/125
Outer Jacket	LSZH
Color Jacket	aqua
Cable structure	I-V(ZN)HH-1,8
Temperature during operating	-20°C to +70°C

OM4	
Fiber	OM4 G50/125
Outer Jacket	LSZH
Color Jacket	heather violet
Cable structure	I-V(ZN)HH-1,8
Temperature during operating	-20°C to +70°C

OM5	
Fiber	OM5 G50/125
Outer Jacket	LSZH
Color Jacket	lime green
Cable structure	I-V(ZN)HH-1,8
Temperature during operating	-20°C to +70°C

a	Neuerstellung	25.04.2018	ZK	drawn	25.04.2018	ZK	 EasyLan® ...for a better connectivity
				appr.	25.04.2018	FG	
				Titel: EasyLan® I-V(ZN)HH LED Duplex FO patch and adapter cables			
				Drawing number: ZN-FO181353			
Index	Revision code	Date	Name				Dimensions: mm
							Original: DIN A4
							Sheet 2 of 2